


# ST SERIES

## RELAY SOCKETS

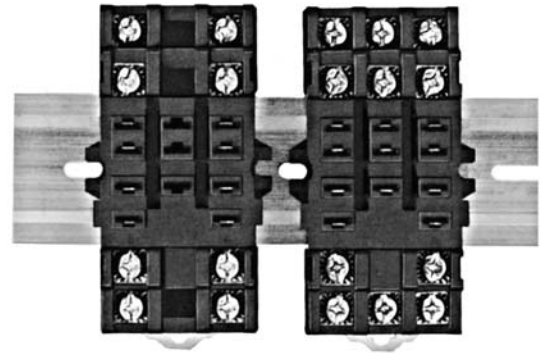

CUSTOM CONNECTOR

**DESCRIPTION** 8 and 11 Pin Square Base Sockets, DIN Rail Mountable

**ELECTRICAL RATING** • 300 Volts, 15 Amps

**CONSTRUCTION**

- Contacts** • Brass, Nickel Plated
- Screws** • Binder Head, 6 - 32 x 1/4" Steel, Zinc Plated
- Pressure Clamp, 6 - 32 X 5/16" Steel Zinc Plated, Wire Range #12 - #22 Solid or Stranded
- Molding** • Break Resistant Thermoplastic Black Standard, Grey Available

**AGENCY APPROVALS** • UL recognized, File No. E60008



• CSA certified, File No. LR29513


• CE

### ORDERING CODE


PART NO.	DESCRIPTION	TERMINAL TYPE
ST08	DPDT, 8 Pin Blade	Binder Head Screws
ST08-PC	DPDT, 8 Pin Blade	Pressure Clamp Screws
ST11	3PDT, 11 Pin Blade	Binder Head Screws
ST11-PC	3PDT, 11 Pin Blade	Pressure Clamp Screws

### ACCESSORIES

PART NO.	DESCRIPTION (Refer to the accessories pages 25-27))
C-103-PM	Prepunched Aluminum DIN Rail (1 Meter Lengths)
C-104-PM	Prepunched Steel DIN Rail (1 Meter Lengths)
C-105-PM	Prepunched Steel DIN Rail (1 Meter Lengths)
C-106-2PM	Prepunched Steel DIN Rail (2 Meter Lengths)
C-108-PM	Prepunched Raised Aluminum DIN Rail (1 Meter Lengths)
C-108-2PM	Prepunched Raised Aluminum DIN Rail (2 Meter Lengths)
HDB-8	Hold Down Spring

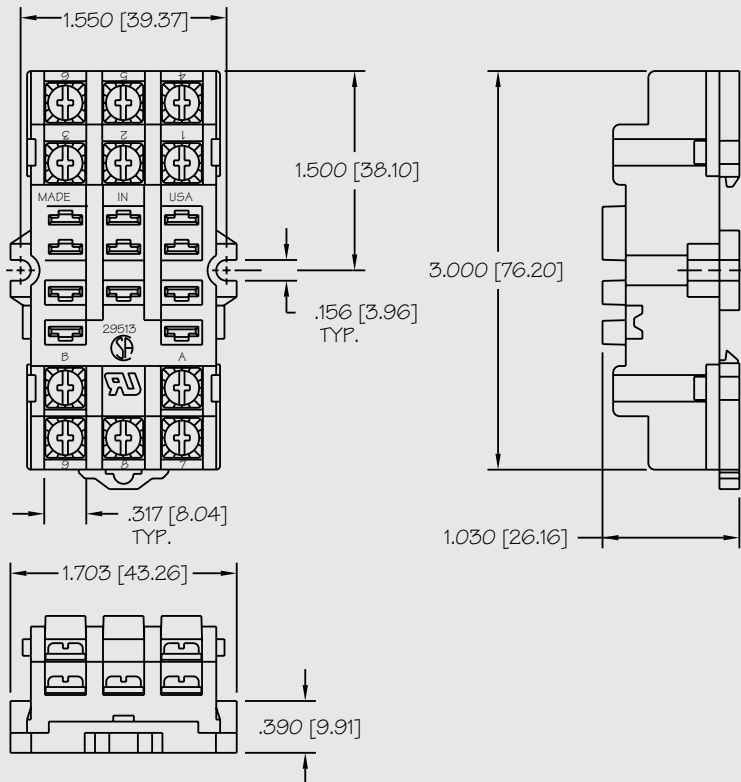

#### TERMINAL LOCATION

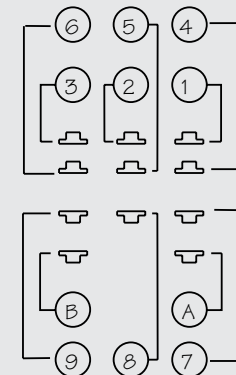

TOP VIEW

#### ST SERIES NOTE:

Terminals 2,5 and 8 omitted on DPDT, 8 Pin models