

MODEL TL-5902


International size reference: 1/2AA, ER14252

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)


■ Nominal capacity @ 0.5 mA, to 2V	1.2 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	50 mA
■ Maximum pulse current capability	100 mA
■ Weight	9.2g (0.324 oz)
■ Volume	4.3 cc
■ Operating temperature range	-55°C to +85°C
■ U.L. Component Recognition, MH 12193	

TADIRAN LITHIUM BATTERIES

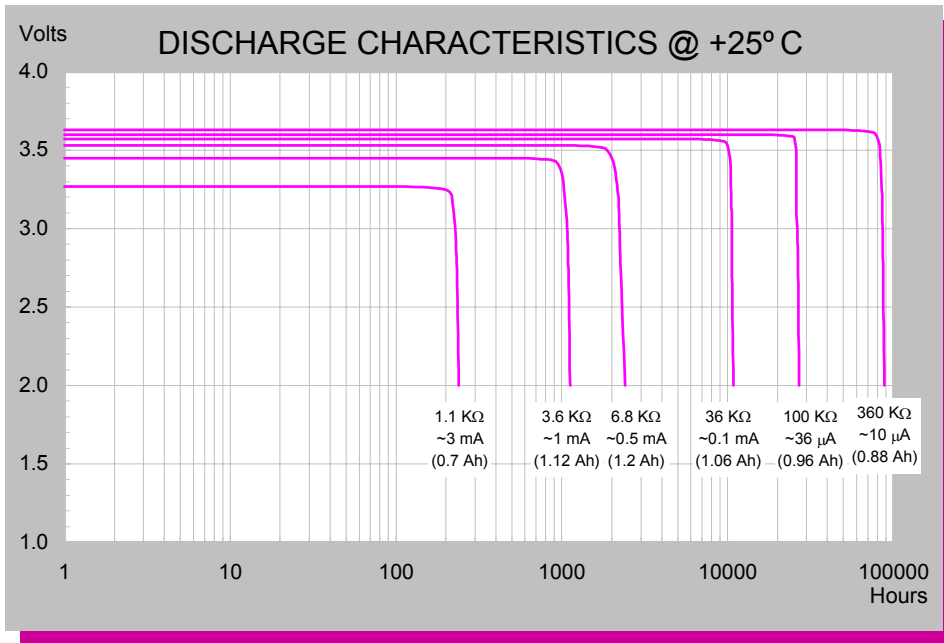

AVAILABLE TERMINATIONS

SUFFIX- /S STANDARD	15-5902-21500
SUFFIX- /T SOLDER TABS	15-5902-31500
SUFFIX- /P AXIAL PINS	15-5902-41500
SUFFIX- /PT2 RADIAL PINS	15-5902-36500
SUFFIX- /TP POLARIZED TABS	15-5902-52500
SUFFIX- /PT POLARIZED TABS	15-5902-53500

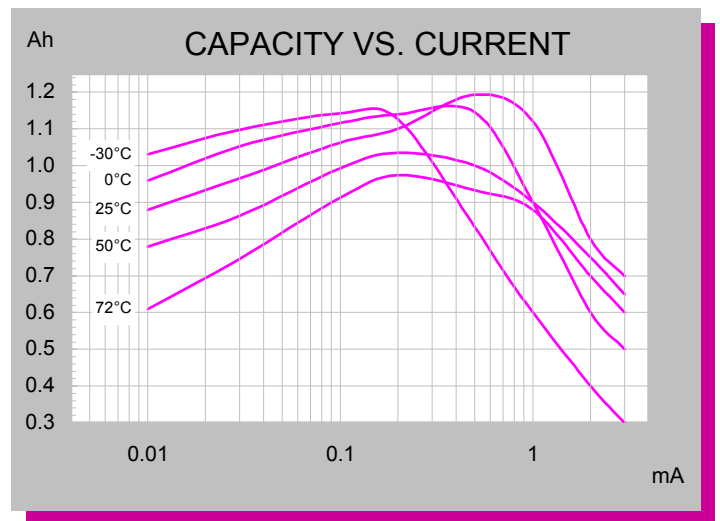

LITHIUM XTRA

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance. Rev. B 03/03