

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0010013026](#)
Status: **Active**
Overview: [SPOX Connector System](#)
Description: 5.08mm Pitch SPOX Crimp Terminal Housing, 2 Circuits, Natural

Documents:

[3D Model](#) [Product Specification PS-5197-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [5197](#)
 Application Signal, Wire-to-Board
 Overview [SPOX Connector System](#)
 Product Name SPOX
 UPC 800753612631

Physical


Circuits (maximum) 2
 Color - Resin Natural
 Flammability 94V-2
 Gender Receptacle
 Glow-Wire Capable No
 Material - Resin Nylon
 Net Weight 766.600/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 5.08mm
 Stackable No
 Temperature Range - Operating -40° to +105°C

Material Info

Engineering Number 5197-02

Reference - Drawing Numbers

Product Specification PS-5197-001
 Sales Drawing SD-5197-N

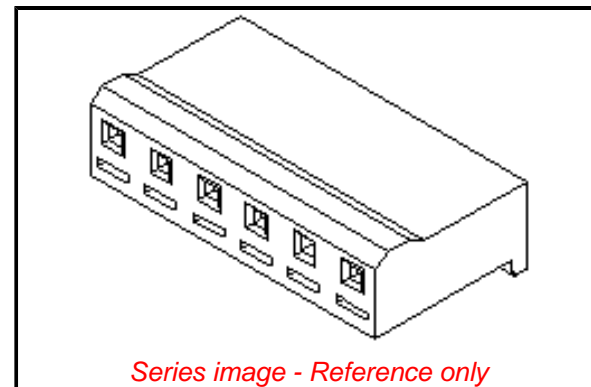

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[5197 Series](#)

Mates With

[5281](#) , [5282](#)

Use With

[5194](#) , [5225](#)