




Electrical Commercial and Industrial

3M™ Scotchlok™ Male Disconnect, Fully Nylon Insulated Butted Seam MNU14-250DMIK, 16-14 AWG

3M ID 80610057772 UPC# 00054007023005 3M Product Number MNU14-250DMIK

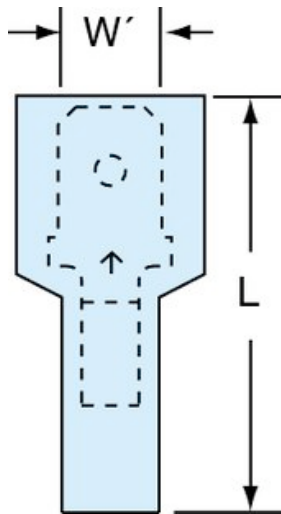

This terminal has a wire range of 16-14 AWG and has case quantities of 1000 per case.



Overview

Documentation

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.085 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Scotchlok
China RoHS - Below MCV	Yes
Conductor Sizes	16 - 14 AWG
CSA File Number	LR22190
Diameter (D)	0.3 Inch
EU RoHS Compliant	Yes
Fastener Orientation	Male
Insulation Material	Nylon
Length (L)	0.95 Inch
Male Tab Width (W')	0.25 Inch
Maximum Insulation Outer Diameter	0.17 Inch

Maximum Insulation Outer Diameter	0.17 Inch
Packaging	1000 per bulk box
Pad Width	0.250 Inch
Terminal Style	Fully Insulated
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512
Width (W)	0.44 Inch

Manufacturing Origin: USA

© 3M 2014. All Rights Reserved.