


Sealed Nickel Cadmium Batteries

Model: PCBM-3.6



Specifications

Nominal Voltage		3.6 Volt
Rated Capacity		110 mA
Dimensions	Diameter in. (mm)	0.57 (14.5)
	Height in. (mm)	2.05 (52.0)
	Height with solder tabs	2.05 (52.0)
Weight Approx.	Weight Approx.	21 gm
	Internal Resistance	< 45 mΩ
	Standard Charge (0.1C)	11 mA
	Trickle Charge	(0.03C)~(0.05C)
	Fast Charge ΔV	n/a
Recommended Operating Temperature Range	Std/Trickle Charge	20±5°C
	Fast Charge	n/a
	Discharge	20±5°C
	Storage	-20°C to 45°C
Standard Discharge (0.2C) Cut Off Voltage		1.0V per cell
High Rate Discharge (1 C) Cut Off Voltage		1.0V per cell


Dimensions

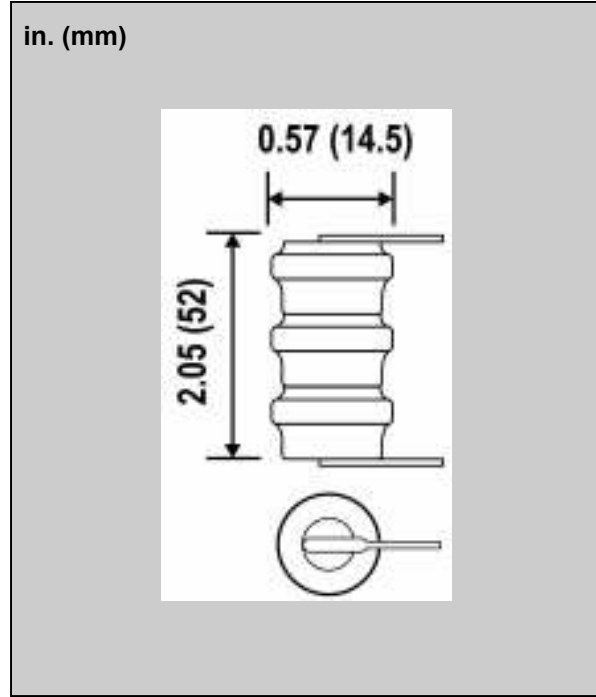


Charging and Discharging Characteristics

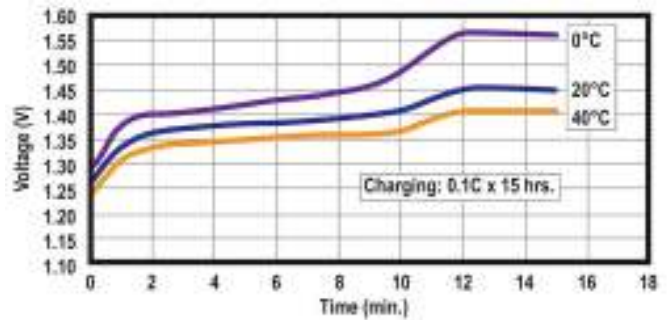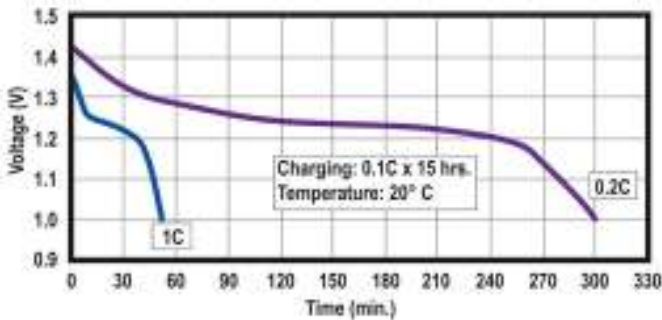


Fast Charge

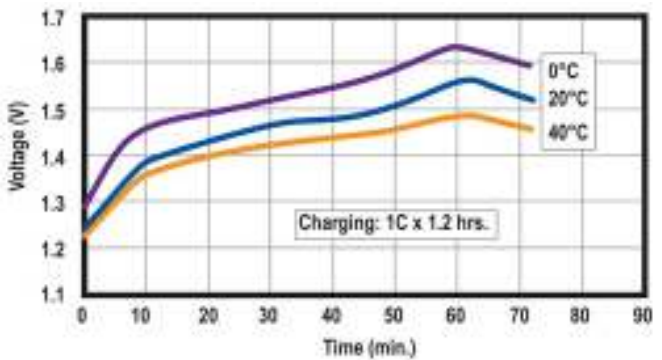


Trickle Charge

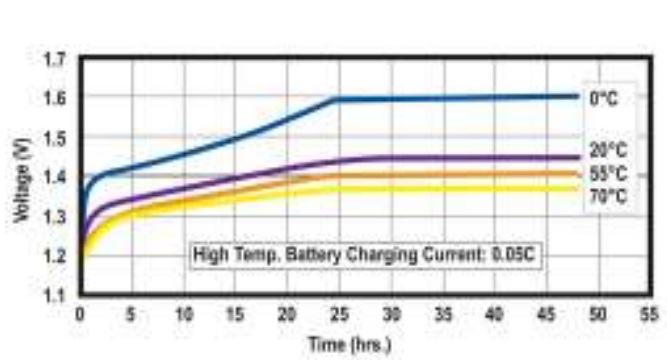


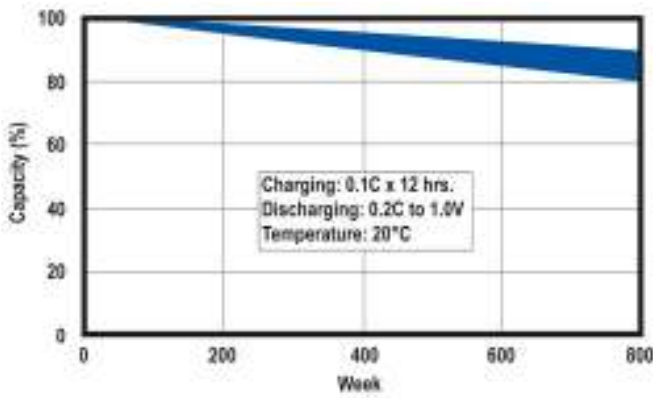


Standard Battery Cycle Life

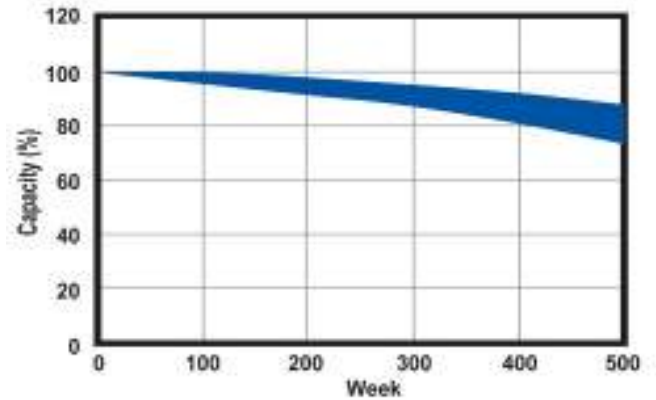


Fast Charging Cycle Life

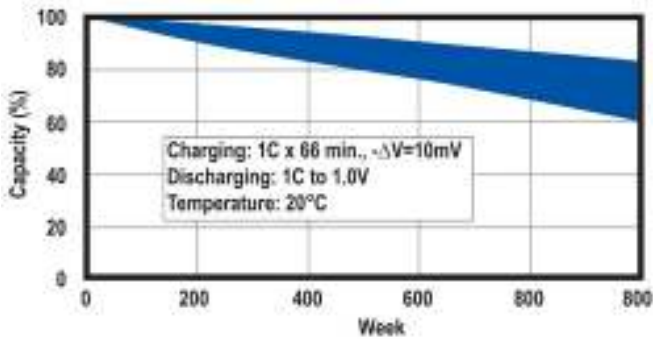


Cycle Life Using Trickle Charging

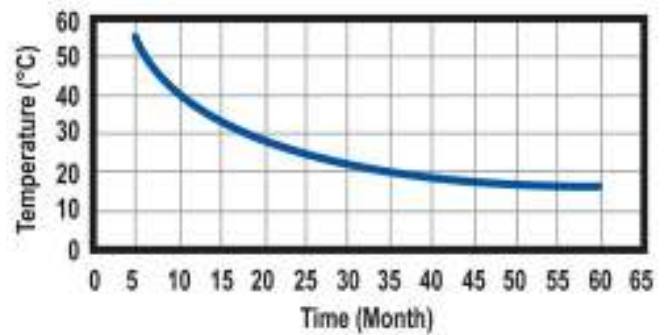

Stand-by Battery Life

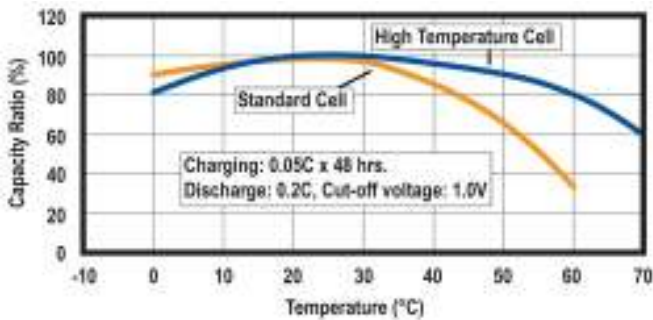

Capacity vs. Temperature

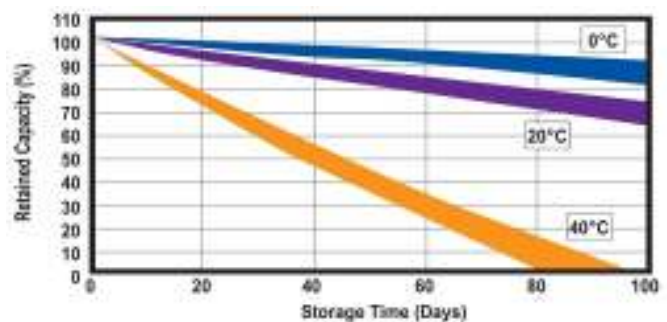

Retained Capacity In Storage

Corporate Headquarters and Domestic Sales
 Power-Sonic Corporation • 7550 Panasonic Way • San Diego, CA 92154 • U.S.A
 Phone: (619) 661-2020 • Fax: (619) 661.3650
 Email Sales: national-sales@power-sonic.com
 Email Customer Service: customer-service@power-sonic.com
 E-mail Technical Support: technical-support@power-sonic.com

International Sales
 Power-Sonic Corporation • P.O. Box 5242 • Redwood City, CA 94063 • U.S.A.
 Phone: (650) 364-5001 • Fax: (650) 366-3662
 Email Sales: international-sales.com@power-sonic.com

www.power-sonic.com