


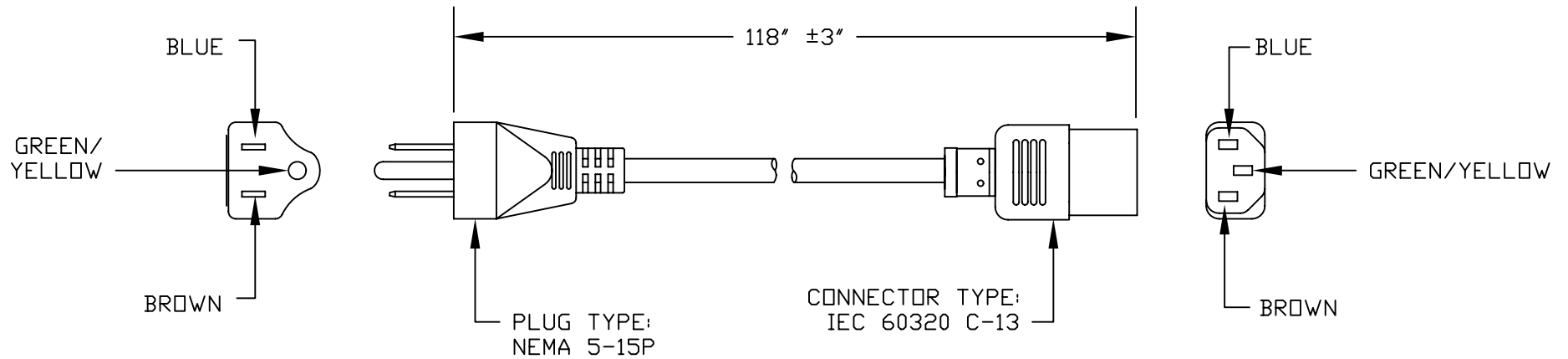
VOLEX

GROUP

## Standard Cord Details: 17605 10 B1




Specifications	
Certifications	
Part Number	17605 10 B1
Connector Type	C13
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	PS204
Connector Catalog No.	386A
Cable	SJT AWG 14x3 (Shielded)
Jacket Color	Black
Length in Feet	9'10
Length in Meters	3
Temperature Rating	60 C
Packaging Units Per Carton	50
Color Coding	International
Nominal OD in Inches	0.39
Nominal OD in Millimeters	9.91



VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE

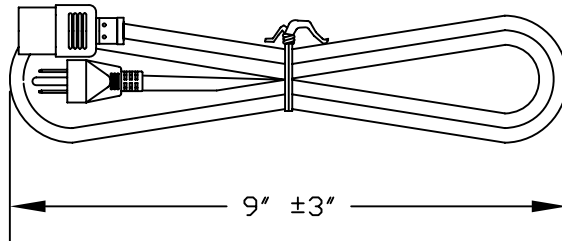

**NOTES**

- 1) CORDAGE: CORDAGE: 14/3 SJT, FOIL SHIELDED WITH DRAIN WIRE, 60°C, BLACK
- 2) APPROVALS:
- 3) RATING: 15 AMP/125 VOLTS
- 4) FLAME RATING : FT2
- 5) DRAIN WIRE CONNECTED TO GROUND PIN OF PLUG MOLD ONLY. DRAIN WIRE IS CUT FLUSH WITH JACKET EDGE PRIOR TO MOLDING CONNECTOR.
- 6) ALL DIMENSIONS IN inches.
- 7) PACKAGING: 50 PIECES/CARTON.

1	C.U.D - NEW RELEASE	7/26/07
REV	DESCRIPTION	DATE



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

**Proprietary Notice:**

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

**MATERIAL:**  
PLUG: PVC, BLACK  
JACKET: PVC, BLACK  
RoHs/Prop 65 Compliant

**FINISH:**  
JACKET: SMOOTH

**SCALE:**  
NOT TO SCALE

**ECD:**  
N/A

**ITEM DESCRIPTION**  
SHIELDED CORDSET-NORTH AMERICAN  
DETACHABLE POWER SUPPLY CORD (9'10")

**TOLERANCE UNLESS OTHERWISE SPECIFIED**  
.XXX ± .005  
.XX ± .02  
.X ± .03  
FRACT. ± 1/32  
ANGULAR ± 1/2°

APPROVED	DRAWN BY	DATE:
STC	STC	7/26/07

PART NO. 17605 10 B1