


VOLEX


GROUP

## Standard Cord Details: 17743 10 B1




Specifications	
<b>Certifications</b>	
<b>Part Number</b>	17743 10 B1
<b>Connector Type</b>	C13
<b>Plug Type</b>	5-15P
<b>Category</b>	Plastic
<b>Application</b>	Detachable
<b>Plug Catalog No.</b>	PS204
<b>Connector Catalog No.</b>	386A
<b>Cable</b>	SVT AWG 18x3 (Shielded)
<b>Jacket Color</b>	Black
<b>Length in Feet</b>	9'10"
<b>Length in Meters</b>	3
<b>Temperature Rating</b>	60 C
<b>Packaging Units Per Carton</b>	H-100, H-25
<b>Color Coding</b>	International
<b>Nominal OD in Inches</b>	0.253
<b>Nominal OD in Millimeters</b>	6.43

2997mm ±76mm [118" ±3"]

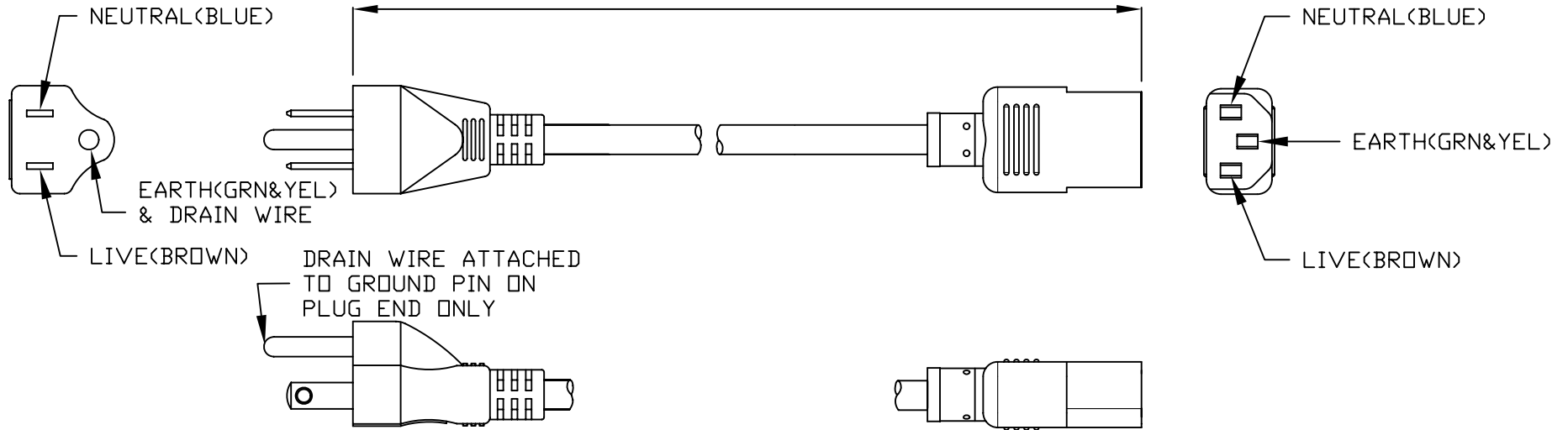

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE

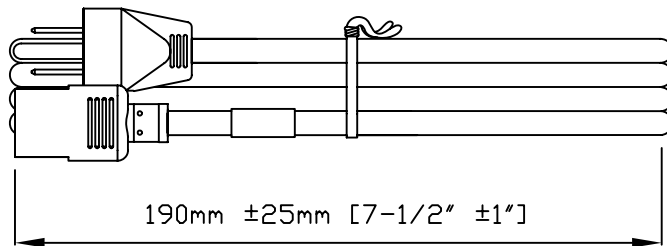

**NOTES:**

- 1) CORDAGE: 18/3 SVT, FOIL SHIELDED, 60°C, BLACK
- 2) APPROVALS:
- 3) RATING: 10 AMP/125 VOLTS
- 4) FLAME RATING : FT2
- 5) PACKAGING: 35 PIECES PER CARTON

REV	DESCRIPTION	DATE
1	C.U.D - NEW RELEASE	6/5/07



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

**Proprietary Notice:**

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

**MATERIAL:**  
CONNECTOR, PLUG: PVC, BLACK  
JACKET: PVC, BLACK  
  
ROHS COMPLIANT  
  
**FINISH:**  
JACKET: SMOOTH

**SCALE:**  
NOT TO SCALE  
  
**ECD:**  
N/A  
  
**TOLERANCE UNLESS OTHERWISE SPECIFIED**  
.XXX ± .005  
.XX ± .02  
.X ± .03  
FRACT. ± 1/32  
ANGULAR ± 1/2°

**ITEM DESCRIPTION**  
CORDSET - NORTH AMERICAN  
DETACHABLE POWER SUPPLY CORD (9'10")

APPROVED STC	DRAWN BY STC	DATE: 6/5/07
-----------------	-----------------	-----------------

PART NO.  
**17743 10 B1**