




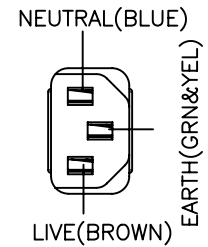
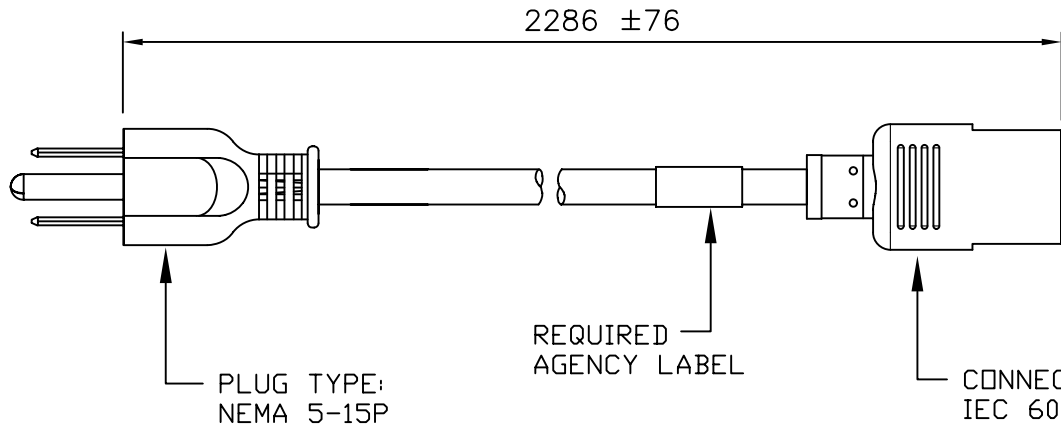
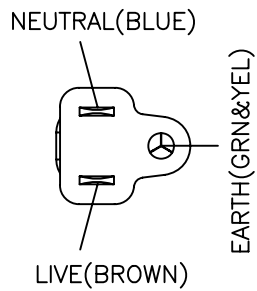
VOLEX

GROUP

## Standard Cord Details: 17757 10 B1




Specifications	
<b>Certifications</b>	
<b>Part Number</b>	17757 10 B1
<b>Connector Type</b>	C13
<b>Plug Type</b>	5-15P
<b>Category</b>	Plastic
<b>Application</b>	Detachable
<b>Plug Catalog No.</b>	US15S3
<b>Connector Catalog No.</b>	V1625
<b>Cable</b>	SVT AWG 18x3
<b>Jacket Color</b>	Black
<b>Length in Feet</b>	7'6"
<b>Length in Meters</b>	2.3
<b>Temperature Rating</b>	105C
<b>Packaging Units Per Carton</b>	50
<b>Color Coding</b>	International
<b>Nominal OD in Inches</b>	0.246
<b>Nominal OD in Millimeters</b>	6.25
<b>Notes</b>	See 17251 for 60C version.



VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE

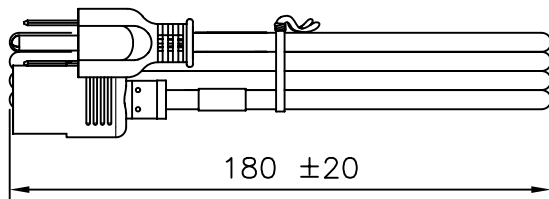

**NOTES:**

- 1) CORDAGE: 18/3 SVT, 105°C, BLACK
- 2) APPROVALS:
- 3) RATING: 10 AMP/125 VOLTS
- 4) FLAME RATING : FT2
- 5) PACKAGING: 100 PIECES/CARTON
- 6) ALL DIMENSIONS IN MILLIMETERS.

REV	DESCRIPTION	DATE
2	REVISED TO SHOW CHINA MANUFACTURED CORD	11/26/07
1	C.U.D - NEW RELEASE	12/20/05



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Fremont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

**Proprietary Notice:**

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

**MATERIAL:**  
 PLUG: PVC, BLACK  
 JACKET: PVC, BLACK  
 RoHs/Prop 65 Compliant

**FINISH:**  
 JACKET: SMOOTH

**SCALE:**  
 NOT TO SCALE

**ECD:**  
 N/A

**ITEM DESCRIPTION**  
 CORDSET-NORTH AMERICAN  
 DETACHABLE POWER SUPPLY CORD (7.5')

**TOLERANCE UNLESS OTHERWISE SPECIFIED**  
 .XXX ± .005  
 .XX ± .02  
 .X ± .03  
 FRACT. ± 1/32  
 ANGULAR ± 1/2°

APPROVED CR	DRAWN BY MAF	DATE: 12/20/05
----------------	-----------------	-------------------

**PART NO.**  
 17757 10 B1