





VOLEX

GROUP

Standard Cord Details: 17758 10 B1




Specifications	
Certifications	
Part Number	17758 10 B1
Connector Type	C13
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	US15S3
Connector Catalog No.	386A
Cable	SJT AWG 18x3
Jacket Color	black
Length in Feet	6'7"
Length in Meters	2
Temperature Rating	105 C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
Nominal OD in Inches	0.315
Nominal OD in Millimeters	8
Notes	See 17500 for 60C version. See 17729 for shielded version.

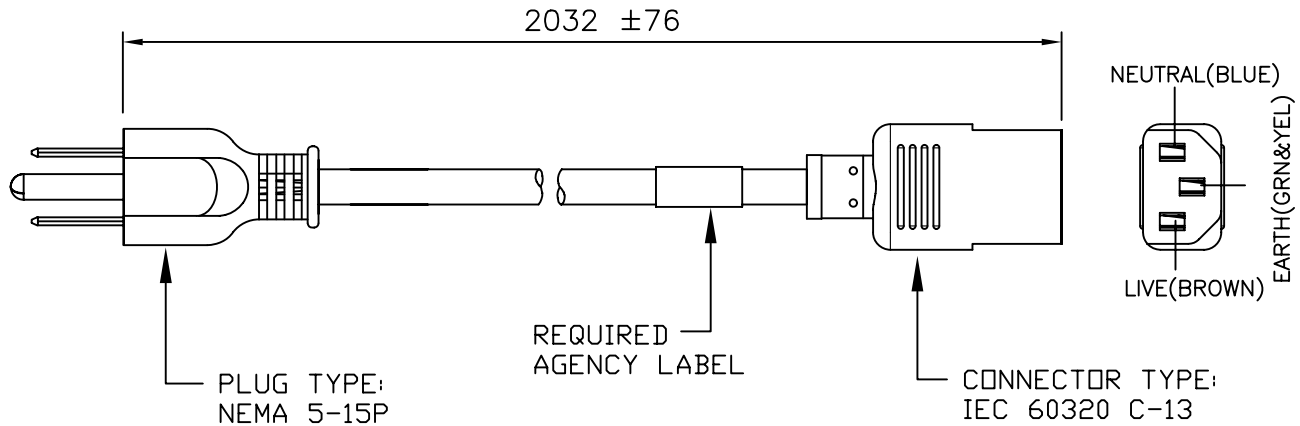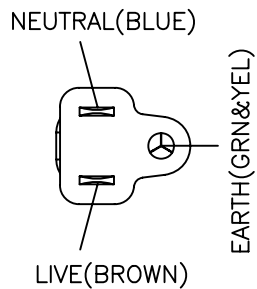

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE

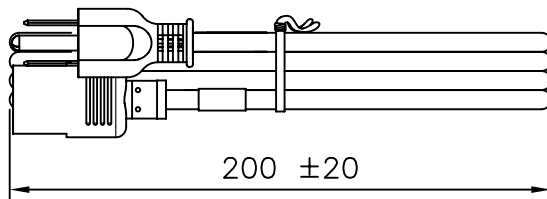

- NOTES:**
- 1) CORDAGE: 18/3 SJT, 105°C, BLACK
 - 2) APPROVALS:
 - 3) RATING: 10 AMP/125 VOLTS
 - 4) FLAME RATING : FT2
 - 5) PACKAGING: 80 PIECES/CARTON
 - 6) ALL DIMENSIONS IN MILLIMETERS.

3	REVISED TO SHOW CHINA MANUFACTURED CORD	11/26/07
2	FORMAT UPDATE	08/18/04
1	C.U.D - NEW RELEASE	06/10/04
REV	DESCRIPTION	DATE



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
 PLUG: PVC, BLACK
 JACKET: PVC, BLACK
 RoHs/Prop 65 Compliant

FINISH:
 JACKET: SMOOTH

SCALE:
 NOT TO SCALE

ECD:
 N/A

ITEM DESCRIPTION
 CORDSET-NORTH AMERICAN
 DETACHABLE POWER SUPPLY CORD (6'7")

TOLERANCE UNLESS OTHERWISE SPECIFIED
 .XXX ± .005
 .XX ± .02
 .X ± .03
 FRACT. ± 1/32
 ANGULAR ± 1/2°

APPROVED	DRAWN BY	DATE:
CR	ARK	06/10/04

PART NO.
 17758 10 B1