




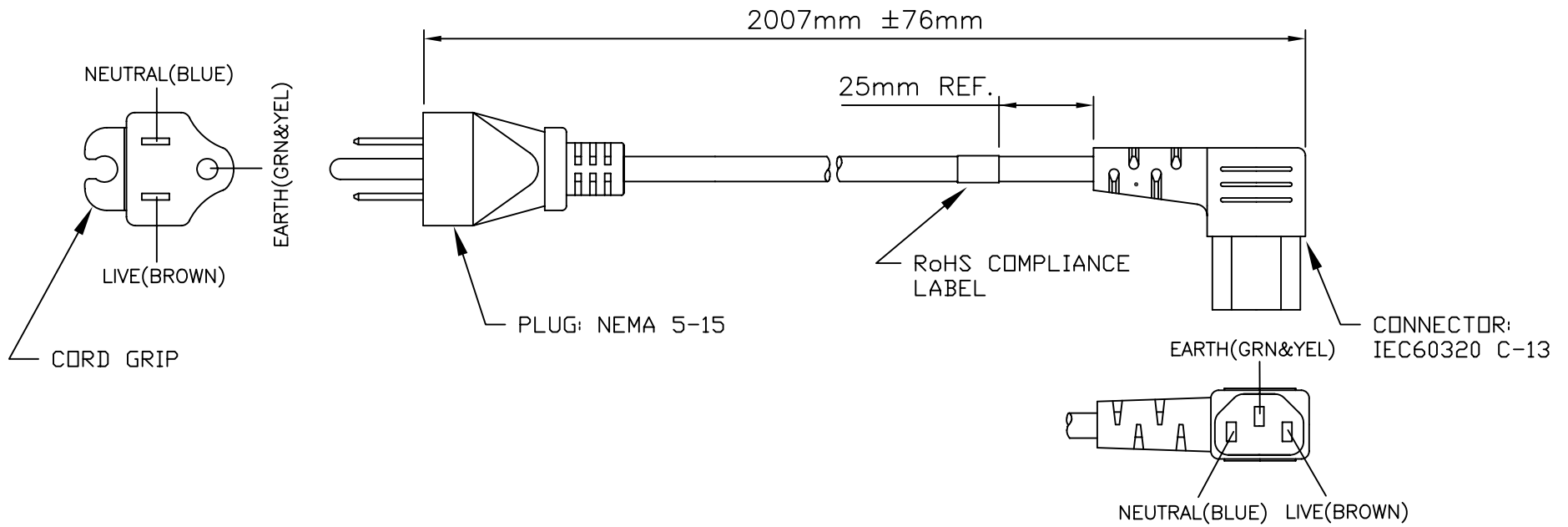
VOLEX

GROUP

Standard Cord Details: 17508 10 B1




Specifications	
Certifications	
Part Number	17508 10 B1
Connector Type	C13
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	PS204GR
Connector Catalog No.	V1625A
Cable	SJT AWG 16x3
Jacket Color	black
Length in Feet	6'7"
Length in Meters	2
Temperature Rating	60 C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
Nominal OD in Inches	0.34
Nominal OD in Millimeters	8.64



VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

- NOTES:**
- 1) CORDAGE: 16/3 SJT, 60°C, BLACK
 - 2) APPROVALS:
 - 3) RATING: 13 AMP/125 VOLTS
 - 4) PACKAGING: 100 PIECES PER CARTON
 - 5) ALL DIMENSIONS IN MILLIMETERS

PACKAGING: FOLD & TIE

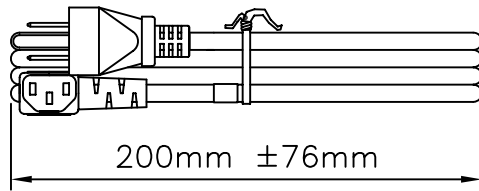

REV	DESCRIPTION	DATE
1	C.U.D - NEW RELEASE	9/11/07



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Fremont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLACK

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD:
N/A

ITEM DESCRIPTION
CORDSET - NORTH AMERICAN
DETACHABLE POWER SUPPLY CORD(6'7")

TOLERANCE UNLESS OTHERWISE SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°

APPROVED STC	DRAWN BY STC	DATE: 9/11/07
-----------------	-----------------	------------------

PART NO.
17508 10 B1