




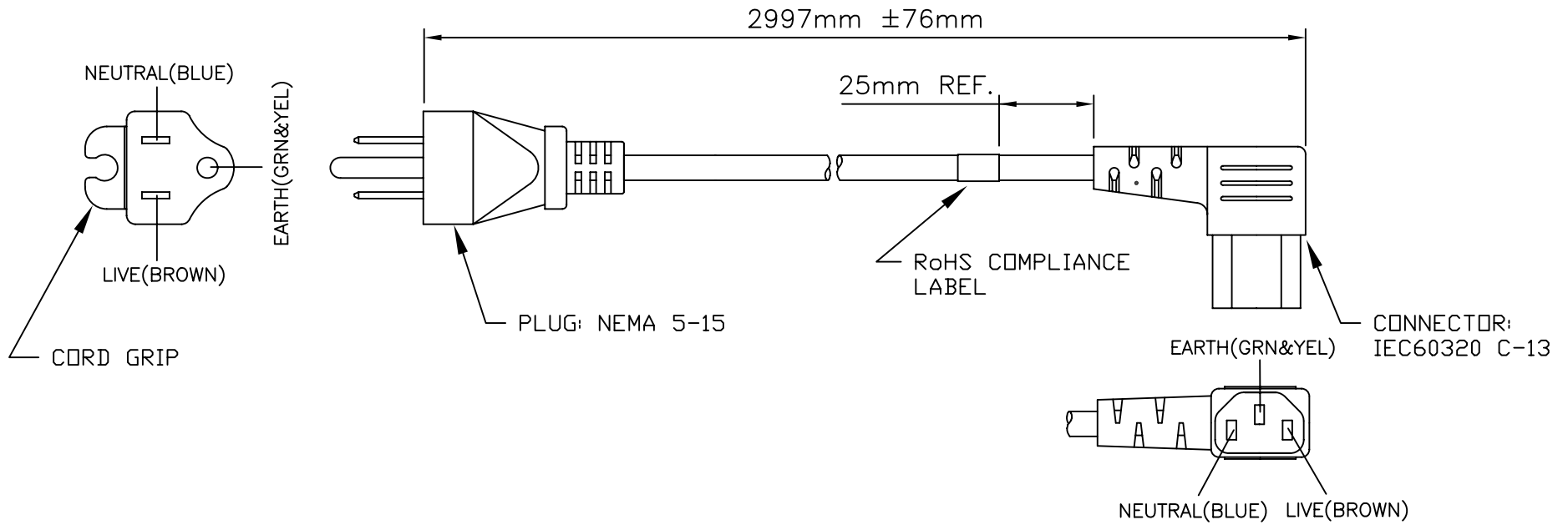
VOLEX

GROUP

## Standard Cord Details: 17509 10 B1




Specifications	
Certifications	
Part Number	17509 10 B1
Connector Type	C13
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	PS204GR
Connector Catalog No.	V1625A
Cable	SJT AWG 16x3
Jacket Color	black
Length in Feet	9'10"
Length in Meters	3
Temperature Rating	60 C
Packaging Units Per Carton	H-50,H-25
Color Coding	International
Nominal OD in Inches	0.34
Nominal OD in Millimeters	8.64



VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

- NOTES:**
- 1) CORDAGE: 16/3 SJT, 60°C, BLACK
  - 2) APPROVALS:
  - 3) RATING: 13 AMP/125 VOLTS
  - 4) PACKAGING: 50 PIECES PER CARTON
  - 5) ALL DIMENSIONS IN MILLIMETERS

PACKAGING: FOLD & TIE

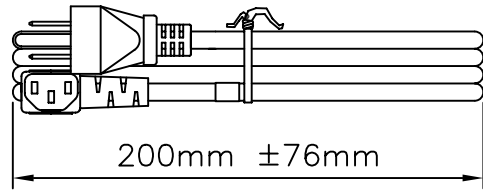

REV	DESCRIPTION	DATE
1	C.U.D - NEW RELEASE	9/11/07

- Indianapolis, IN
- Conover, N.C.
- Fremont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

**Proprietary Notice:**

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

**MATERIAL:**  
PLUG: PVC, BLACK  
JACKET: PVC, BLACK

**FINISH:**  
JACKET: SMOOTH

**SCALE:**  
NOT TO SCALE

**ECD:**  
N/A

**TOLERANCE UNLESS OTHERWISE SPECIFIED**  
.XXX ± .005  
.XX ± .02  
.X ± .03  
FRACT. ± 1/32  
ANGULAR ± 1/2°

**ITEM DESCRIPTION**  
CORDSET - NORTH AMERICAN  
DETACHABLE POWER SUPPLY CORD(9'10")

APPROVED STC	DRAWN BY STC	DATE: 9/11/07
PART NO. <b>17509 10 B1</b>		