




VOLEX

GROUP

Standard Cord Details: 17461 10 S2




Specifications	
Certifications	
Part Number	17461 10 S2
Connector Type	5-15R
Plug Type	5-15P
Category	Special
Application	Extension
Plug Catalog No.	PS204
Connector Catalog No.	US515RS
Cable	SJ AWG 16x3
Jacket Color	black
Length in Feet	10'
Length in Meters	3.05
Temperature Rating	60 C
Packaging Units Per Carton	S-15
Color Coding	North America
Nominal OD in Inches	0.34
Nominal OD in Millimeters	8.64
Notes	Restricted use only. Special Use Cord for equipment with built-in receptacle with blades and grounding pin for cord attachment.

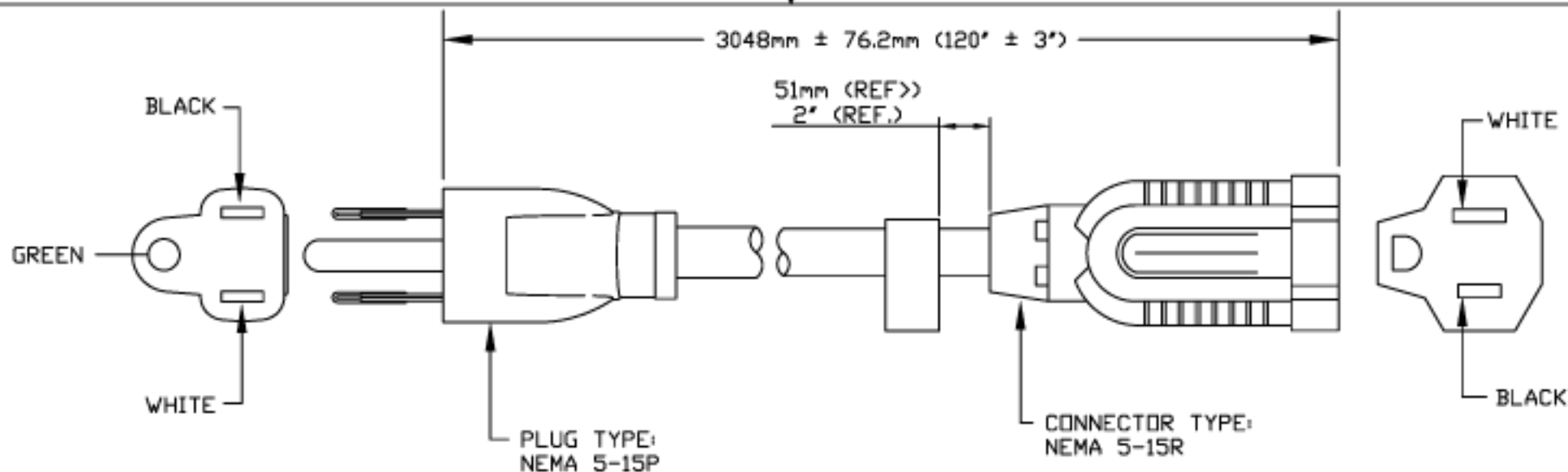

NOTE:

RESTRICTED USE DETACHABLE POWER SUPPLY CORD FOR BUSINESS, MAILING MACHINES AND ELECTRICAL EQUIP. THAT HAVE A BUILT IN RECEPTACLE WITH BLADES AND GROUNDING PIN FOR CORD ATTACHMENT.

PACKAGING: COIL & BAG

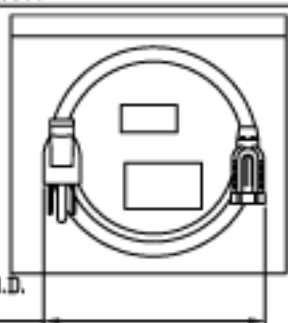


178mm ± 25.4mm O.D.
(7' ± 1' O.D.)

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

NOTES:

- 1) CORDAGE: 16/3/SJ/60°C/BLACK, LEAD FREE
- 2) APPROVALS:
- 3) RATING: 13 AMP/125 VOLTS
- 4) FLAME RATING: FT2
- 5) CORDAGE O.D.: .340 (REF.)
- 6) PACKAGING: 15 PIECES/CARTON
- 7) ALL DIMENSIONS IN MILLIMETERS UNLESS OTHERWISE NOTED.

REV	DESCRIPTION	DATE
3	CHANGE CONNECTOR STYLE	08/22/05
2	FORMAT UPDATE	08/20/04
1	C.U.D - NEW RELEASE	06/11/04



Indianapolis, IN
 Conover, N.C.
 Freemont, CA
 Aguascalientes, MX
 Tijuana, Mexico
 Hermosillo, MX
 Clinton, AR
 Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLACK, LEAD FREE

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD:
N/A

TOLERANCE UNLESS OTHERWISE SPECIFIED
 .XXX ± .005
 .XX ± .02
 .X ± .03
 FRACT. ± 1/32
 ANGULAR ± 1/2°

ITEM DESCRIPTION:
CORDSET - NORTH AMERICAN POWER SUPPLY CORD (10')

APPROVED: STC
DRAWN BY: ARK
DATE: 06/11/04

PART NO.: 17461 10 S2