




VOLEX

GROUP

Standard Cord Details: 17462 10 S2




Specifications	
Certifications	
Part Number	17462 10 S2
Connector Type	5-15R
Plug Type	5-15P
Category	Special
Application	Add A Line
Plug Catalog No.	
Connector Catalog No.	
Cable	SJT AWG 16x3
Jacket Color	black
Length in Feet	8'
Length in Meters	2.44
Temperature Rating	60 C
Packaging Units Per Carton	S-10
Color Coding	North America
Nominal OD in Inches	0.34
Nominal OD in Millimeters	8.64
Notes	Restricted use only. Add-a-line plug. See 17463 for 15ft version.

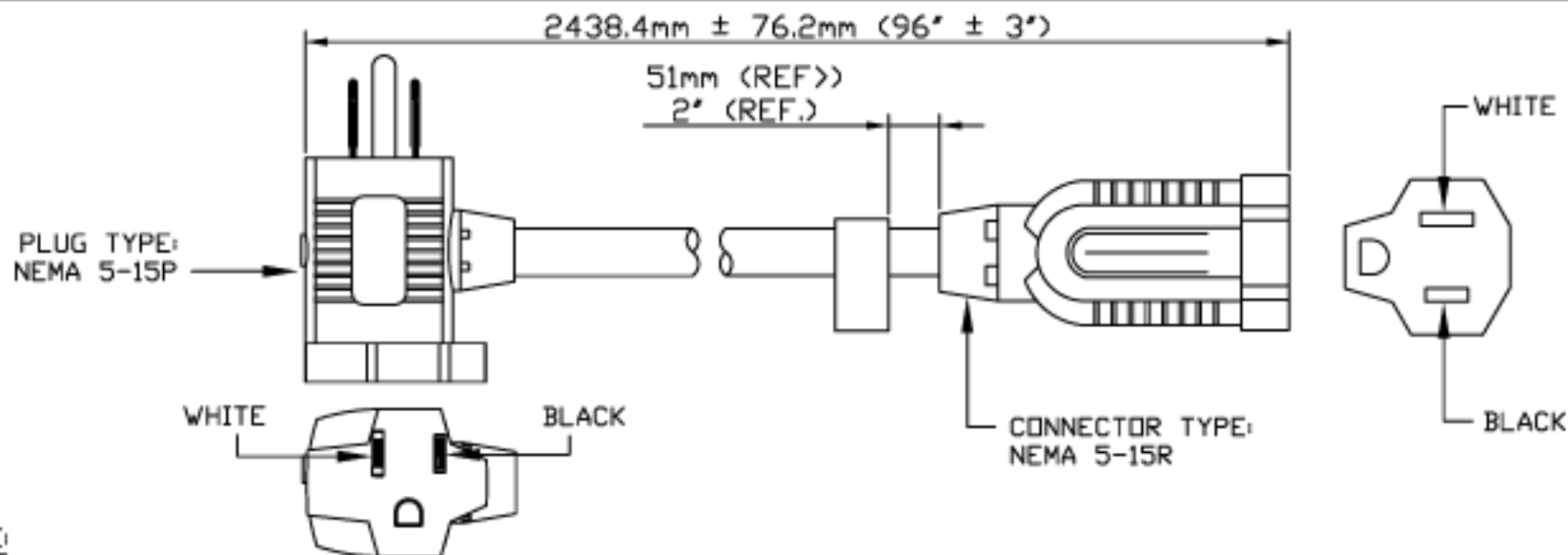

NOTE:

RESTRICTED USE DETACHABLE POWER SUPPLY CORD FOR BUSINESS, MAILING MACHINES AND ELECTRICAL EQUIP. THAT HAVE A BUILT IN RECEPTACLE WITH BLADES AND GROUNDING PIN FOR CORD ATTACHMENT.

PACKAGING: COIL & BAG

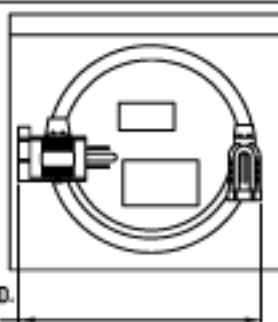

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

NOTES:

- 1) CORDAGE: 16/3/SJT/60°C/BLACK, LEAD FREE
- 2) APPROVALS:
- 3) RATING: 13 AMP/125 VOLTS
- 4) FLAME RATING : FT2
- 5) CORDAGE D.D. : .340 (REF.)
- 6) PACKAGING: 10 BAGS/CARTON
- 7) ALL DIMENSIONS IN MILLIMETERS UNLESS OTHERWISE NOTED.

REV	DESCRIPTION	DATE
3	CHG PLUG & CONNECTOR STYLE	08/22/05
2	FORMAT UPDATE	08/20/04
1	C.U.D - NEW RELEASE	06/11/04



- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:
This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLACK, LEAD FREE

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD:
N/A

TOLERANCE UNLESS OTHERWISE SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°

ITEM DESCRIPTION:
CORDSET - NORTH AMERICAN DETACHABLE POWER SUPPLY CORD (8')

APPROVED: STC
DRAWN BY: ARK
DATE: 06/11/04

PART NO.: 17462 10 S2