



VOLEX


GROUP

Standard Cord Details: 17625 10 B1




Specifications

Certifications	
Part Number	17625 10 B1
Connector Type	C13
Plug Type	C14
Category	Plastic
Application	Jumper
Plug Catalog No.	
Connector Catalog No.	386A
Cable	
Jacket Color	black
Length in Feet	3'3
Length in Meters	1
Temperature Rating	60 C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
Nominal OD in Inches	0.353
Nominal OD in Millimeters	8.97
Notes	(*)Rated at 13A-250V or 10A-250V. See 17624 for 18 gauge version. See 17525 for unshielded version.

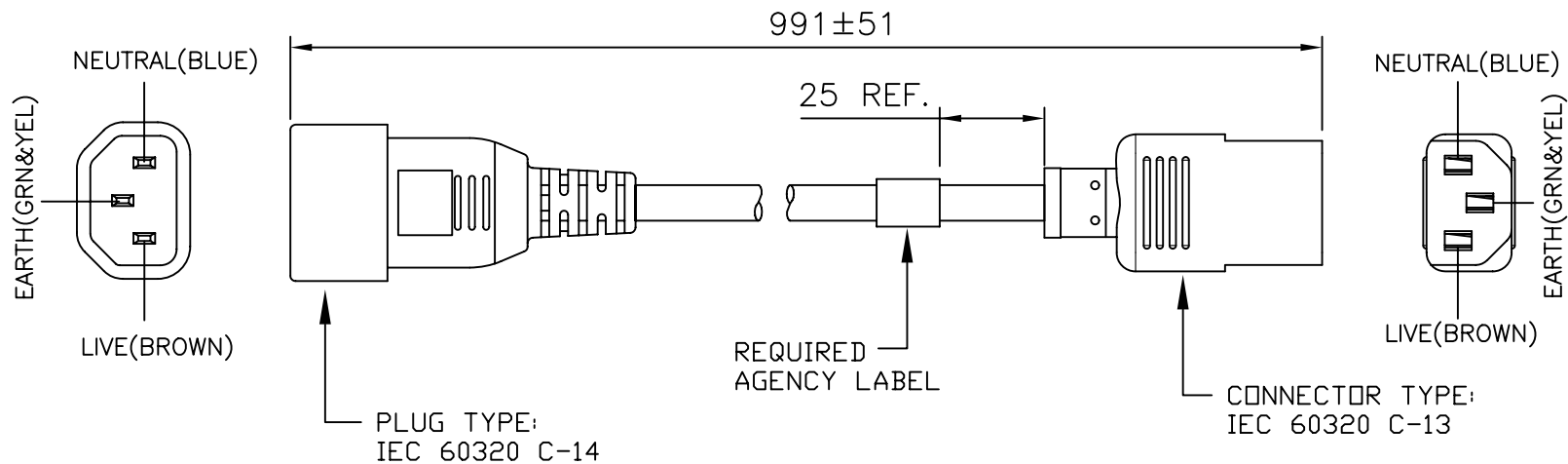



VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

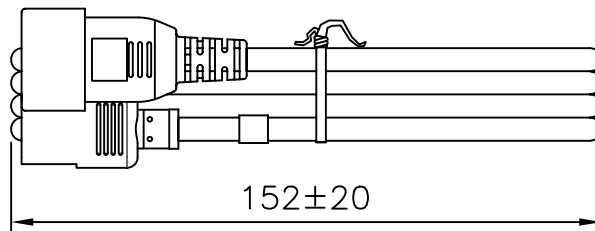PACKAGING: FOLD & TIE



NOTES:

- 1) CABLE: 16/3 SJT, FOIL SHIELDED WITH DRAIN WIRE, 60°C, BLACK
- 2) APPROVALS:  
- 3) RATING: 13 AMP/250 VOLTS
- 4) FLAME RATING : FT2
- 5) ALL DIMENSIONS IN MILLIMETERS.
- 6) DRAIN WIRE ATTACHED TO GROUND PIN ON PLUG END ONLY.
- 7) 100 CORDS PER CONTAINER.

REV	DESCRIPTION	DATE
2	REVISED TO SHOW CHINESE MANUFACTURED PRODUCT	11/28/07
1	C.U.D - NEW RELEASE	10/29/07



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG,CONNECTOR: PVC, BLACK
JACKET: PVC, BLACK
ROHS COMPLIANT

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD:
N/A

ITEM DESCRIPTION
CORDSET-NORTH AMERICAN
DETACHABLE POWER SUPPLY CORD

TOLERANCE
UNLESS OTHERWISE SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°

APPROVED	DRAWN BY	DATE:
STC	STC	10/29/07

PART NO.
17625 10 B1