



VOLEX



GROUP

Standard Cord Details: 17036 10 H100




Specifications	
Certifications	
Part Number	17036 10 H100
Connector Type	C5
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	PS204
Connector Catalog No.	VAC5S
Cable	SPT-2 AWG 18x3
Jacket Color	Black
Length in Feet	6
Length in Meters	1.8
Temperature Rating	60C
Packaging Units Per Carton	100
Color Coding	
Nominal OD in Inches	.142x.338
Nominal OD in Millimeters	
Notes	See 17035 for 3 foot version. See 17037 for 10ft version. See 17038A for C7 connector version.

NEUTRAL(RIBBED)
EARTH(GREEN)
LIVE(NORMAL)

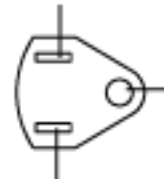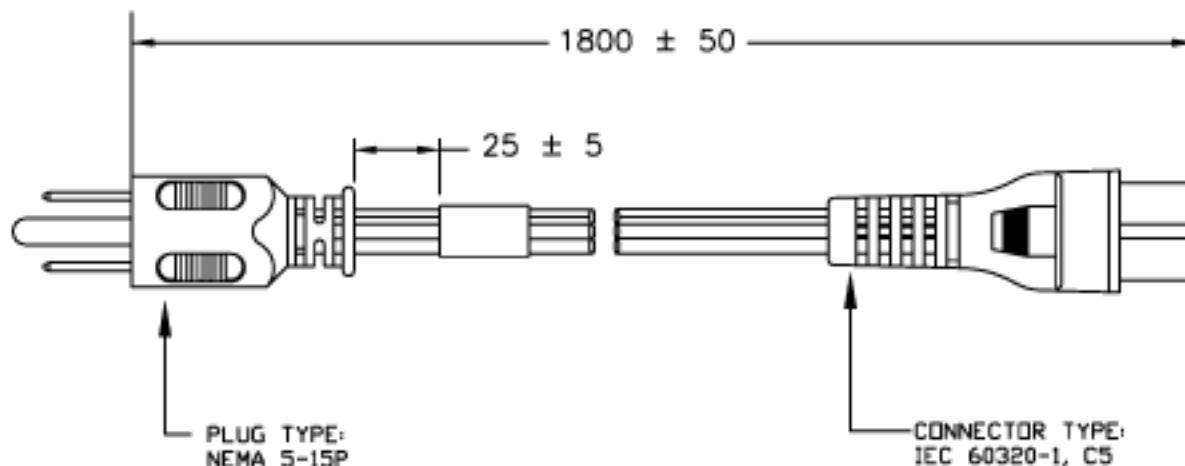



NEUTRAL(RIBBED)
EARTH(GREEN)
LIVE(NORMAL)

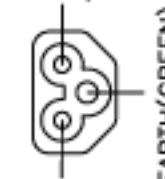



VOLEX RESERVES THE
RIGHT TO ALTER
NON-CRITICAL DIMENSIONS
WITHOUT NOTICE.

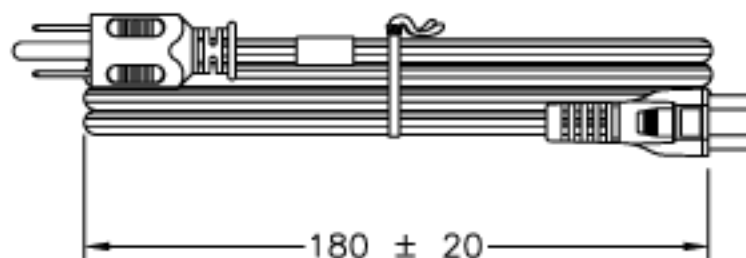PACKAGING: FOLD & TIE



NOTES:

- 1) CORDAGE: 18/3/SPT-2/60°C/BLACK, LEAD FREE
- 2) APPROVALS:  
- 3) RATING: 2.5 AMP/125 VOLTS
- 4) FLAME RATING : VW-1
- 5) CORDAGE D.D. : .145" x .330" (REF.)
- 6) PACKAGING: 100 PIECES/CARTON
- 7) ALL DIMENSIONS IN MILLIMETERS UNLESS OTHERWISE NOTED.

1	C.U.D - NEW RELEASE	09/19/05
REV	DESCRIPTION	DATE



- Indianapolis, IN
- Conover, N.C.
- Freemant, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanoto, Canada

Proprietary
Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLACK, LEAD FREE

FINISH:
JACKET: RIBBED

SCALE:
NOT TO
SCALE

ECD
N/A

ITEM DESCRIPTION
CORDSET - NORTH AMERICAN
DETACHABLE POWER SUPPLY CORD (6')

TOLERANCE
UNLESS OTHERWISE
SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°

APPROVED	DRAWN BY	DATE
	PAR	09/19/05

PART NO.
17036 10 H100