





VOLEX

GROUP

Standard Cord Details: 17271A 10 B1

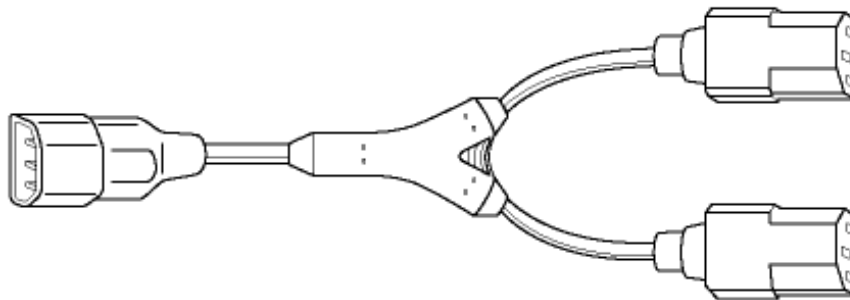


Specifications	
Certifications	
Part Number	17271A 10 B1
Connector Type	C13
Plug Type	C14
Category	Plastic
Application	Y Cord
Plug Catalog No.	
Connector Catalog No.	
Cable	SJT AWG 16x3
Jacket Color	black
Length in Feet	10' 2' legs
Length in Meters	
Temperature Rating	60 C
Packaging Units Per Carton	B-25
Color Coding	North America
Nominal OD in Inches	0.34
Nominal OD in Millimeters	8

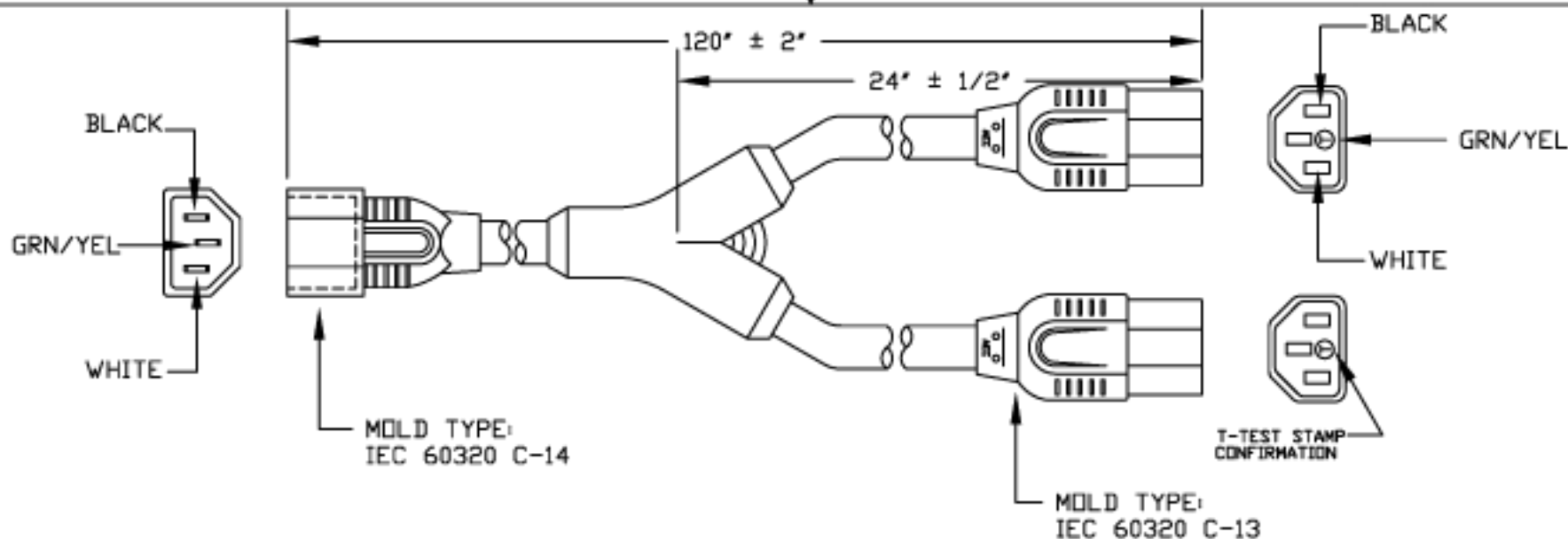

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: BULK

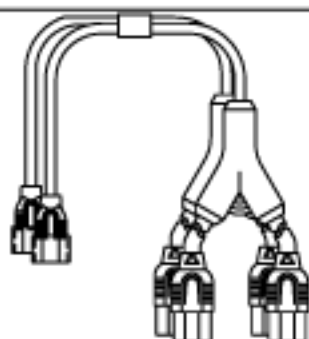

NOTES:

- 1) CORDAGE: 16/3/SJT/60°C/BLACK/LEAD FREE
- 2) APPROVALS:
- 3) RATING: 13 AMPS/125 VOLTS
- 4) FLAME RATING : FT2
- 5) CORDAGE D.D. : .340" (REF.)
- 6) PACKAGING: 50 PIECES/CARTON
- 7) ALL DIMENSIONS IN inches.

1	C.U.D - NEW RELEASE	06/03/05
REV	DESCRIPTION	DATE



- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLK, LEAD FREE

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD
N/A

ITEM DESCRIPTION
CORDSET - NORTH AMERICAN
DETACHABLE POWER SUPPLY CORD (10')

APPROVED
AVW

DRAWN BY
PAR

DATE:
06/03/05

PART NO.

17271A 10 B1

TOLERANCE
UNLESS OTHERWISE
SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°