





VOLEX

GROUP

Standard Cord Details: 17749 10 B1

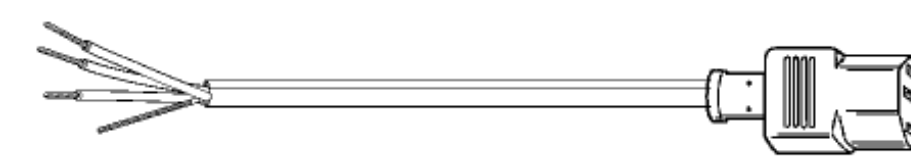

| Specifications | |
|-----------------------------------|-------------------------|
| Certifications | |
| Part Number | 17749 10 B1 |
| Connector Type | C13 |
| Plug Type | none |
| Category | Plastic |
| Application | Non-Detachable |
| Plug Catalog No. | |
| Connector Catalog No. | 386A |
| Cable | SVT AWG 18x3 (Shielded) |
| Jacket Color | black |
| Length in Feet | 6'7_ |
| Length in Meters | 2 |
| Temperature Rating | 60 C |
| Packaging Units Per Carton | H-100.H-25 |
| Color Coding | International |
| Nominal OD in Inches | 0.27 |
| Nominal OD in Millimeters | 6.86 |

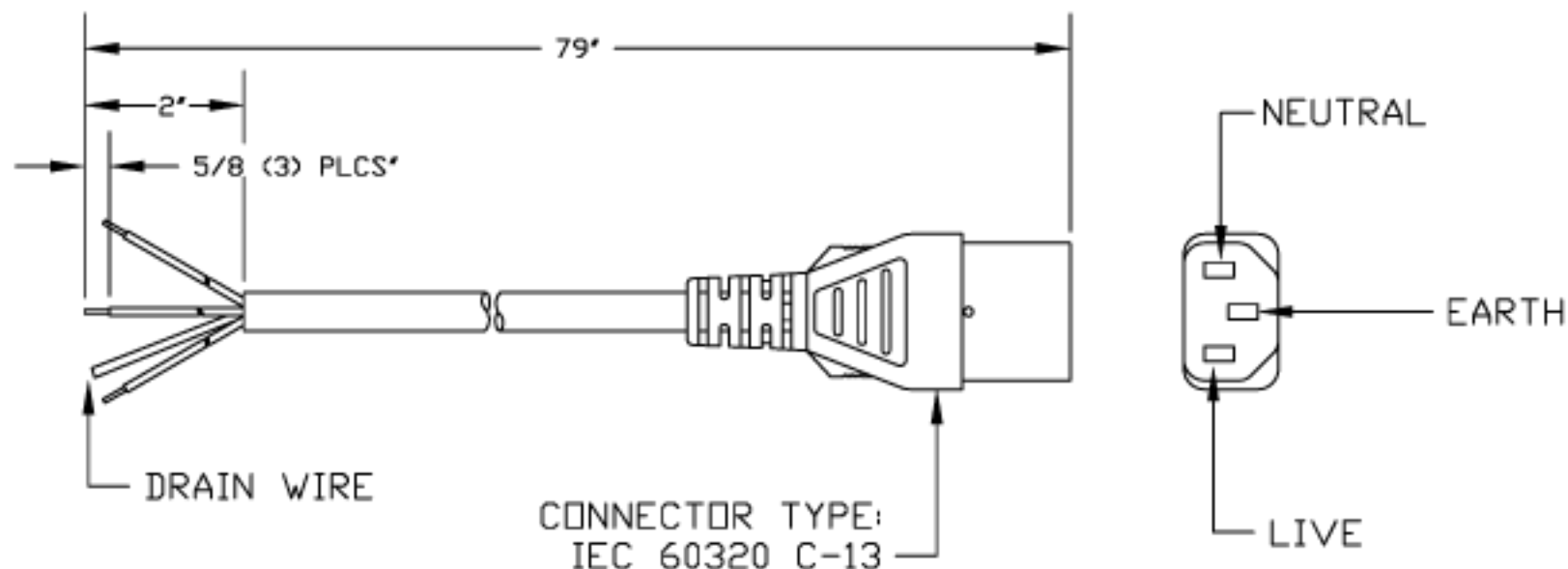

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE



NOTES:

- 1) CABLE: 18/3/SVTS (FOIL SHIELD)/60°C/BLACK
- 2) APPROVALS:
- 3) RATING: 10 AMP/250 VOLTS
- 4) FLAME RATING: FT2
- 5) ALL DIMENSIONS IN inches.
- 6) PACKAGING: 80 PIECES/CARTON.
- 7) DRAIN WIRE NOT CONNECTED ON CONNECTOR END.

| | | |
|-----|---------------------|----------|
| 1 | C.U.D - NEW RELEASE | 03/13/06 |
| REV | DESCRIPTION | DATE |



Indianapolis, IN
 Conover, N.C.
 Freemont, CA
 Aguascalientes, MX
 Tijuana, Mexico
 Hermosillo, MX
 Clinton, AR
 Kanata, Canada

Proprietary Notice:
 This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
 CONNECTOR: PVC, BLACK
 JACKET: PVC, BLACK
 LEAD FREE

FINISH:
 JACKET: SMOOTH

SCALE:
 NOT TO SCALE

ECD:
 N/A

TOLERANCE UNLESS OTHERWISE SPECIFIED
 .XXX ± .005
 .XX ± .02
 .X ± .03
 FRACT. ± 1/32
 ANGULAR ± 1/2°

ITEM DESCRIPTION:
 CORDSET-NORTH AMERICAN WIRING HARNESS (6'7")

| | | |
|---------------------------------|------------------------|--------------------------|
| APPROVED: MAF | DRAWN BY: CR | DATE: 03/13/06 |
| PART NO.: 17749 10 B1 | | |