


HBL7594 -- Twist-Lock Plug




2P3W, 15A 125V, ML-2P, Nylon Cover, Phenolic Body, Black

Product Specifications

Product Type	 <p>Twist-Lock Devices</p>
Product Item	Plug
Wiring Scheme	2 Pole, 3 Wire Grounding
Amperage	15A
Voltage	125V AC
NEMA Configuration	ML-2P
Item Style	Standard
Device Color	Black
Cord Dia.	.281"-.421" (7.1-10.7)
Blade Holder Material	Black Phenolic
Housing Material	Black Phenolic
Cord Clamp Material	Metallic
Blade Material	Brass
Terminal Clamp Material	Cold rolled steel-nickel-plated
Terminal Screw Material	#8-32 Brass

Ground Screw Material	Brass (green finish)
Cord Clamp Screw Material	Steel-zinc-plated
Body Holding Screw Material	Steel-zinc-plated
Ratings	Molded into face
Dielectric Voltage Withstand	2000V minimum
Current Interrupting	Certified for current interrupting at full rated current.
Temperature Rise	Max 30C temperature rise at full rated current after 50 cycles of overload at 150% of rated current at a power factor of .75.
Cord Accommodation	Round portable service cords of diameters commensurate with the device rating as defined in UL Standard 62, CSA C22.2 No. 49.
Terminal Accommodation	15A-#14AWG
Terminal Identification	Terminals identified in accordance with UL 498 (X, Y, Z, White, Green)
Flammability	HB or better per UL 94 or CSA 22.2 No. 0.6
Operating Temperatures	Maximum Continuous 75 C Minimum -40 C (w/o impact)
Moisture Resistance	IP20
Listings	UL/CSA
Catalog Page	Click here for catalog page B6
Brochures	Click here for product brochure
Hubbellnet	Click here for Hubbellnet
Catalog Section	Click here for Section-B
UPC Number	78358523777
Weight in LBs	0.1

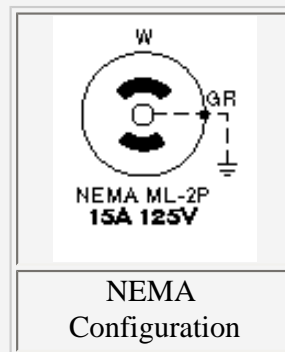


NEMA
Configuration

TWIST-LOCK® Devices


2 Pole, 3 Wire Grounding

15 Ampere, 125 Volts

Midget TWIST-LOCK® Devices

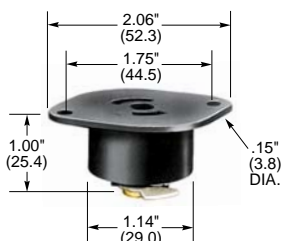

HBL7596N

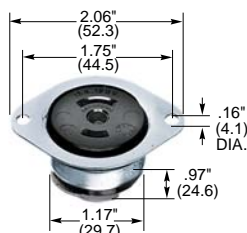


HBL7596



HBL7598




HBL7594V

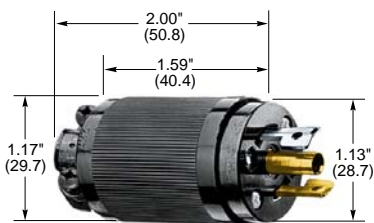

HBL7594



HBL7570

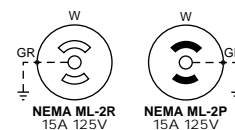

Flanged Receptacles

Description	Catalog Numbers	
Exposed terminals, black nylon flange.	HBL7596N	-
Exposed terminals, stainless steel flange.	HBL7596	-
Covered terminals, stainless steel flange, accepts cord .500" (12.7) in dia.	HBL7598	-

Male Plugs IP20 SUITABILITY

Description	Cord Dia.	Catalog Numbers	
Valise® male plug, black nylon, insulation displacement terminals.	.300"-.430" (7.6-10.9)	-	HBL7594V
Black nylon cover, phenolic body, multiple drive screw terminals.	.281"-.421" (7.1-10.7)	-	HBL7594
Angle plug, black nylon cover, phenolic body, multiple drive screw terminals.	.335"-.421" (8.5-10.7)	-	HBL7570

Weatherproof Accessory IP55** SUITABILITY

Description	Catalog Number
Seal-Tite® cover, black elastomer, for use with a HBL7594V plug when used with a HBL7593V connector body or a HBL7593V connector body when used with a flanged inlet.	HBL7495V** *

*Notes: These devices are not interchangeable with any other devices in this catalog. All male ground pins are sleeves and female device grounds are split pin. **IP55 Suitability when installed and used properly with plug and connector body combination. * Not UL Listed.*



HBL7495V