



Straight Blade Devices  
**15 and 20 Ampere, 250 Volts**  
 2 Pole, 3 Wire Grounding  
**Insulgrip® Plugs and Flanged Inlets**




**HBL5666C**

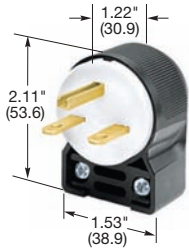

**HBL5666CA**

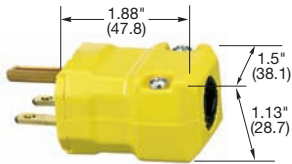

**HBL5666VY**

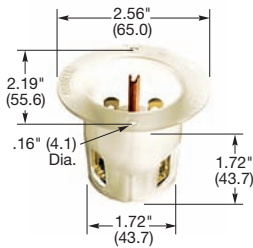

**HBL5678C**

**Plugs**

Description	Cord Diameter	Catalog Number	
Insulgrip® Plug, black and white nylon.	.230"-.720" (5.8-18.3)	<b>HBL5666C</b>	<b>HBL5466C</b>
Insulgrip® Plug, corrosion resistant, yellow nylon.	.230"-.720" (5.8-18.3)	<b>HBL56CM66C</b>	<b>HBL54CM66C</b>
8-Position Insulgrip® Angle Plug, black and white nylon.	.325"-.655" (8.3-16.6)	<b>HBL5666CA</b>	<b>HBL5466CA</b>
Valise® Plug, yellow nylon.	.220"-.660" (5.6-16.8)	<b>HBL5666VY</b>	<b>HBL5464VY</b>

Note: See page A-47 for accessories.



**15A 250V**  
 NEMA 6-15P  
 UL CSA  
 1.5 HP



**20A 250V**  
 NEMA 6-20P  
 UL CSA  
 2 HP

**Insulgrip® Flanged Inlets**

Description	Catalog Number	
Nylon casing, back wired.	<b>HBL5678C</b>	<b>HBL5478C</b>

Note: Flanged inlets are not HP rated.  
 See page A-47 for accessories.



**15A 250V**  
 NEMA 6-15P  
 UL CSA



**20A 250V**  
 NEMA 6-20P  
 UL CSA