

# Straight Blade Devices 15 and 20 Ampere, 125 Volts

2 Pole, 3 Wire Grounding

## HBL® Extra Heavy Duty Compact and Style Line® Decorator Receptacles



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL Listed  
1 HP

### Receptacles

#### HBL® Extra Heavy Duty Compact, Back and Side Wired, Duplex


Description	Color	Catalog Numbers	
Flush, nylon face, back and side wired.	Black	HBL5252BK	HBL5352BK
	Blue	-	HBL5352BL
	Brown	HBL5252	HBL5352
	Gray	HBL5252GY	HBL5352GY
	Ivory	HBL5252I	HBL5352I
	Red	HBL5252R	HBL5352R
	White	HBL5252W	HBL5352W
On a 4 in. (101.6) round cover.	Brown	HBL5253	-

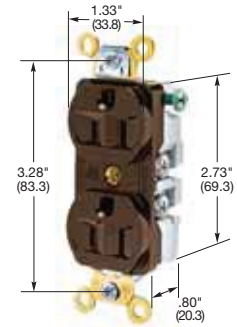

HBL5252

#### HBL® Extra Heavy Duty Compact, Side Wired Only, Duplex


Description	Color	Catalog Numbers	
Flush, nylon face, side wired only.	Brown	HBL5242	HBL5342
	Gray	HBL5242GY	HBL5342GY
	Ivory	HBL5242I	HBL5342I
	White	HBL5242W	HBL5342W
Ring terminal connection.	Brown	HBL5242RT	HBL5342RT

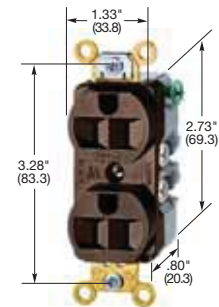

HBL5242

#### Heavy Duty, Single


Description	Color	Catalog Numbers	
Flush, side wired only.	Brown	HBL5251	-
	Ivory	HBL5251I	-
Panel mount 1.75 in. (44.5) centers.	Brown	HBL5258	HBL5358
	Ivory	HBL5258I	-

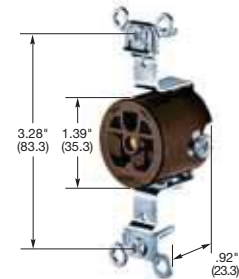


HBL5251

#### Heavy Duty Style Line® Decorator\*

Description	Color	Catalog Numbers	
Flush, nylon face, back and side wired.	Almond	HBL2152AL	HBL2162AL
	Black	HBL2152BK	HBL2162BK
	Brown	HBL2152	HBL2162
	Gray	HBL2152GY	HBL2162GY
	Ivory	HBL2152I	HBL2162I
	Office White	HBL2152OW	HBL2162OW
	White	HBL2152WA	HBL2162WA
Isolated ground. <sup>(1)</sup>	Gray	-	IG2162GY
	Orange	IG2152	IG2162

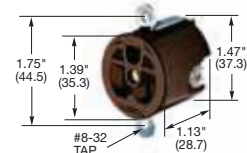

HBL5258

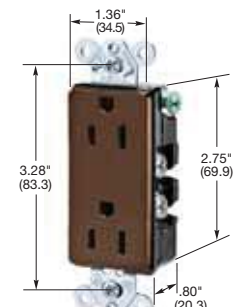

HBL2152

Notes: See page A-44 for accessories.

See Section K for wallplates.

(1) See Section J for complete line of isolated ground devices.

\*Style Line Duplex devices are not Fed. Spec. Listed.