


Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-315	S-8	BA15s	28V .900A	C-2V

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28.0	.810	.900	.990	24.0	32.0	40.0	300 Hrs

Dimensional Characteristics:

1. L.C.L. = 1.13" (28.7mm)
2. Base = Nickel-plated Brass Construction.

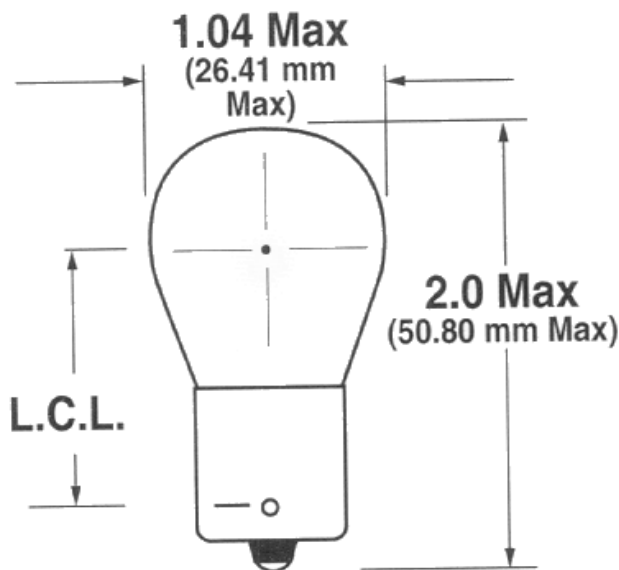

Title:

**S-8 Single Contact Bayonet Base Lamp
28V .900A Gas-Filled**

Drawn	4/20/02	CI	Notes: Unless otherwise specified, all dimensions are in inches.
Checked	4/20/02	EB	
Approved	4/20/02	EB	