


Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-456	G4-1/2	BA9s	28V .17A	C-2F

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28	.153	.170	.187	1.50	2.00	2.50	5,000 Hrs

Dimensional Characteristics:

1. L.C.L. = .56" (14.2mm)
 2. Base = Nickel-plated Brass Construction
- ANSI Standard No. 456

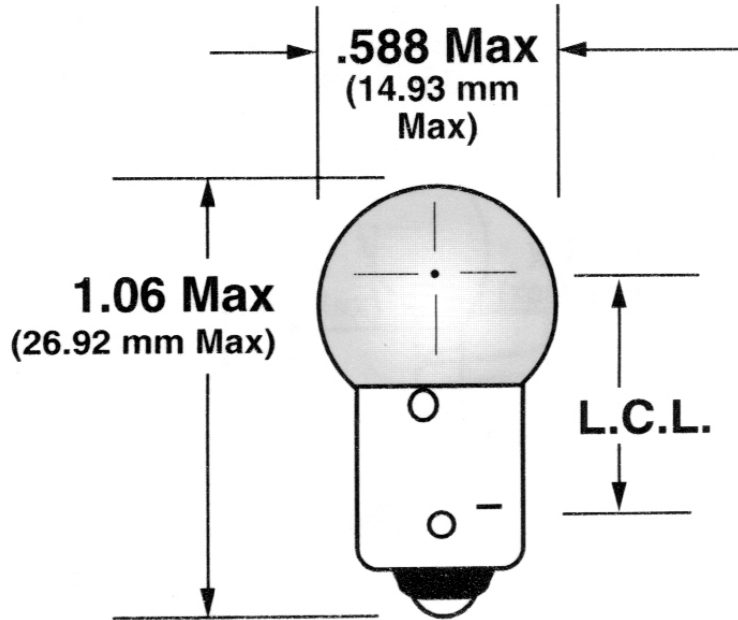

			Title: G4-1/2 Miniature Bayonet Base Lamp 28V .170A Vacuum
Revision			
Drawn	06/08/09	CI	Notes: Unless otherwise specified, all dimensions are in inches.
Checked	06/08/09	EB	
Approved	06/09/09	EB	
			Rev: 1