


Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-1665IF	S-8	BA15s	28V 0.800A	C-2V

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28.0V	.720	.800	.880	—	Not Rated	—	1,000 Hrs

Dimensional Characteristics:

1. L.C.L. = 1.13" (28.7mm)
2. Base = Nickel-plated Brass Construction
3. Frosted Envelope

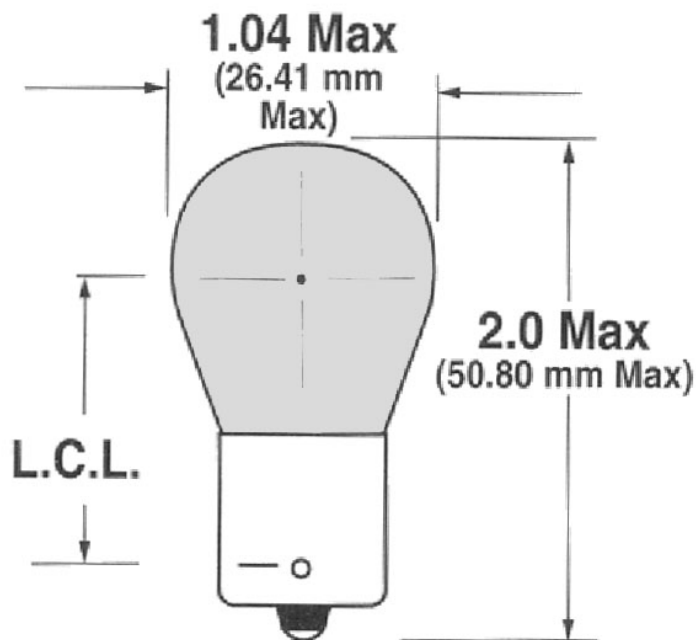

Title:

**S-8 Frosted Single Contact Bayonet Base Lamp
28V .800A Gas-Filled**

Drawn	06/29/09	CI	Notes: Unless otherwise specified, all dimensions are in inches.	Rev: 1
Checked	06/29/09	EB		
Approved	06/30/09	EB		