


T-1³/₄ MIDGET FLANGE BASE

SUBMINIATURE LAMP

28V 40mA

| WAMCO PART NO. | ENVELOPE SIZE | BASE TYPE | RATING | FILAMENT SHAPE | | | |
|----------------|---------------------------------|-----------|----------|----------------------------------|------|------|----------|
| WL-327R | T-1 ³ / ₄ | MF | 28V 40mA | C-2F | | | |
| TEST VOLTS | CURRENT (mA) | | | LIGHT OUTPUT (MSCP) ² | | | LIFE HRS |
| | MIN | NOM | MAX | MIN | NOM | MAX | |
| 28V | 36 | 40 | 44 | .255 | .340 | .425 | 4,000 |

DIMENSIONAL CHARACTERISTICS

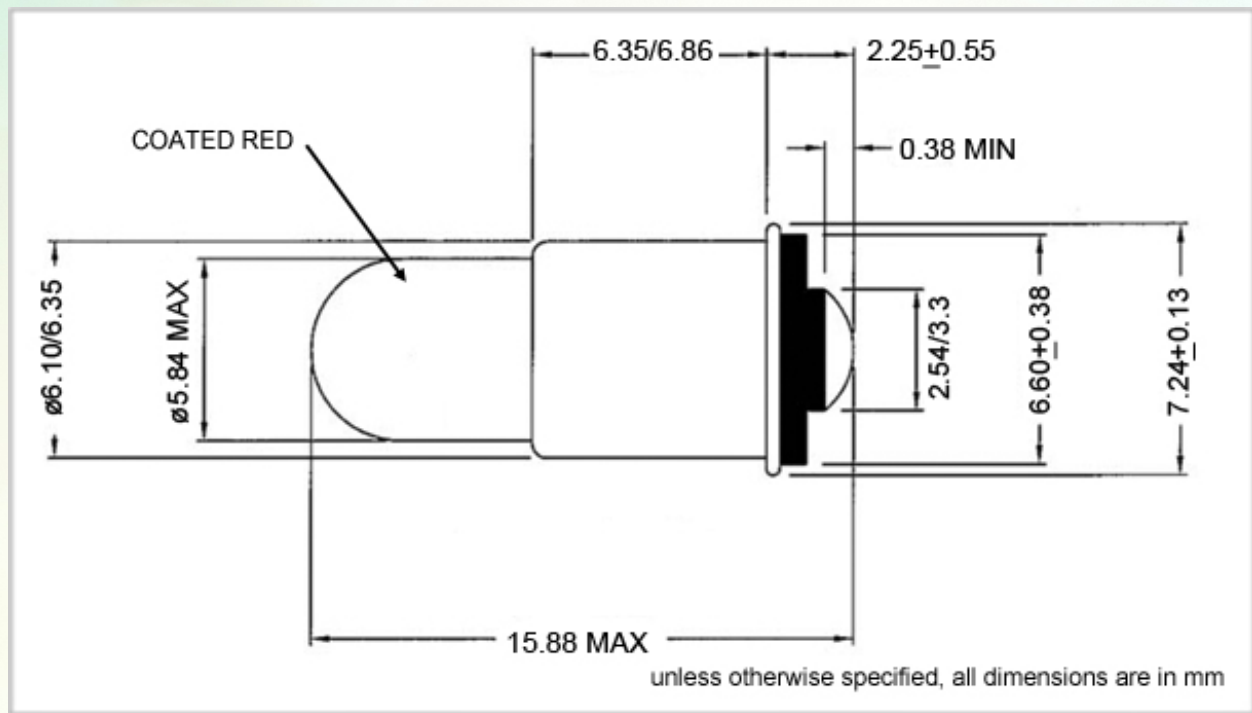

NOTES

1. Coated red
2. MSCP rating for clear lamp prior to coating
3. Part mark WL-327R
4. RoHS compliant
5. ANSI trade number 327 R

