



## Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Average Life Hours
WL-5104WW	T5	BP	4W	7,500 Hrs

### Electrical Data

Rated Wattage (W)	Operating Volts (rms) (V)			Current (A)	Constant Coil Heat Current (A)
	Min	Nom	Max		
4.5	24V	29V	34V	.170	.250


### Operating Conditions

Description	Temperature (°C)			Operating Position
	Min	Nom	Max	
Lamp Ambient Temperature	-15	25	50	Unrestricted
Cap Temperature	—	—	80	

### Photometric Data

Color	Luminous Flux Nom (lm)	CRI	Color Temp (K)
Warm White (WW)	145	85	3,100

**Dimensional Characteristics:** Glass diameter 16 mm max.

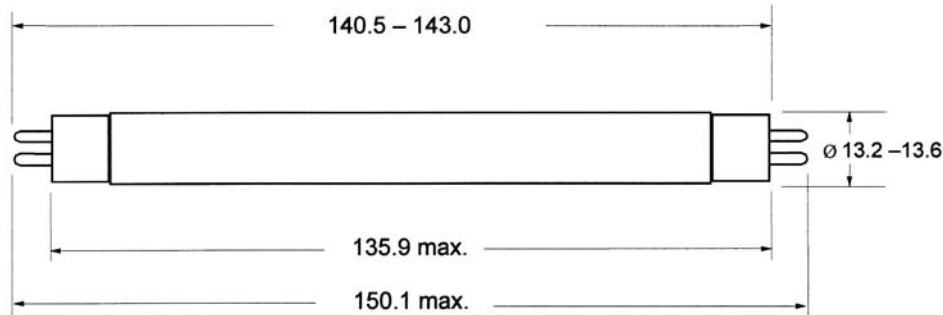

ANSI Standard No. 5104W

**Title:**

**Fluorescent Lamp  
4W T5 Bi-Pin Tri-phosphor**

The product must be used with suitable operating equipment and in accordance with the specified data.

<b>Drawn</b>	12/04/09	SL	<b>Notes:</b> Unless otherwise specified, all dimensions are in mm.	<b>Rev:</b> 2
<b>Checked</b>	12/07/09	EB		
<b>Approved</b>	12/07/09	EB		