

PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY

MOUNTING HOLE, Ø 0.310"

PART NO.	LENS COLOR	VOLTAGE	CURRENT [mA]	RATED LIFE HOURS
LED 6V SERIES				
WL-2191U1-6V	RED	5V-6V	20mA	100,000
WL-2191U5-6V	GREEN	5V-6V	20mA	100,000
WL-2191U7-6V	YELLOW	5V-6V	20mA	100,000
LED 12V SERIES				
WL-2191U1-12V	RED	12V-14V	20mA	100,000
WL-2191U5-12V	GREEN	12V-14V	20mA	100,000
WL-2191U7-12V	YELLOW	12V-14V	20mA	100,000
LED 24V SERIES				
WL-2191U1-24V	RED	24V-28V	20mA	100,000
WL-2191U5-24V	GREEN	24V-28V	20mA	100,000
WL-2191U7-24V	YELLOW	24V-28V	20mA	100,000

NOTES


1. Minimum panel thickness 0.030"
2. 6" leads with 1/2" strip are standard
3. Storage temperature
T_{STG}: -25°C - +80°C
4. Ambient temperature
T_A: -20°C - +60°C
5. Voltage tolerance
V_{OP}: ±10%
6. Body material
Nylon, white
7. Lens material
Polycarbonate
8. Bezel material
Chrome
9. Wire gauge
18 AWG
10. Wire strip
1/2"
11. Anode(+)
Red lead

CERTIFICATIONS

UL (E340667), RoHS



DIMENSIONAL CHARACTERISTICS

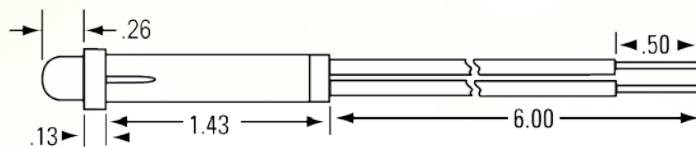

unless otherwise specified, all dimensions are in inches



OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

