
 


1.0 Meter or Custom

3: 1 Fiber OM1, OM2, OM3 or OM4 selectable.  
Simplex zip cable OD1.8mm, 2.0mm, and 3.0mm selectable.  
Any color of cable available. OFNP, OFNR and LSZH available.

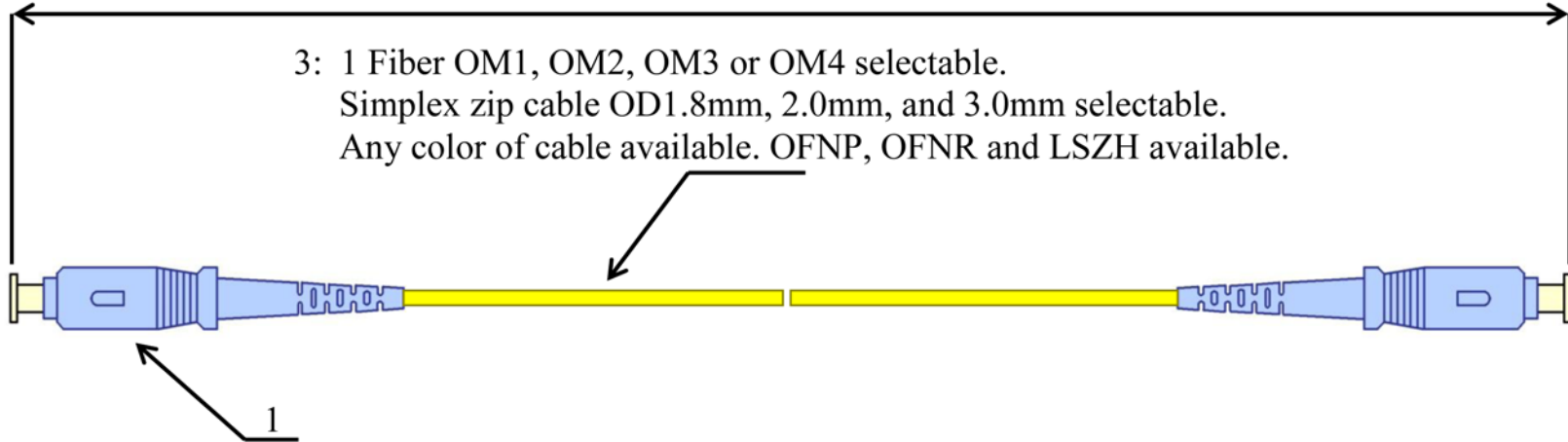

2: Every connector can be changed to FC, ST or LC.



FC Connector



ST Connector



LC Connector

Item # NFO-STST-S9SX-3M

NUMBER	DESCRIPTION	MATERIAL	Specification	SPECIFICATION		LENGTH	TOLERANCE	TITLE	SingleMode Simplex SC, FC, ST, LC
1	Connector	SC	Ecru – SM	Type	SC - SM	≤ 5 m	+4 cm/-3 cm	<b>DRAWING #</b>	0907080205.4
2	Connector	FC, ST and LC	Ecru – SM	Insertion Loss	≤ 0.2 dB	> 5 m	+5 cm/-5 cm	<b>DRAWN BY</b>	Rowell Comilang
3	Optical Cable	OFNP, OFNR or LSZH	9/125 um	Return Loss	≥ 50 dB	-	-	<b>CHECKED BY</b>	Engr. Lemuel Aguilar
-	-	-	-	Test Wavelength	1050 nm	-	-	<b>DATE</b>	12.22.2010