


QUEST CABLING SOLUTIONS CAT6 UTP PATCH CORD ISO/IEC 11801 & EN50288 & ANSI/TIA-568C.2
ETL/3P VERIFIED - 24AWGX4P PATCH TYPE CMR (UL) E466009 ROHS


- W/OR 1 OR 2
- W/GR 3 GR 6
- BL 4 W/BL 5
- W/BR 7 BR 8
- W/OR 1 OR 2
- W/GR 3 GR 6
- BL 4 W/BL 5
- W/BR 7 BR 8

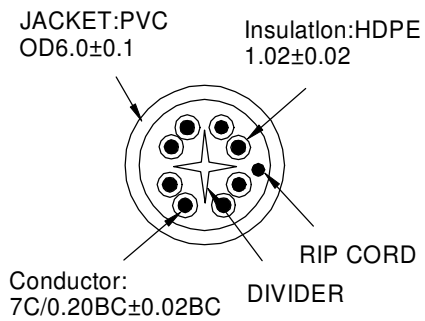

NPC-6XXX
LENGTH
COLOR

COLOR(X)	
BLACK	1
BLUE	2
RED	3
ORANGE	4
YELLOW	5
GREEN	6
WHITE	8
GREY	9

Length: 1', 3', 5', 7' 10', 15', 25', 50', 100'

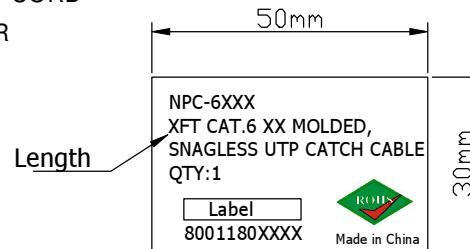

9			
8			
7			
6			
5			
4			
3	60P PVC MOLDED	12	g
2	8P8C MALE, GOLD PLATED PINS	2	pcs
1	CABLE:(7C/0.20BC±0.02BC+HDPE1.02)*4P+RIP OD:6.0±0.1MM	1	pcs
NO	Description	Q,TY	Unit

QUEST Technology Int'l, Inc. 11200 NW 538th St., Medley, FL 33178 Tel: 954-913-8800 Fax: 954-913-9876 www.QUESTtechnologyintl.com				DESCRIPTION	CAT6 UTP PATCH CORD	SCALE	FIT	UNITS:MM	3RD ANGLE
APPROVED	CHECKED	DRAWING	DESIGNED	DRAWING NO	URT6-M4F-XX-XX	△			
Wxp	Wxp	David Feng	David Feng	FINISHING		△	2014.05.09		A1
				MATERIAL		SYM	DATE		REVISION