

Smart-UPS

APC Smart-UPS SC 420VA 230V

SC420I



APC Smart-UPS, 260 Watts / 420 VA, Input 230V / Output 230V, Interface Port DB-9 RS-232



Includes: CD with software, Smart UPS signalling RS-232 cable, User Manual

Standard Lead Time: Usually in Stock





Output


Output Power Capacity	260 Watts / 420 VA
Max Configurable Power	260 Watts / 420 VA
Nominal Output Voltage	230V
Output Voltage Distortion	Less than 5% at full load
Output Frequency (sync to mains)	47 - 53 Hz for 50 Hz nominal, 57 - 63 Hz for 60 Hz nominal
Output Connections	(1) IEC 320 C13  (3) IEC 320 C13  (2) IEC Jumpers

Input

Nominal Input Voltage	230V
Input Frequency	50/60 Hz +/- 3 Hz (auto sensing)
Input Connections	IEC-320 C14
Input voltage range for main operations	160 - 286V
Input voltage adjustable range for mains operation	151 - 302V

Batteries & Runtime

Battery Type	Maintenance-free sealed Lead-Acid battery with suspended electrolyte : leakproof
Typical recharge time	3 hour(s)
Replacement Battery	RBC2 , RBC2J
RBC™ Quantity	1
Runtime Graph	

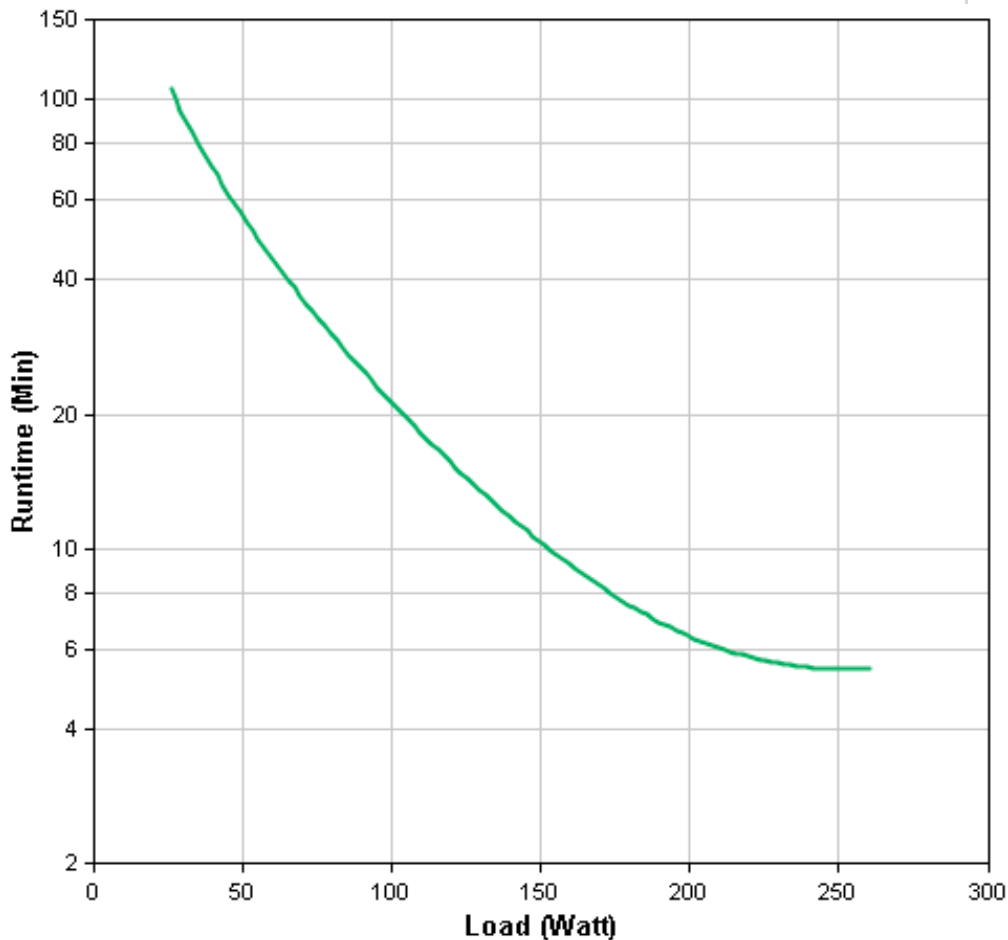

Hover over the line on the graph above to view the runtime at any desired load

Curve fit to measured runtime data. All measurements taken with new, fully charged batteries, at typical environmental conditions, with no electrical input and balanced resistive load (PF = 1.0) output.

[View Enlarged Graph](#)

[View Runtime Chart](#)

Communications & Management

Interface Port(s)	DB-9 RS-232
Control panel	LED status display with On Line : On Battery : Replace Battery and Overload indicators
Audible Alarm	Alarm when on battery : distinctive low battery alarm : overload continuous tone alarm

Emergency Power Off (EPO) N/A

Surge Protection and Filtering

Surge energy rating	320 Joules
Filtering	Full time multi-pole noise filtering : 0.7% IEEE surge let-through : zero clamping response time : meets UL 1449
Data Line Protection	RJ-45 Modem/Fax/DSL/10-100 Base-T protection

Physical

Maximum Height	168.00 mm
Maximum Width	119.00 mm
Maximum Depth	368.00 mm
Net Weight	9.09 KG
Shipping Weight	10.23 KG
Shipping Height	318.00 mm
Shipping Width	262.00 mm
Shipping Depth	508.00 mm
Color	Grey
Units per Pallet	40.00

Environmental

Operating Environment	0 - 40 °C
Operating Relative Humidity	0 - 95%
Operating Elevation	0-3000 meters
Storage Temperature	-15 - 45 °C
Storage Relative Humidity	0 - 95%
Storage Elevation	0-15000 meters
Audible noise at 1 meter from surface of unit	45.00 dBA
Online Thermal Dissipation	50.00 BTU/hr

Conformance

Regulatory Approvals	CE,GOST,VCCI,VDE
Standard Warranty	2 years repair or replace
Environmental Compliance	RoHS 7b Exemption,China RoHS,REACH: Contains No SVHCs

**The time to recharge to 90% of full battery capacity following a discharge to shutdown using a load rated for 1/2 the full load rating of the UPS.