

You are here: [Home](#) > [Products](#) > [Uninterruptible Power Supply \(UPS\)](#) > [Replacement Battery Cartridges](#)




APC Replacement Battery Cartridge #110
Part Number: APCRBC110



[Technical Specifications](#) [Product Overview](#) [Documentation](#) [Ratings and Reviews](#)

Batteries & Runtime

Battery Type	Maintenance-free sealed Lead-Acid battery with suspended electrolyte : leakproof
RBC™ Quantity	1
Runtime Graph	

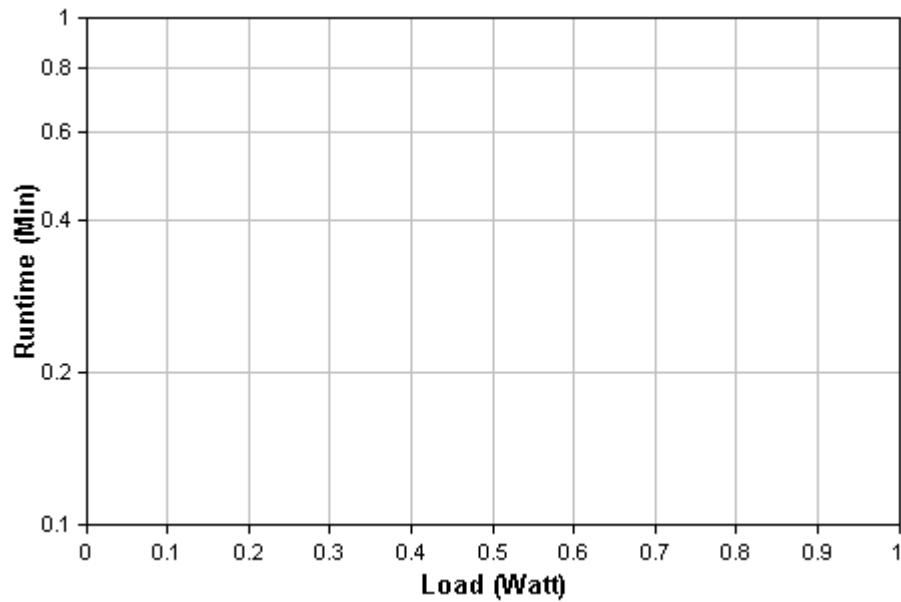

Hover over the line on the graph above to view the runtime at any desired load

[View Enlarged Graph](#)

[View Runtime Chart](#)

Physical

Maximum Height	105.00 mm
Maximum Width	151.00 mm
Maximum Depth	65.00 mm

Net Weight	2.50 KG
Shipping Weight	2.95 KG
Shipping Height	89.00 mm
Shipping Width	175.00 mm
Shipping Depth	213.00 mm
Color	Black
Units per Pallet	240.00

Environmental

Operating Environment	0 - 40 °C
Operating Relative Humidity	0 - 95%
Operating Elevation	0-3000 meters
Storage Temperature	-15 - 45 °C
Storage Relative Humidity	0 - 95%
Storage Elevation	0-15000 meters

Conformance

Standard Warranty	1 year repair or replace
-------------------	--------------------------

Sustainable Offer Status

RoHS	Compliant
REACH	REACH: Contains No SVHCs