

## Premium Molded D-sub Cable, DB9 Male / Female, 2.5 ft

### Features for this product

- Foil plus braid shield provides maximum protection against EMI/RFI
- All lines wired straight through for extending serial devices
- Hex nuts on female connectors are removable to expose 4-40 thumbscrews
- Gold plated contacts provide reliable connections with repeated mating cycles
- DB9 male to female connectors, lengths range from 2.5 ft. to 50 ft.



L-com's top of the line offering of D-sub cable assemblies provide maximum protection against data corrupting EMI/RFI. Double shielded cable (copper braid plus aluminum mylar foil) and a custom steel internal enclosure separate these cables from any off the shelf D-sub cable on the market. Ideal for any electrically noisy environment where fans, motors or switches are nearby. Custom lengths and pinouts are available with modest minimum requirements.

### Details for this D-Subminiature product


|              |   |
|--------------|---|
| L-com Item # | CS2N9MF-2.5   |
| Manufacturer | L-com   |
| UPC #        | 822335012714  |
| RoHS Status  | <a href="#">Partially RoHS Compliant Stock</a>  |



| Item # | Description | 1-9 | 10-24 | 25-99 | 100-249 | 250-499 |
|--------|-------------|-----|-------|-------|---------|---------|
|--------|-------------|-----|-------|-------|---------|---------|

**Premium D-Sub Cable Assemblies - Fully Populated and Double Shielded**

The CS2N Series of D-Sub cable assemblies is our top of the line D-Sub cabling offering. These cables offer the best features for those applications where only the best will do. The bulk cable utilizes 26AWG stranded conductors with double shielding (copper braid plus aluminum mylar foil) and flexible PVC jacket. Fully molded backshells also have a unique stamped steel internal enclosure that provides the ultimate in shielding performance. Mounting is done via rugged 4-40 thumbscrews that are easy to grip without the need for a screwdriver. Hex nuts on female connectors are removable to expose 4-40 thumbscrews. Color: Light Gray.

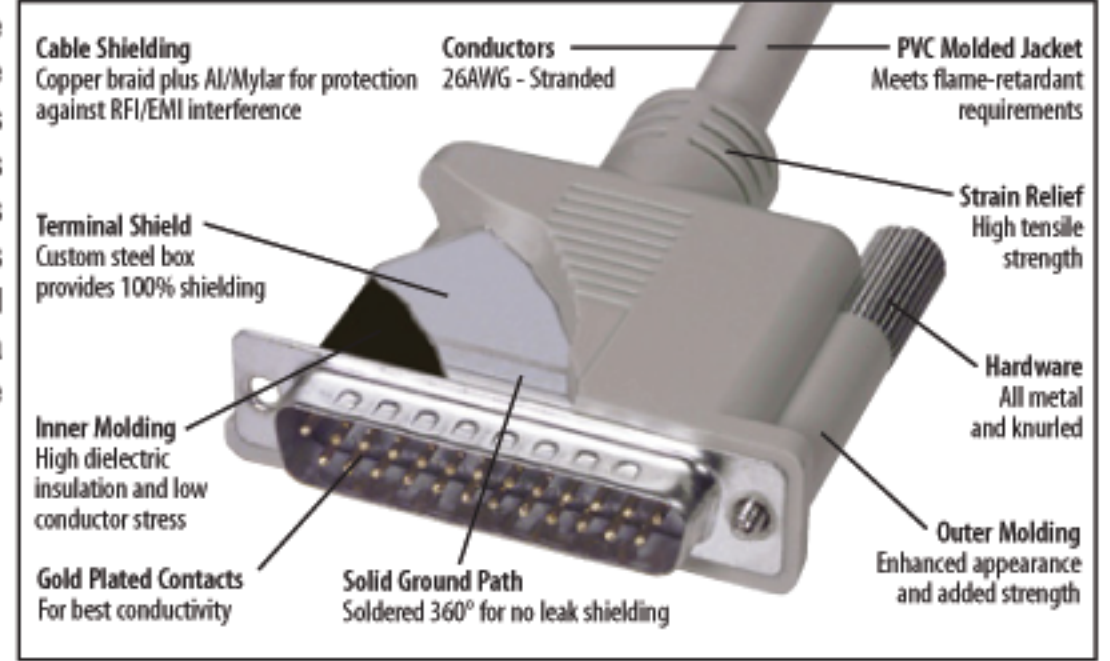

**✓ Premium 9 Pin D-Sub Cables - Molded, Fully Populated and Double Shielded**

|                             |  |       |       |       |       |       |
|-----------------------------|--|-------|-------|-------|-------|-------|
| <a href="#">CS2N9MM-2.5</a> | Premium Molded Cable, DB9 Male / Male, 2.5 ft    | 16.25 | 15.97 | 14.99 | 13.99 | 12.95 |
| <a href="#">CS2N9MM-5</a>   | Premium Molded Cable, DB9 Male / Male, 5.0 ft    |       |       |       |       |       |
| <a href="#">CS2N9MM-6</a>   | Premium Molded Cable, DB9 Male / Male, 6.0 ft    |       |       |       |       |       |
| <a href="#">CS2N9MM-10</a>  | Premium Molded Cable, DB9 Male / Male, 10.0 ft   |       |       |       |       |       |
| <a href="#">CS2N9MM-12</a>  | Premium Molded Cable, DB9 Male / Male, 12.0 ft   |       |       |       |       |       |
| <a href="#">CS2N9MM-15</a>  | Premium Molded Cable, DB9 Male / Male, 15.0 ft   |       |       |       |       |       |
| <a href="#">CS2N9MM-25</a>  | Premium Molded Cable, DB9 Male / Male, 25.0 ft   |       |       |       |       |       |
| <a href="#">CS2N9MM-50</a>  | Premium Molded Cable, DB9 Male / Male, 50.0 ft   |       |       |       |       |       |
| <a href="#">CS2N9MF-2.5</a> | Premium Molded Cable, DB9 Male / Female, 2.5 ft  |       |       |       |       |       |
| <a href="#">CS2N9MF-5</a>   | Premium Molded Cable, DB9 Male / Female, 5.0 ft  |       |       |       |       |       |
| <a href="#">CS2N9MF-6</a>   | Premium Molded Cable, DB9 Male / Female, 6.0 ft  |       |       |       |       |       |
| <a href="#">CS2N9MF-10</a>  | Premium Molded Cable, DB9 Male / Female, 10.0 ft |       |       |       |       |       |
| <a href="#">CS2N9MF-12</a>  | Premium Molded Cable, DB9 Male / Female, 12.0 ft |       |       |       |       |       |
| <a href="#">CS2N9MF-15</a>  | Premium Molded Cable, DB9 Male / Female, 15.0 ft |       |       |       |       |       |
| <a href="#">CS2N9MF-25</a>  | Premium Molded Cable, DB9 Male / Female, 25.0 ft |       |       |       |       |       |
| <a href="#">CS2N9MF-50</a>  | Premium Molded Cable, DB9 Male / Female, 50.0 ft |       |       |       |       |       |

**✓ Premium High Density 15 Pin D-Sub Cables - Molded, Fully Populated and Double Shielded**

|                              |   |       |       |       |       |       |
|------------------------------|---|-------|-------|-------|-------|-------|
| <a href="#">CS2H15MM-2.5</a> | Premium Molded Cable, HD15 Male / Male, 2.5 ft    | 26.99 | 26.99 | 26.99 | 26.99 | 26.99 |
| <a href="#">CS2H15MM-5</a>   | Premium Molded Cable, HD15 Male / Male, 5.0 ft    |       |       |       |       |       |
| <a href="#">CS2H15MM-6</a>   | Premium Molded Cable, HD15 Male / Male, 6.0 ft    |       |       |       |       |       |
| <a href="#">CS2H15MM-10</a>  | Premium Molded Cable, HD15 Male / Male, 10.0 ft   |       |       |       |       |       |
| <a href="#">CS2H15MM-12</a>  | Premium Molded Cable, HD15 Male / Male, 12.0 ft   |       |       |       |       |       |
| <a href="#">CS2H15MM-15</a>  | Premium Molded Cable, HD15 Male / Male, 15.0 ft   |       |       |       |       |       |
| <a href="#">CS2H15MM-25</a>  | Premium Molded Cable, HD15 Male / Male, 25.0 ft   |       |       |       |       |       |
| <a href="#">CS2H15MM-50</a>  | Premium Molded Cable, HD15 Male / Male, 50.0 ft   |       |       |       |       |       |
| <a href="#">CS2H15MF-2.5</a> | Premium Molded Cable, HD15 Male / Female, 2.5 ft  |       |       |       |       |       |
| <a href="#">CS2H15MF-5</a>   | Premium Molded Cable, HD15 Male / Female, 5.0 ft  |       |       |       |       |       |
| <a href="#">CS2H15MF-6</a>   | Premium Molded Cable, HD15 Male / Female, 6.0 ft  |       |       |       |       |       |
| <a href="#">CS2H15MF-10</a>  | Premium Molded Cable, HD15 Male / Female, 10.0 ft |       |       |       |       |       |
| <a href="#">CS2H15MF-12</a>  | Premium Molded Cable, HD15 Male / Female, 12.0 ft |       |       |       |       |       |
| <a href="#">CS2H15MF-15</a>  | Premium Molded Cable, HD15 Male / Female, 15.0 ft |       |       |       |       |       |
| <a href="#">CS2H15MF-25</a>  | Premium Molded Cable, HD15 Male / Female, 25.0 ft |       |       |       |       |       |
| <a href="#">CS2H15MF-50</a>  | Premium Molded Cable, HD15 Male / Female, 50.0 ft |       |       |       |       |       |

**Note:** Cables utilizing coaxial signal lines are recommended for video monitors.

**✓ Premium 25 Pin D-Sub Serial Parallel Cables - Molded, Fully Populated and Double Shielded**

|                              |   |       |       |       |       |       |
|------------------------------|---|-------|-------|-------|-------|-------|
| <a href="#">CS2N25MM-2.5</a> | Premium Molded Cable, DB25 Male / Male, 2.5 ft    | 39.99 | 39.99 | 39.99 | 39.99 | 39.99 |
| <a href="#">CS2N25MM-5</a>   | Premium Molded Cable, DB25 Male / Male, 5.0 ft    |       |       |       |       |       |
| <a href="#">CS2N25MM-6</a>   | Premium Molded Cable, DB25 Male / Male, 6.0 ft    |       |       |       |       |       |
| <a href="#">CS2N25MM-10</a>  | Premium Molded Cable, DB25 Male / Male, 10.0 ft   |       |       |       |       |       |
| <a href="#">CS2N25MM-12</a>  | Premium Molded Cable, DB25 Male / Male, 12.0 ft   |       |       |       |       |       |
| <a href="#">CS2N25MM-15</a>  | Premium Molded Cable, DB25 Male / Male, 15.0 ft   |       |       |       |       |       |
| <a href="#">CS2N25MM-25</a>  | Premium Molded Cable, DB25 Male / Male, 25.0 ft   |       |       |       |       |       |
| <a href="#">CS2N25MM-50</a>  | Premium Molded Cable, DB25 Male / Male, 50.0 ft   |       |       |       |       |       |
| <a href="#">CS2N25MF-2.5</a> | Premium Molded Cable, DB25 Male / Female, 2.5 ft  |       |       |       |       |       |
| <a href="#">CS2N25MF-5</a>   | Premium Molded Cable, DB25 Male / Female, 5.0 ft  |       |       |       |       |       |
| <a href="#">CS2N25MF-6</a>   | Premium Molded Cable, DB25 Male / Female, 6.0 ft  |       |       |       |       |       |
| <a href="#">CS2N25MF-10</a>  | Premium Molded Cable, DB25 Male / Female, 10.0 ft |       |       |       |       |       |
| <a href="#">CS2N25MF-12</a>  | Premium Molded Cable, DB25 Male / Female, 12.0 ft |       |       |       |       |       |
| <a href="#">CS2N25MF-15</a>  | Premium Molded Cable, DB25 Male / Female, 15.0 ft |       |       |       |       |       |
| <a href="#">CS2N25MF-25</a>  | Premium Molded Cable, DB25 Male / Female, 25.0 ft |       |       |       |       |       |
| <a href="#">CS2N25MF-50</a>  | Premium Molded Cable, DB25 Male / Female, 50.0 ft |       |       |       |       |       |

**✓ Premium 37 Pin D-Sub Serial Parallel Cables - Molded, Fully Populated and Double Shielded**

|                              |   |       |       |       |       |       |
|------------------------------|---|-------|-------|-------|-------|-------|
| <a href="#">CS2N37MM-2.5</a> | Premium Molded Cable, DB37 Male / Male, 2.5 ft    | 69.99 | 69.99 | 69.99 | 69.99 | 69.99 |
| <a href="#">CS2N37MM-5</a>   | Premium Molded Cable, DB37 Male / Male, 5.0 ft    |       |       |       |       |       |
| <a href="#">CS2N37MM-10</a>  | Premium Molded Cable, DB37 Male / Male, 10.0 ft   |       |       |       |       |       |
| <a href="#">CS2N37MM-15</a>  | Premium Molded Cable, DB37 Male / Male, 15.0 ft   |       |       |       |       |       |
| <a href="#">CS2N37MM-25</a>  | Premium Molded Cable, DB37 Male / Male, 25.0 ft   |       |       |       |       |       |
| <a href="#">CS2N37MM-50</a>  | Premium Molded Cable, DB37 Male / Male, 50.0 ft   |       |       |       |       |       |
| <a href="#">CS2N37MF-2.5</a> | Premium Molded Cable, DB37 Male / Female, 2.5 ft  |       |       |       |       |       |
| <a href="#">CS2N37MF-5</a>   | Premium Molded Cable, DB37 Male / Female, 5.0 ft  |       |       |       |       |       |
| <a href="#">CS2N37MF-10</a>  | Premium Molded Cable, DB37 Male / Female, 10.0 ft |       |       |       |       |       |
| <a href="#">CS2N37MF-15</a>  | Premium Molded Cable, DB37 Male / Female, 15.0 ft |       |       |       |       |       |
| <a href="#">CS2N37MF-25</a>  | Premium Molded Cable, DB37 Male / Female, 25.0 ft |       |       |       |       |       |
| <a href="#">CS2N37MF-50</a>  | Premium Molded Cable, DB37 Male / Female, 50.0 ft |       |       |       |       |       |