



THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

REVISIONS			
REV	DESCRIPTION	DATE	APPROVED
A	INITIAL RELEASE	06/10/10	DFP
A	ECN99999: CORRECTED PRODUCT DESCRIPTION IN TITLE BLOCK	10/04/10	DFP

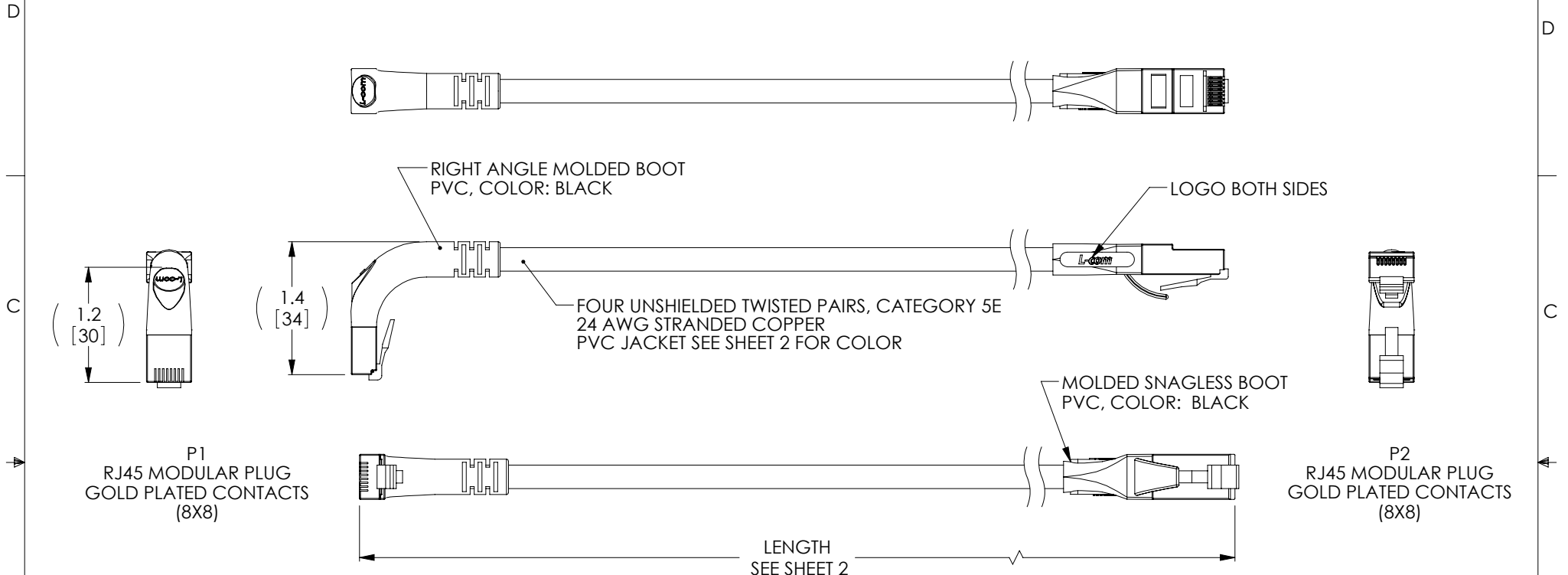

**WIRING MAP**

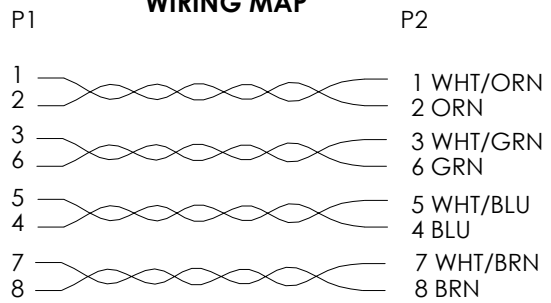

- NOTES:**
1. CABLE ASSEMBLY SHALL BE TESTED FOR CONTINUITY.
  2. CABLE ASSEMBLY SHALL BE INDIVIDUALLY PACKAGED IN ACCORDANCE WITH L-COM PACKAGING SPECIFICATION PS-0031.

**RoHS Compliant** ✓

UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE IN INCHES [mm] OVERALL CABLE LENGTH TOLERANCE: ≤12 [305] = +1 [25] / -0 >12 [305] ≤60 [1524] = +2 [51] / -0 >60 [1524] ≤120 [3048] = +4 [102] / -0 >120 [3048] ≤300 [7620] = +6 [152] / -0 >300 [7620] = +3% / -0%	APPROVALS	DATE		45 BEECHWOOD DRIVE NORTH ANDOVER, MA 01845
	DRAWN BY D. PARHAM	04/15/2010		CATEGORY
ALL OTHER DIMENSIONAL TOLERANCES: .X = ±.2 .XX = ±.02 .XXX = ±.005	CHECKED BY D. CASTRO	04/29/2010	PRODUCT DESCRIPTION	
PROJECTION 	APPROVED BY P. McNEIL	04/29/2010	CA RJ45 STR- RA CAT 5E	
	CONFIGURATION DETAILS OF UNDIMENSIONED FEATURES MAY VARY		SIZE <b>A</b>	FSCM NO. <b>43321</b>
	COLOR VARIATIONS MAY OCCUR		DWG. NO. TRD815RA	REV. <b>A</b>
			SCALE: NONE	CAD FILE: TRD815RA.SLDDRW
			SHEET 1 OF 2	

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

PART NUMBER	COLOR	LENGTH FEET [METERS]	PART NUMBER	COLOR	LENGTH FEET [METERS]	PART NUMBER	COLOR	LENGTH FEET [METERS]	PART NUMBER	COLOR	LENGTH FEET [METERS]
TRD815RABLK-1	BLACK	1 [0.31]	TRD815RARD-1	RED	1 [0.31]	TRD815RAOR-1	ORANGE	1 [0.31]	TRD815RABL-1	BLUE	1 [0.31]
TRD815RABLK-2	BLACK	2 [0.61]	TRD815RARD-2	RED	2 [0.61]	TRD815RAOR-2	ORANGE	2 [0.61]	TRD815RABL-2	BLUE	2 [0.61]
TRD815RABLK-3	BLACK	3 [0.91]	TRD815RARD-3	RED	3 [0.91]	TRD815RAOR-3	ORANGE	3 [0.91]	TRD815RABL-3	BLUE	3 [0.91]
TRD815RABLK-5	BLACK	5 [1.52]	TRD815RARD-5	RED	5 [1.52]	TRD815RAOR-5	ORANGE	5 [1.52]	TRD815RABL-5	BLUE	5 [1.52]
TRD815RABLK-7	BLACK	7 [2.13]	TRD815RARD-7	RED	7 [2.13]	TRD815RAOR-7	ORANGE	7 [2.13]	TRD815RABL-7	BLUE	7 [2.13]
TRD815RABLK-10	BLACK	10 [3.05]	TRD815RARD-10	RED	10 [3.05]	TRD815RAOR-10	ORANGE	10 [3.05]	TRD815RABL-10	BLUE	10 [3.05]
TRD815RABLK-15	BLACK	15 [4.57]	TRD815RARD-14	RED	15 [4.57]	TRD815RAOR-14	ORANGE	15 [4.57]	TRD815RABL-15	BLUE	15 [4.57]
TRD815RABLK-20	BLACK	20 [6.10]	TRD815RARD-20	RED	20 [6.10]	TRD815RAOR-20	ORANGE	20 [6.10]	TRD815RABL-20	BLUE	20 [6.10]
TRD815RABLK-25	BLACK	25 [7.62]	TRD815RARD-25	RED	25 [7.62]	TRD815RAOR-25	ORANGE	25 [7.62]	TRD815RABL-25	BLUE	25 [7.62]
TRD815RABLK-30	BLACK	30 [9.14]	TRD815RARD-30	RED	30 [9.14]	TRD815RAOR-30	ORANGE	30 [9.14]	TRD815RABL-30	BLUE	30 [9.14]
TRD815RABLK-40	BLACK	40 [12.19]	TRD815RARD-40	RED	40 [12.19]	TRD815RAOR-40	ORANGE	40 [12.19]	TRD815RABL-40	BLUE	40 [12.19]
TRD815RABLK-50	BLACK	50 [15.24]	TRD815RARD-50	RED	50 [15.24]	TRD815RAOR-50	ORANGE	50 [15.24]	TRD815RABL-50	BLUE	50 [15.24]
TRD815RABLK-60	BLACK	60 [18.29]	TRD815RARD-60	RED	60 [18.29]	TRD815RAOR-60	ORANGE	60 [18.29]	TRD815RABL-60	BLUE	60 [18.29]
TRD815RABLK-75	BLACK	75 [22.86]	TRD815RARD-75	RED	75 [22.86]	TRD815RAOR-75	ORANGE	75 [22.86]	TRD815RABL-75	BLUE	75 [22.86]
TRD815RABLK-100	BLACK	100 [30.48]	TRD815RARD-100	RED	100 [30.48]	TRD815RAOR-100	ORANGE	100 [30.48]	TRD815RABL-100	BLUE	100 [30.48]
TRD815RAGR-1	GREEN	1 [0.31]	TRD815RAY-1	YELLOW	1 [0.31]	TRD815RAGRY-1	GRAY	1 [0.31]			
TRD815RAGR-2	GREEN	2 [0.61]	TRD815RAY-2	YELLOW	2 [0.61]	TRD815RAGRY-2	GRAY	2 [0.61]			
TRD815RAGR-3	GREEN	3 [0.91]	TRD815RAY-3	YELLOW	3 [0.91]	TRD815RAGRY-3	GRAY	3 [0.91]			
TRD815RAGR-5	GREEN	5 [1.52]	TRD815RAY-5	YELLOW	5 [1.52]	TRD815RAGRY-5	GRAY	5 [1.52]			
TRD815RAGR-7	GREEN	7 [2.13]	TRD815RAY-7	YELLOW	7 [2.13]	TRD815RAGRY-7	GRAY	7 [2.13]			
TRD815RAGR-10	GREEN	10 [3.05]	TRD815RAY-10	YELLOW	10 [3.05]	TRD815RAGRY-10	GRAY	10 [3.05]			
TRD815RAGR-15	GREEN	15 [4.57]	TRD815RAY-15	YELLOW	15 [4.57]	TRD815RAGRY-15	GRAY	14 [4.57]			
TRD815RAGR-20	GREEN	20 [6.10]	TRD815RAY-20	YELLOW	20 [6.10]	TRD815RAGRY-20	GRAY	20 [6.10]			
TRD815RAGR-25	GREEN	25 [7.62]	TRD815RAY-25	YELLOW	25 [7.62]	TRD815RAGRY-25	GRAY	25 [7.62]			
TRD815RAGR-30	GREEN	30 [9.14]	TRD815RAY-30	YELLOW	30 [9.14]	TRD815RAGRY-30	GRAY	30 [9.14]			
TRD815RAGR-40	GREEN	40 [12.19]	TRD815RAY-40	YELLOW	40 [12.19]	TRD815RAGRY-40	GRAY	40 [12.19]			
TRD815RAGR-50	GREEN	50 [15.24]	TRD815RAY-50	YELLOW	50 [15.24]	TRD815RAGRY-50	GRAY	50 [15.24]			
TRD815RAGR-60	GREEN	60 [18.29]	TRD815RAY-60	YELLOW	60 [18.29]	TRD815RAGRY-60	GRAY	60 [18.29]			
TRD815RAGR-75	GREEN	75 [22.86]	TRD815RAY-75	YELLOW	75 [22.86]	TRD815RAGRY-75	GRAY	75 [22.86]			
TRD815RAGR-100	GREEN	100 [30.48]	TRD815RAY-100	YELLOW	100 [30.48]	TRD815RAGRY-100	GRAY	100 [30.48]			

**L-com** Global Connectivity 45 BEECHWOOD DRIVE  
NORTH ANDOVER, MA 01845

CATEGORY: MODULAR

PRODUCT DESCRIPTION: CA RJ45 STR- RA CAT 5E

SIZE: <b>A</b>	FSCM NO.: <b>43321</b>	DWG. NO.: <b>TRD815RA</b>	REV.: <b>A</b>
SCALE: NONE			CAD FILE: TRD815RA.SLDDRW
			SHEET 2 OF 2