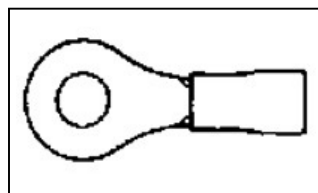


[Corporate Home](#) | [Electronic Components](#) | [Segments](#) | [Who We Are](#)

Worldwide

[Products](#) [Documentation](#) [Resources](#) [My Account](#) [Customer Support](#)

35666 Product Details

**35666**

TE Part Number: 35666

Active [Add to Part List](#)

Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))**Product Highlights:**

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = SOLISTRAND
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#) [Previous](#) [1](#) ... **[6]** [7](#) [8](#) [9](#) [10](#) ... [20](#) [Next](#) **Quick Links**

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Compare Products](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#) **NEW!**

Documentation & Additional Information

Product Drawings:

- [TERMINAL, RING TONGUE,SOLISTRAND ZTM](#) (PDF, English)

Catalog Pages/Data Sheets:

- [SOLISTRAND BUDGET AND DIAMOND GRIP UNINSULATED TERMI...](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- [EMD Terminal and Splice Kit](#) (PDF, English)

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

| | |
|--|--|
| <p>Product Type Features:</p> <ul style="list-style-type: none">● Terminal Shape = Ring Tongue● Receptacle Style = Straight● Body Style = SOLISTRAND● Barrel Type = Closed Barrel● Wire/Cable Type = Regular Wire● Insulation = No● Insulation Support = Non-Insulation Support● Stud Size = 3/4● Stud Diameter (mm [in]) = 19.84 [0.781]● Shape = RING-048● Heavy Duty = No● Material = Copper● Finish = Tin <p>Body Related Features:</p> <ul style="list-style-type: none">● Wire Range (mm [AWG]) = 8.00² [8]● Wire Range (CMA) = 13,100 - 20,800● Barrel I.D. Min. (mm [in]) = 4.37 [0.172]● Wire Barrel I.D. (mm [in]) = 4.37 [0.172]● Stock Thickness (mm [in]) = 1.30 [0.051] | <p>Industry Standards:</p> <ul style="list-style-type: none">● Government/Industry Qualification = No● RoHS/ELV Compliance = RoHS compliant, ELV compliant● Lead Free Solder Processes = Not relevant for lead free process● RoHS/ELV Compliance History = Always was RoHS compliant <p>Packaging Related Features:</p> <ul style="list-style-type: none">● Packaging Method = Loose Piece <p>Other:</p> <ul style="list-style-type: none">● Brand = AMP |
|--|--|

[Provide Website Feedback](#) | [Need Help?](#)