


THESE DRAWINGS ARE THE PROPERTY OF QUALTEK ELECTRONICS AND NOT TO BE REPRODUCED FOR OR COMMUNICATED TO A THIRD PARTY WITHOUT THE EXPRESS WRITTEN PERMISSION OF AN OFFICER OF QUALTEK ELECTRONICS.

REVISION			
REV.	DESCRIPTION	DATE	APPROVED
B	RoHS Compliancy	06-01-06	DP

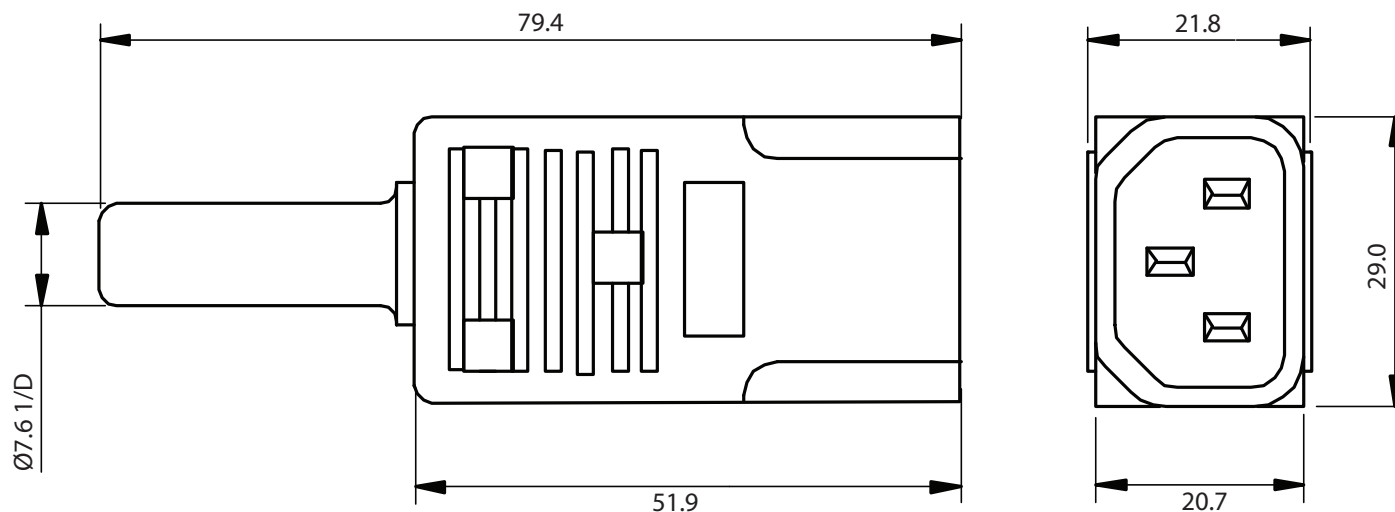

NOTES:

FOR USE WITH 18 AWG CORDAGE
 MAX. RATING: 10A 250V AC
 CONTACT RESISTANCE: < 10m OHM
 INSULATION RESISTANCE: > 1,000M OHM
 A.C. BREAKDOWN: POLE-POLE 6.5 kV POLE- ACCESSIBLE 6.5 kV
 OPERATING TEMPERATURE: -40°C TO +70°C
 WITHDRAWL FORCE: 10N(MIN), 50N(MAX)
 MATERIAL:
 MOULDING: NYLON, FLAMMABILITY RATING U.L. 94V-0
 CONTACTS: BRASS, NICKEL PLATED
 APPROVALS: UL, CSA, VDE
 RoHS COMPLIANT

CONTROLLED

Dim range (mm)	Tolerance +/- (mm)	Qualtek Electronics Corp. PPC DIVISION		
		Part Number:	712-00/00	RoHS Compliant
0-1	0.15	Description: REWIRABLE PLUG ASSEMBLY		
1-6	0.20			
6-18	0.30	UNIT: mm	REV. B	
18-50	0.50	Drawn / Date	Checked / Date	Approved / Date
50-120	0.70	B.ZHANG 04-11-02	04-11-02	JJH / 04-11-02
120-250	0.90			
250-500	1.20			