



TUF4AAPE

FOCUSED

- Bright White Spot LEDs produce tight spot beam



TOUGH

- Shatterproof lens protects lamp from damage



DURABLE

- Impact resistant light survives a 20-foot drop



WEATHERPROOF

- Survives both rugged weather on the job and floats for easy retrieval from water



RELIABLE

- Push button switch is designed to last a lifetime



Ideally suited for mid-sized jobs in smaller areas, the TUF4AAPE is easy to hold and pack up. It's bright white spot puts light where you need it most and the shatterproof lens shelters the LED.

Sturdy construction protects the internal components from damage in severe weather and demanding conditions on the job.




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

Product Detail:

Designation:	Hard Case Professional 4AA LED Flashlight
Model:	TUF4AAPE
Color:	Black and Dark Grey
Power Source:	Four "AA"
ANSI/NEDA:	15 Series
Lamp:	Four Nichia CS LEDs
Lamp Output Rating:	24 Lumens
Runtime:	15 Hrs (alkaline), 30 Hrs (lithium)
Durability:	Survives 20 Foot Drop
Typical Weight:	428 grams (15.1 oz.) (with alkaline batteries)
Dimensions (in):	8.87 x 3.03 (L x W)

Performance:

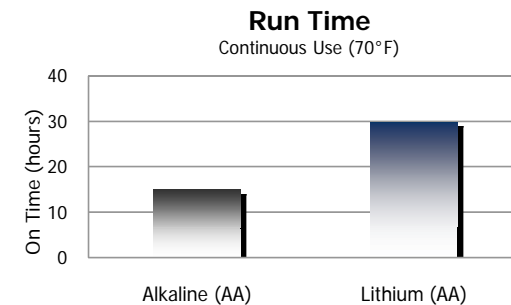

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication

Contents herein do not constitute a warranty
©Energizer / All Rights Reserved