

NEW 3 Channel XLR Microphone Mixer

- 3 XLR inputs
- 1 Balanced XLR output
- THD + Noise: 0.02%
- Max Output Level: +14dB
- Max Input Level: -14dB
- Clipping Headroom: 4dB
- Max Gain: +60dB
- Low Cut: -3dB@100Hz
- Current Draw :20mA
- Phantom Power: 18V DC (2 9V batteries not included)



MMB3XLR

48V DC Phantom Power Supply For Condenser Microphones

- Male XLR mic output connector
- Female XLR mic input connector
- 110/0V 60/50Hz
- 5ft. AC power cord included

MCPP100



Pre-Amplified Line Level Mic

- Add-on mini-microphone for all systems
- High sensitivity microphone with 1.5 ft. power/audio cable
- Easy to install and ideal for all security surveillance voice recording applications
- Line level output
- 12V DC power supply included



CAMMIC



CAMMIC



UTPAUDIO (shown below)

CAT5 Cable 1.8km



UTPAUDIO (shown below)

Audio CAT5 Extender and Ground Loop Device

- Gold-plated RCA female to RJ45
- Used in pairs via one CAT5 UTP cable to send audio signal of up to 1 mile
- 20Hz to 20kHz bandwidth
- Available for 75-120 Ohm cable
- High performance to eliminate audio ground loop problem
- No power required
- Sold in Pairs



UTPAUDIO

70V Speaker Line Transformer


- For Hi-Fi applications
- Taps: 20, 15, 10, 5
- 70V, 20W
- Sold individually



T7020

3 Position Stereo Selector Switch

- Three positions allow 3 stereo source inputs into 1 stereo source
- Sold individually

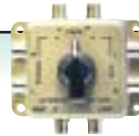

SSS1

5 Watt Line Transformer with Color-Coded Leads

- Taps: .25, .50, 1.0, 2.5, 5.0
- Sold individually



T70255

Matching Telephone Line Input Transformer

- Input matching transformer to connect telephone systems to aux. input of P.A. amplifiers for telephone paging
- Allows a music-on-hold system to a telephone system when connected to a 25V line output of a P.A. amplifier or tuner
- Impedance: 500/600 Ohms (line)
- Sold individually



TLT1

70 Volt - 20 Watt Line Transformer

- Multiple wattage taps: 20W, 15W, 10W & 5W
- EZ mount peel & stick to connect to existing 8 Ohm speakers
- Sold individually



T20

25 & 70 Volt Line Transformers

- Multiple taps: 10, 5, 2.5, 1.25, .625
- Sold individually



25 V Line **T2510**
70 V Line **T7010**