

Rackmount Power Outlet Strips



Design Features **Features**

- Standard 19" EIA rack mountable
- Utilizes 1U (1.75") panel height
- Have convenient lighted power switches on front surface which also indicate if power is on or off
- Popular black color
- UL Recognized

- 15 amp surge suppressed models meet UL 1363 and UL 1449 specifications for 330 volt suppressed voltage rating

- 20 amp non-surge suppressed models meet UL1363 specifications

15 amp models

- Are surge suppressed for use with your sensitive equipment
- Have outlets located either on the front surface or on the rear surface for maximum versatility
- Transient energy rating of 450 joules.
- Have 12 foot long power cords with standard 3-prong AC plug to allow the POS strip to be mounted anywhere in the cabinet rack, in any size cabinet rack, and to connect to any standard wall outlet

20 amp models

- Will accept your higher power rated equipment
- Have outlets located on the front surface for easy accessibility
- Have 12 foot long power cords to allow the POS strips to be mounted anywhere in the cabinet rack, and in any size cabinet rack

- Have either one or two power cords feeding either one or two separate circuits to allow for maximum capacity in one POS strip
- Have either standard 3-prong AC plugs or safety conscious locking AC plugs




Catalog Number		Surge Suppressed	Amp Capacity	Power Cords			Outlets	
				Number	Length	Plug	Number	Location
POS-194-S		Yes	15	1	12'	Non-locking	8	Rear
POS-195-S		Yes	15	1	12'	Non-locking	8	Front
POS-201		No	20	1	12'	Non-locking	8	Front
POS-202		No	20	1	12'	Locking	8	Front

PART NAME	RACKMOUNT POWER OUTLET STRIP (15 AMP) (SURGE SUPPRESSED)	PART No.	POS-195-S	REV. DATE	6-3-10
-----------	---	----------	-----------	-----------	--------

MATERIAL:
HOUSING - 20 GA. STEEL


FINISH:
HOUSING - TEXTURED BLACK

- NOTES:**
- INTERNAL WIRE CAPACITY - 14 AWG SOLID TW CONDUCTOR
 - ALL COMPONENTS ARE U.L. APPROVED
 - SURGE SUPPRESSION PROTECT VOLTAGE: 330 V.
 - U.L. LISTED IN U.S.A. AND CANADA. U.L. FILE #E203236

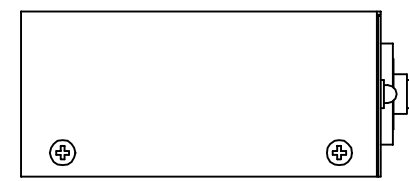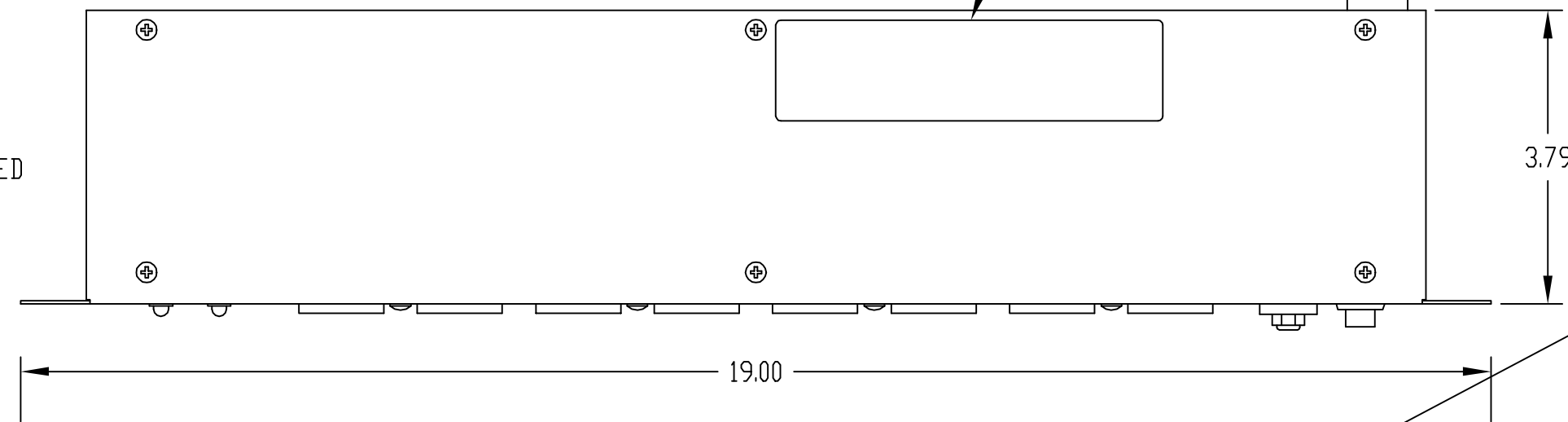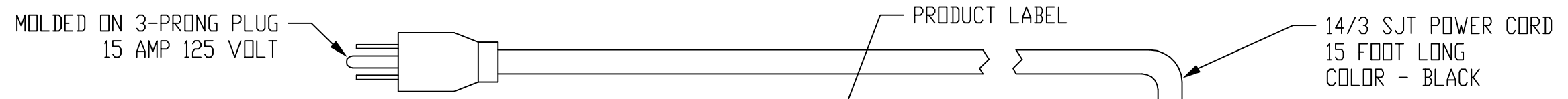


SURGE PROTECTION INDICATOR LAMP
15 AMP 125 VOLT, LENS COLOR - RED

GROUND INDICATOR LAMP
15 AMP 125 VOLT, LENS COLOR - GREEN

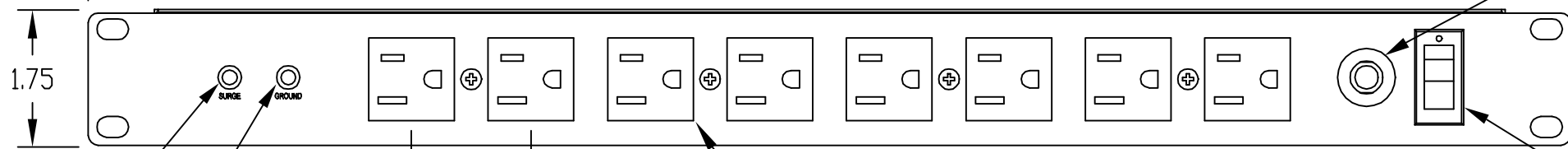


GROUNDING TYPE RECEPTACLE (8 PLCS.)
15 AMP 125 VOLT
COLOR - BLACK

CIRCUIT BREAKER THERMAL TYPE
15 AMP 125 VOLT WITH RESET
COLOR - BLACK

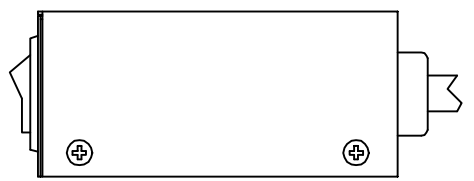

ON / OFF SWITCH (ILLUMINATED)
15 AMP 125 VOLT, COLOR - BLACK
BUTTON COLOR - RED TRANSPARENT
ILLUMINATED IN "ON" POSITION

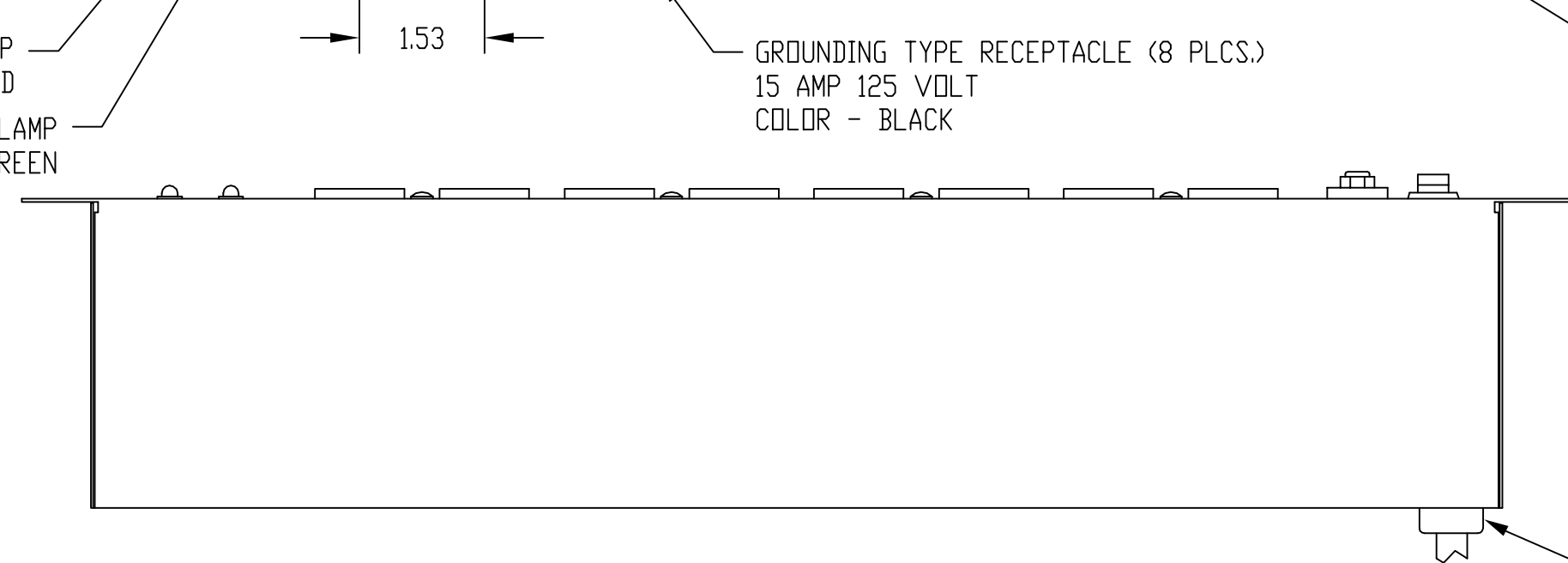

STRAIN RELIEF CORD SET TYPE
COLOR - BLACK

