




Open Racks **Table Top Rack**

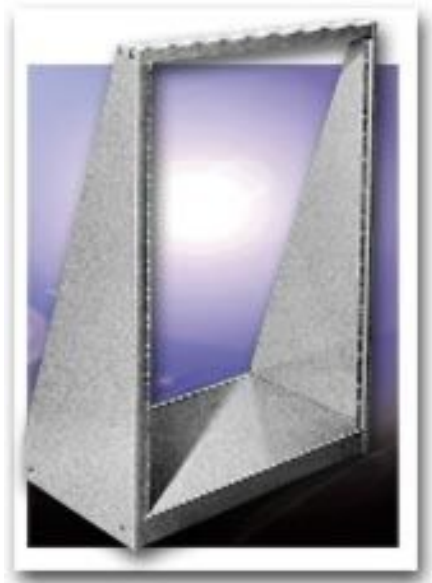

Design Features

Chassis-type base holds heavy components for table mounting applications. Supporting angles provide strength and rigidity. Panel mounting rails tapped #10-32 on E.I.A. universal spacing. (Use #7346 screws - order separately) Standard 19" panel fits flush with front. Base, 20.37" x 12.00". Shipped knocked down.

Finish: Metallic Gray and Black Texture

Features

Shipped knockdown in one carton.

Finishes

Finish: Black Texture (BT) and Metallic Grey

Table Top Rack				
Catalog Number	Drawings	Panel Space	Height	Weight Lbs.
RR-1248		21.00"	24.00"	14.25
RR-1249		28.00"	31.00"	16.75



PART
NAME

TABLE TOP RELAY RACK

PART
No.

RR-1248 AND RR-1249

MATERIAL:


SIDES & CROSS BAR _____ 16 GA. STEEL

BASE _____ 18 GA. STEEL

FINISH: METALLIC GRAY OR
BLACK TEXTURED

MOUNTING RAILS TAPPED #10-32 ON E.I.A. UNIVERSAL SPACING.

UNIT SHIPPED KNOCKED DOWN

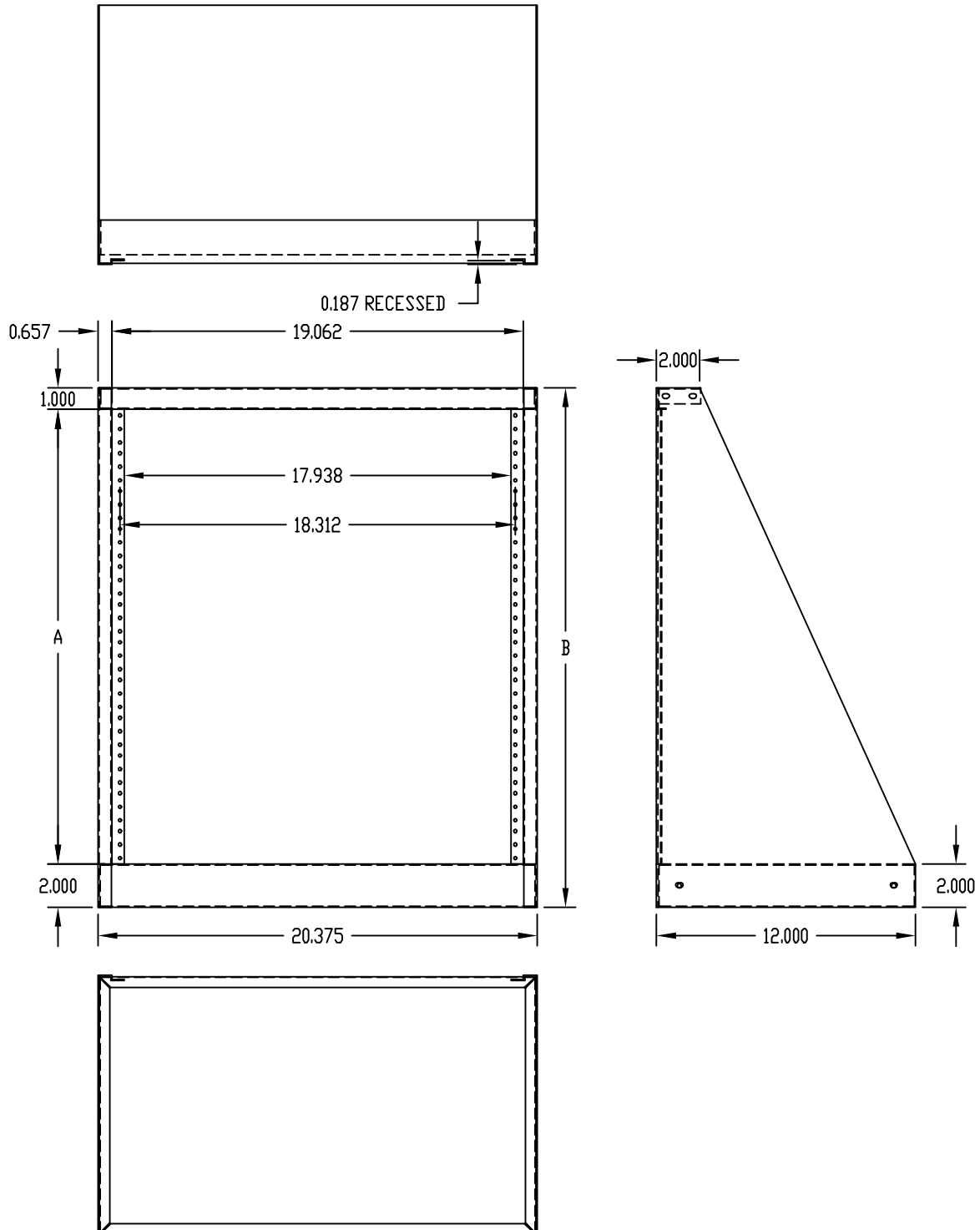

PART No.

A

B

RR-1248

21.000

24.000

RR-1249

28.000

31.000