


Trimmers

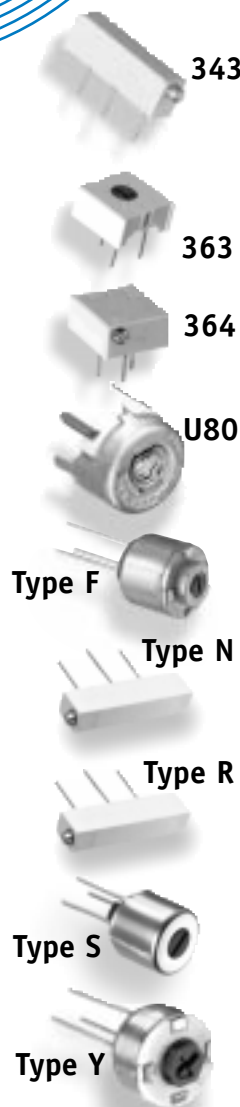

| | Resistive Element | Number of Turns | Power Rating (watts) | Resistance Range (ohms) | Tolerance | Body Dimension L x W x H (inches) | Terminal Configuration |
|--------|--------------------|-----------------|----------------------|-------------------------|------------|-----------------------------------|------------------------|
| 343 | Cermet | 20 | 0.75 | 10-2 meg | ±10% | 0.75 x 0.19 x 0.25 | PC |
| 363 | Cermet | Single | 0.5 | 10-2 meg | ±20% | 0.375 sq. x 0.190 | PC in 3 configurations |
| 364 | Cermet | 25 | 0.5 | 10-2 meg | ±10% | 0.375 sq. x 0.190 | PC in 4 configurations |
| U80 | Wirewound | Single | 3.0 | 5-5K | ±20% | 0.770 dia. | PC |
| Type F | Carbon composition | Single | 0.25 | 100-5meg | ±10%, ±20% | 0.500 dia x 0.531 | PC Solder lug |
| Type N | Carbon composition | 3 | 0.25 | 100-2.5 meg | ±10%, ±20% | 1.250 x 0.250 x 0.359 | PC |
| Type R | Carbon composition | 25 | 0.25 | 100-2.5 meg | ±10%, ±20% | 1.250 x 0.250 x 0.359 | PC in 2 configurations |
| Type S | Cermet | Single | 0.5 | 50-1 meg | ±10% | 0.375 dia. x 0.375 | PC in 2 configurations |
| Type Y | Carbon composition | Single | 0.25 | 100-5 meg | ±10%, ±20% | 0.500 dia x 0.359 | PC Solder lug |

Attenuators

Clarostat provides a variety of stock and custom Attenuators. Options and features include UL-approved, long rotational life, low to high power, versatile, circuit board mountable and compact units to meet specific design requirements. For a complete listing or for engineering assistance, call our Applications Engineers at the toll-free number below.

In this catalog, refer to the following: *Modular MOD POT 70 and 72, Wirewound Series 43 and 58, Board Washable Series 2000 and Industrial Series J.* Also, Type BT hot-molded, adjustable attenuators featuring 0.500" diameter, PC pin terminals, operation to 35 MHz, compact, board mountable (not shown).