


Proto-Boards® , Solderless Breadboards & Accessories

PB-105

Solderless Proto-Board Systems

- Today's Standard For Quality In Breadboarding
- Ideal for prototyping circuit applications to 57MHz & more!
- QT Sockets & bus strips mounted on rugged back panel
- Recommended for design, test fixture, quality control and education.
- "The only breadboard you'll ever have to buy!"
- Unconditional lifetime warranty
- Nickel silver alloy pins are pre-stressed, spring loaded and non-corrosive for long term reliability
- Molded in a rugged thermoplastic for durability and high temperature application
- Heavy mylar backing eliminates possibility of short circuits
- Patented design
- Proudly made in the U.S.A. from domestic materials
- Innovators of high quality breadboards since 1973

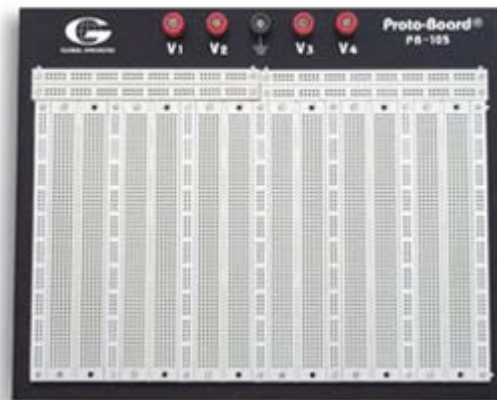

PB-105

Sockets	6/QT59S	Length	9.2 in (234mm)
Bus Strips	4/QT47B 7/QT59B	Width	11.4 in (280mm)
IC Capacity	48	Height	1.4 in (36mm)
Terminals	912	Powered	No
Tie Points	4560	Weight	29.0 oz
Binding Posts	5	Part Number	104-1050
Backplate	Aluminum		