

DANTONA

INDUSTRIES, INC.

For all your battery needs!

Camcorder Batteries



DANTONA PART SEARCH



Dantona Part # TR164A

Voltage: 6

Capacity: 335


Composition: ALKALINE

Dimensions: 17.1MM DIA X 44.9MM HGT

Connector: PRESSURE

Description: * * NEW AND IMPROVED *
*

WATCH, CALCULATOR, PHOTO AND ORGANIZER BATTERIES

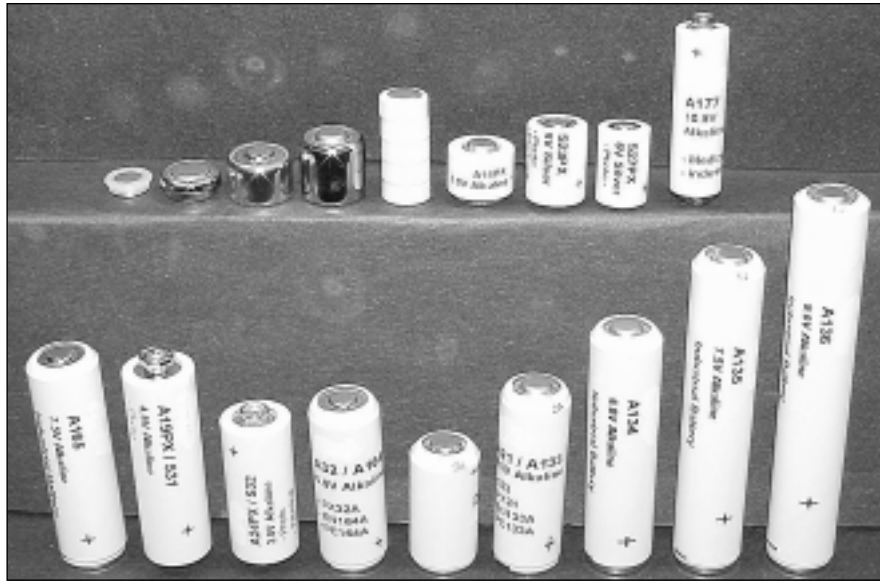

(Alkaline & Silver Oxide)

PART NO.	VOLTS	mAh	DIA. x HGT. (MM)	EVEREADY	DURACELL	PANASONIC RAY-O-VAC	OTHER	IEC NO.	CHEMISTRY	NEDA NO.	
L754	1.5	110	7.9 x 5.4	193	D193	L754	AG5	LR48	ALK	-	
TR132A	3	600	17.1 x 33.4	E132	PC132A	H-2P	E132, TR132R	2 MR50	ALK	1203M	
TR133A	4.5	600	17.1 x 49.9	E133	PC133A	H-3P	E133, TR133R	3MR50	ALK	1314M	
TR134A	6	600	17.1 x 66.5	E134	PC134A	-	E134, TR134R	4MR50	ALK	1409M	
TR135A	7.5	600	17.1 x 83.2	E135	PC135A	-	E135, TR135R	5MR50	ALK	1505M	
TR136A	9	600	17.1 x 97.9	E136	PC136A	-	E136, TR136R	6MR50	ALK	1616	
TR138A	12	600	17.1 X 133.6	E138	PC138A	-	-	7MR50	ALK	-	
TR164A	6	325	17.1 x 44.9	E164	PC164A	-	E164, TR164R	RMR52	ALK	1410	
TR165A	7.5	325	17.1 x 44.9	E165	PC165A	-	E165, TR165R	-	ALK	1506M	
TR175A	7.5	110	12.9 x 26.2	E175	PC175A	HM-SC	E175, TR175R	5NR44	ALK	1501	
TR175S	7.75	110	12.9 x 26.2	-	-	-	E175, TR175R	-	SILVER	-	
TR177A	10.5	110	12.9 x 47.1	E177	PC177A	-	E177, TR177R	7NR44	ALK	1606M	
V1ALK	1.5	650	15.8 x 16.4	PX1A	PC1A	-	EPX-1A	-	ALK	1109	
V3GA	1.5	30	7.9 x 3.6	192	D192	L736	AG3, 92A, 4261	LR41	ALK	-	
V8GA	1.5	25	11.6 x 2.1	191	D191A	LR1120	L1121, G8, LR112, AG8	LR55	ALK	1169A	
V10GA	1.5	50	11.6 x 3.05	189	D189A	LR1130	189-1 L1131, G10, RW89, LR113	LR54	ALK	1168A	
V12GA	1.5	80	11.6 x 4.2	186	D186A	LR43	186-1 L1142, G12, RW84, AG12	LR43	ALK	1167A	
V13GA	1.5	100	11.6 x 5.4	A76	D76A	LR44	RW82 L1154, G13, AG13, D76A	LR44	ALK	1166A	
V14PX	3	390	15.8 X 14	EPX14	PX14	PX14	RPX14	-	2MR9	ALK	-
V19PX	4.5	600	16.8 x 60.0	531	PX19	PX19	RPX19	-	3LR50	ALK	-
V21PX	4.5	600	16.8 x 50.5	523	PX21	PX21	RPX21	-	3LR50	ALK	1306AP
V23PX	6	105	14.2 X 20.2	EPX23	PX23	PX23	RPX23	-	-	SILVER	-
V24PX	3	600	16.8 x 43.5	532	PX24	PX24	RPX24	PX24	2LR50	ALK	1308AP
V27PX	6	145	12.3 X 20.1	EPX527	PX27	PX27	RPX27	-	-	SILVER	-
V28PX	1.36	145	12.8 x 25.2	544	PX28	4SR44	RPX28	4G-13	4SR44	ALK	1406SOP
V74PX	15	45	16.0 x 35	504	M504	W10E	-	BA332/U	10F15	ALK	220
V76PX	1.5	165	11.6 x 5.35	EPX76	MS76H	G-13	RS76	KS76	SR44	SILVER	1107SOP
V400PX	1.5	67	11.47 X 3.43	E400N	-	-	-	RM400R	-	SILVER	-
V625U	1.5	185	16.0 x 6.2	-	-	-	-	-	LR9	ALK	-
V675PX	1.35	210	11.6 x 5.4	EPX675	PX675	H-C	RPX675	H1154, RW52, 313	MR44	MERC	1128MP
V4034PX	6	100	13.0 x 25.2	A544, 537	PX28A	L1325	-	7H34, 4G13	4LR44	ALK	-
V640ALK	1.5	325	15.8 x 11.1	E640	PC640A	MR9	-	EPX640	NR52	ALK	1125M
625A	1.5	390	15.4 x 6.05	A625PX	PC625A	-	-	L1560, A625, LR9	-	ALK	-