

## LIGHTED APPLIANCE ROCKERS



Fig. 1



Fig. 2



Fig. 3



Fig. 4



Fig. 5

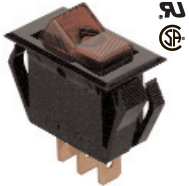


Fig. 6



Fig. 7



Fig. 8



Fig. 9



Fig. 10

### On-Off Circuit Function

| Retail Part No. | Bulk Part No. | Fig. No. | Poles/Throws | Amps 125 VAC | Amps 250 VAC | HP 125 VAC | HP 250 VAC | HP 125-250 VAC | Actuator Color        | Actuator Material | Lamp Voltage | Mounting Hole | Spec. Drawing Page/Part No. |
|-----------------|---------------|----------|--------------|--------------|--------------|------------|------------|----------------|-----------------------|-------------------|--------------|---------------|-----------------------------|
| 35-660          | 35-660-BU     | 1        | SPST         | **           | N/R          |            |            |                | Lighted Red           |                   | 12V Incdt    | 0.550 x 1.125 | 257-A                       |
| 35-684          | 35-684-BU     | 2        | SPST         | 10           | N/R          | N/R        | N/R        | N/R            | White w/ Red LED      | Plastic           | ***          | 0.430 x 1.189 | 257-B                       |
| 35-696          | 35-696-BU     | 3        | SPST         | 12           | 8            |            |            | 1/2            | Lighted Red           | Nylon             | 125V Ne      | 0.508 x 0.756 | 257-C                       |
| 35-656          | 35-656-BU     | 4        | SPST         | 15           | 10           |            |            | 1/2            | Black w/Lighted Amber | Nylon             | 125V Ne      | 1.450 x 0.830 | 257-D                       |
| 35-662          | 35-662-BU     | 5        | SPST         | 15           | 15           | 1/2        | 1          |                | Lighted Amber         | Nylon             | 12V Incdt    | 0.453 x 1.110 | 257-E                       |
| 35-664          | 35-664-BU     | 5        | SPST         | 15           | 15           | 1/2        | 1          |                | Lighted Green         | Nylon             | 12V Incdt    | 0.453 x 1.110 | 257-E                       |
| 35-688          | 35-688-BU     | 5        | SPST         | 15           | 15           | 1/2        | 1          |                | Lighted Red           | Nylon             | 105/130V Ne  | 0.453 x 1.110 | 257-E                       |
| 35-689          | 35-689-BU     | 6        | SPST         | 15*          | 10           |            |            | 3/4            | Lighted Red           | Nylon             | 125V Ne      | 0.550 x 1.125 | 257-F                       |
| 35-3790         | 35-3790-BU    | 6        | SPST         | 15           | 10           |            |            | 3/4            | Lighted Amber         | Nylon             | 125V Ne      | 0.550 x 1.125 | 257-F                       |
| 35-621          | 35-621-BU     | 7        | SPST         | 16           | 16           |            |            |                | Black w/Red Lens      | Plastic           | 125V Ne      | 0.870 x 1.070 | 257-G                       |
| 35-3730         | 35-3730-BU    | 8        | SPST         | 16           | 10           |            |            |                | Lighted Amber         |                   | 125V Ne      | 0.550 x 1.125 | 257-H                       |
| 35-3740         | 35-3740-BU    | 8        | SPST         | 16           | 10           |            |            |                | Lighted Red           |                   | 125V Ne      | 0.550 x 1.125 | 257-H                       |
| 35-655          | 35-655-BU     | 9        | DPST         | 20           | 15           | N/R        | N/R        |                | Lighted Red           | Plastic           | 125V Ne      | 1.000 x 1.125 | 257-I                       |
| 35-686          | 35-686-BU     | 10       | DPST         | 20           | 20           | 1/2        | 1          |                | Black w/Red Indicator | Plastic           | 125V Ne      | 1.180 x 0.870 | 257-J                       |
| 35-3750         | 35-3750-BU    | 8        | SPST         | 20           | 16           |            |            |                | Lighted Green         |                   | 125V Ne      | 0.550 x 1.125 | 257-H                       |

Notes: \*Built-in Resistor  
 \*\*Rated 10 Amps @ 30VDC  
 \*\*\*Requires external resistor and diode for AC applications (not included)  
 Incdt=Incandescent  
 Ne=Neon  
 N/R=Not Rated  
 QC=Quick Connect

The Terminal Types for the above parts are QC .250" except for 35-684 is Solder and 35-696 is QC .187".

Note: All figures are for illustration purpose only, and the number/type of terminals may vary.