

561-02634

W.I.C. Tag for 2.8mm to 3.8mm cable range. 16 to 14 awg. Black text on yellow. 20 per strip - 20

Article Number: 561-02634

Part Number: 561-02634

Type: WIC2-3


Miscellaneous Labels

WIC® Markers

WIC® markers permanently and rapidly mark wires. Now, it's simple to change identification on wires which are already marked. This range of clip-on markers is specially designed for use after wire termination has been completed. The unique gripping profile is designed to ensure that clip remains in place under normal and vibration working conditions.

The deeply stamped mark, black print on yellow provide high legibility. The interlocking device ensures perfect alignment of multi-mark legends. A high grade of material guarantees good mechanical properties and chemical resistance against cleaning agents, oils and fuels. Only 3 sizes of markers are needed for identifying wire cross-sections ranging from an outside cable diameter of .75" - .208" (2.0 to 5.3mm).

WIC is an "open marker", open markers can be applied to pre-terminated wire and cable. Use the re-fillable applicator to easily apply and position the markers during installation.

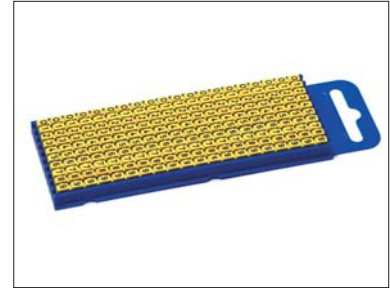


The convenient WIC dispenser ideal for pocket or toolbox storage.

Packaging

The pocket size dispensers of 200 markers (W1 and W2) and 100 markers (W3) adapted for use on site and easy stored. Customized compositions or special characters on request.

WIC Markers	Yes	No
Refillable Applicator	•	
Wire Grips	•	
Color Coded Applicators		•

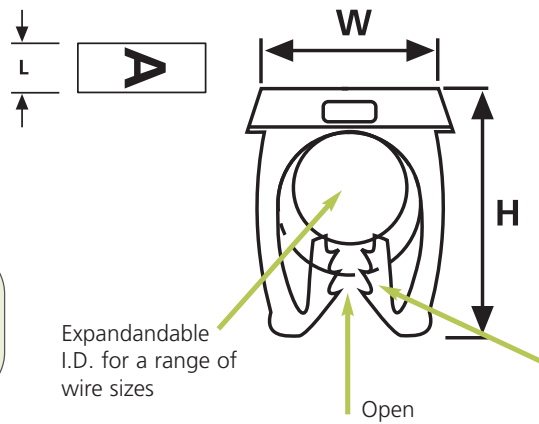

WIC is an "open marker". Open markers can be applied to pre-terminated wire and cable. Use the re-fillable applicator to easily apply and position the markers during installation.

Wire grips to secure the markers to the wire

Product Data	W1 RoHS	W2 RoHS	W3 RoHS
Label Material			
Material	Polyamide 6	Polyamide 6	Polyamide 6
Color	Yellow/ Black Print	Yellow/ Black Print	Yellow/ Black Print
Temperature Range	-40°F to +185°F, intermittent 221°F (-40°C to +85°C, intermittent 105°C)	-40°F to +185°F, intermittent 221°F (-40°C to +85°C, intermittent 105°C)	-40°F to +185°F, intermittent 221°F (-40°C to +85°C, intermittent 105°C)
Flammability	Self-extinguishing UL94VO - base material	Self-extinguishing UL94VO - base material	Self-extinguishing UL94VO - base material
Approvals	ICE 304, EN 60062, UL94	ICE 304, EN 60062, UL94	ICE 304, EN 60062, UL94
Cable Range - in. (mm)	2.0" - 2.8" (50.8 - 71.12)	2.8" to 3.8" (71.12 - 96.52)	4.3" to 5.3" (109.22 - 134.62)
Nominal Wire Cross Section - in. (mm)	0.5" to 1.5" (12.7 - 38.1)	1.5" to 2.5" (38.1 - 63.5)	4" to 6" (101.6 - 152.4)
AWG	20 to 18	16 to 14	10 to 8
Width (W) - in. (mm)	.19" (5)	.22" (5.6)	.31" (8.0)
Height (H) - in. (mm)	.25" (6.4)	.28" (7.1)	.38" (9.6)
Length (L) - in. (mm)	.12" (3.0)	.12" (3.0)	.12" (3.0)
Markers per Strip	20	20	10
Package Quantity	200	200	100

WIC® Markers *continued*

Product Selection					
Wire Size	Legend	Article No.	Part No.	Type	Pkg. Qty.
20-18 Gauge Wire - Wire O.D. in. (mm) .075" - 0.110" (2-2.8)	0	561-01604	561-01604	WIC1-0	200
	1	561-01614	561-01614	WIC1-1	200
	2	561-01624	561-01624	WIC1-2	200
	3	561-01634	561-01634	WIC1-3	200
	4	561-01644	561-01644	WIC1-4	200
	5	561-01654	561-01654	WIC1-5	200
	6	561-01664	561-01664	WIC1-6	200
	7	561-01674	561-01674	WIC1-7	200
	8	561-01684	561-01684	WIC1-8	200
	9	561-01694	561-01694	WIC1-9	200
16 -14 Gauge Wire - Wire O.D. in. (mm) .110" - 0.149" (2.8-3.8)	0	561-02604	561-02604	WIC2-0	200
	1	561-02614	561-02614	WIC2-1	200
	2	561-02624	561-02624	WIC2-2	200
	3	561-02634	561-02634	WIC2-3	200
	4	561-02644	561-02644	WIC2-4	200
	5	561-02654	561-02654	WIC2-5	200
	6	561-02664	561-02664	WIC2-6	200
	7	561-02674	561-02674	WIC2-7	200
	8	561-02684	561-02684	WIC2-8	200
	9	561-02694	561-02694	WIC2-9	200
10-8 Gauge Wire - Wire O.D. in. (mm) .169" - 0.208" (4.3-5.3)	0	561-03604	561-03604	WIC3-0	100
	1	561-03614	561-03614	WIC3-1	100
	2	561-03624	561-03624	WIC3-2	100
	3	561-03634	561-03634	WIC3-3	100
	4	561-03644	561-03644	WIC3-4	100
	5	561-03654	561-03654	WIC3-5	100
	6	561-03664	561-03664	WIC3-6	100
	7	561-03674	561-03674	WIC3-7	100
	8	561-03684	561-03684	WIC3-8	100
	9	561-03694	561-03694	WIC3-9	100

Use **Part No.** for ordering and **Type** for specification purposes.

WIC Markers are also available in A-Z upon request, please contact HellermannTyton for details.

WICTOOL Applicator

WICTOOL easily applies WIC markers to wire. The unique design of curved head and push out system makes this applicator very easy to use and perfectly adapted to WIC markers. WICTOOL must be ordered separate from WIC markers.

Product Selection			
Article No.	Part No.	Type	Pkg. Qty.
561-00001	561-00001	WIC TOOL	5

