

## Shelves (Fixed) - Internal Mount (Two Pair of Panel Rails)

Path: [Home](#) > [Rack Index](#) > Shelves (Fixed) - Internal Mount - Two Pair of Panel Rails



[click to enlarge](#)



[Assembly  
Instructions](#)

### Fixed Shelf (Unvented)

- Attach to the sides of both pair of rack combination rails
- Requires no front rail mounting
- Front & rear lip folded for extra strength
- Weight load tested (RFVS2426BK1) to 350 pounds!
- Versatile design - can be used as shown (easy to install) or upside down (front & rear lip become equipment retainers)
- Heavy duty, 14 Ga. steel construction
- Sides folded up for easy hardware installation from above
- Sides are slotted for easy adjustment with most rail depth locations
- Rugged textured powder paint finish
- Includes all mounting hardware
- If used with our square hole rails you will need to order P/N **CPRSA** rail adaptor for each shelf ordered.  
(below) to more information.
- **MOUNTS ON TWO PAIR OF PANEL RAILS (FRONT & BACK)**

## ***UNVENTED - 19" Rack Mount***

<b>Part Number</b>	<b>Color</b>		<b>Drawing File Size</b>		<b>.zip File Size</b>	<b>Shelf Depth</b>
<b>RFUS1918BK1</b> <b>RFUS1918CG1</b>	Black Grey/Beige		43K		54K	18"
<b>RFUS1921BK1</b> <b>RFUS1921CG1</b>	Black Grey/Beige		43K		56K	21"
<b>RFUS1926BK1</b> <b>RFUS1926CG1</b>	Black Grey/Beige		42K		53K	26"
<b>RFUS1931BK1</b> <b>RFUS1931CG1</b>	Black Grey/Beige		44K		56K	31"

## ***UNVENTED - 24" Rack Mount***


<b>Part Number</b>	<b>Color</b>		<b>Drawing File Size</b>		<b>.zip File Size</b>	<b>Shelf Depth</b>
<b>RFUS2418BK1</b> <b>RFUS2418CG1</b>	Black Grey/Beige		13K		16K	18"
<b>RFUS2421BK1</b> <b>RFUS2421CG1</b>	Black Grey/Beige		14K		18K	21"
<b>RFUS2426BK1</b> <b>RFUS2426CG1</b>	Black Grey/Beige		14K		18K	26"
<b>RFUS2431BK1</b> <b>RFUS2431CG1</b>	Black Grey/Beige		14K		19K	31"

***Note:*** Weight load tested (RFUS2426BK1) to 350 pounds.


---

NOTES

FINISH: TEXTURED POWDER PAINT "BK1" BLACK OR "CG1" GRAY (RAL 7032)  
 10-32 MOUNTING SCREWS AND SPACER SHIMS ARE SUPPLIED WITH THE SHELF

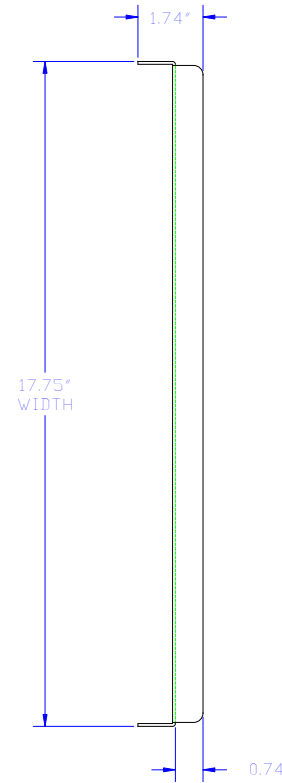

FRONT VIEW

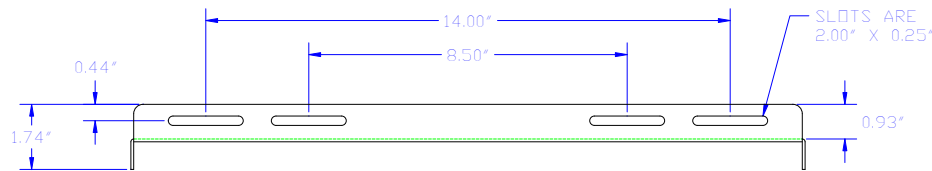

SIDE VIEW

THIS DRAWING IS PROPRIETARY INFORMATION OF HAMMOND MFG.CO.LTD. NOT TO BE USED WITHOUT EXPRESSED WRITTEN PERMISSION OF HAMMOND MFG.CO.LTD.

△	N/A	CUSTOMER INFORMATION	02.04.18	RJG
Rev	ECN	Description	Date	By

Unless Otherwise Spec'd  
 Dimensions are in inches  
 Tolerances are:  
 X ±.1  
 .XX ±.06  
 .XXX ±.020  
 .XXXX ±.0050  
 Holes ±.0050  
 Angles ±.5°

Dwn	R. GODFREY
Date	02.04.18
Chk	---
Mat'l	14 GA STEEL
Sheet	1 of 1

 HAMMOND MANUFACTURING CO. LTD  
 Enclosure Group, Guelph, Ontario, Canada

CONTEMPRA II  
 FIXED SOLID SHELF-RFUS

Part#	RFUS1918	Dwg#	RFUS1918/A1
-------	----------	------	-------------

RFUS1918/A1

Ref. Dwg. XXX


# Shelves - Dual Pair Rail Mount

## FIXED SHELVES

- Heavy duty, 14 Ga. steel construction, folded edges on all four sides for extra strength
- The vented version provides a sturdy shelf without obstructing upward heat movement
- Weight load tested to 350 pounds
- Sides folded up for easy hardware installation from above the shelf
- Sides are slotted for easy adjustment with most rail depth locations
- Rugged textured powder paint finish
- If used with our square hole rails you will need to order P/N **CPRSA** rail adaptor for each shelf ordered
- **MOUNTS ON TWO PAIR OF MOUNTING RAILS (FRONT & BACK)**

Part Number		Shelf Type	Shelf Depth
Black Textured	Beige Textured		
<b>19" Width</b>			
<a href="#">RFVS1918BK1</a>	<a href="#">RFVS1918CG1</a>	Vented	18"
<a href="#">RFVS1921BK1</a>	<a href="#">RFVS1921CG1</a>	Vented	21"
<a href="#">RFVS1926BK1</a>	<a href="#">RFVS1926CG1</a>	Vented	26"
<a href="#">RFVS1931BK1</a>	<a href="#">RFVS1931CG1</a>	Vented	31"
<a href="#">RFUS1918BK1</a>	<a href="#">RFUS1918CG1</a>	Unvented	18"
<a href="#">RFUS1921BK1</a>	<a href="#">RFUS1921CG1</a>	Unvented	21"
<a href="#">RFUS1926BK1</a>	<a href="#">RFUS1926CG1</a>	Unvented	26"
<a href="#">RFUS1931BK1</a>	<a href="#">RFUS1931CG1</a>	Unvented	31"
<b>24" Width</b>			
<a href="#">RFVS2418BK1</a>	<a href="#">RFVS2418CG1</a>	Vented	18"
<a href="#">RFVS2421BK1</a>	<a href="#">RFVS2421CG1</a>	Vented	21"
<a href="#">RFVS2426BK1</a>	<a href="#">RFVS2426CG1</a>	Vented	26"
<a href="#">RFVS2431BK1</a>	<a href="#">RFVS2431CG1</a>	Vented	31"
<a href="#">RFUS2418BK1</a>	<a href="#">RFUS2418CG1</a>	Unvented	18"
<a href="#">RFUS2421BK1</a>	<a href="#">RFUS2421CG1</a>	Unvented	21"
<a href="#">RFUS2426BK1</a>	<a href="#">RFUS2426CG1</a>	Unvented	26"
<a href="#">RFUS2431BK1</a>	<a href="#">RFUS2431CG1</a>	Unvented	31"

Vented

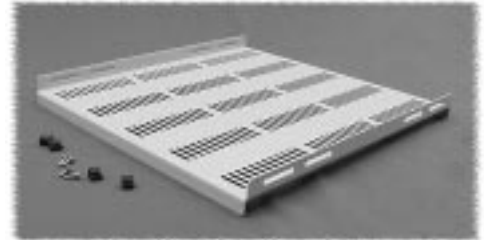

Unvented



## SLIDING SHELVES

- Heavy duty, 14 Ga. steel construction, folded edges on all four sides for extra strength
- The vented version provides a sturdy shelf without obstructing upward heat movement
- Weight load tested to 120 pounds
- Slides are slotted for easy adjustment with most rail depth locations
- Rugged textured powder paint finish

Part Number		Shelf Type	Shelf Depth
Black Textured	Beige Textured		
<b>19" Width</b>			
<a href="#">RSVS1918BK1</a>	<a href="#">RSVS1918CG1</a>	Vented	18"
<a href="#">RSVS1921BK1</a>	<a href="#">RSVS1921CG1</a>	Vented	21"
<a href="#">RSVS1926BK1</a>	<a href="#">RSVS1926CG1</a>	Vented	26"
<a href="#">RSVS1931BK1</a>	<a href="#">RSVS1931CG1</a>	Vented	31"
<a href="#">RSUS1918BK1</a>	<a href="#">RSUS1918CG1</a>	Unvented	18"
<a href="#">RSUS1921BK1</a>	<a href="#">RSUS1921CG1</a>	Unvented	21"
<a href="#">RSUS1926BK1</a>	<a href="#">RSUS1926CG1</a>	Unvented	26"
<a href="#">RSUS1931BK1</a>	<a href="#">RSUS1931CG1</a>	Unvented	31"
<b>24" Width</b>			
<a href="#">RSVS2418BK1</a>	<a href="#">RSVS2418CG1</a>	Vented	18"
<a href="#">RSVS2421BK1</a>	<a href="#">RSVS2421CG1</a>	Vented	21"
<a href="#">RSVS2426BK1</a>	<a href="#">RSVS2426CG1</a>	Vented	26"
<a href="#">RSVS2431BK1</a>	<a href="#">RSVS2431CG1</a>	Vented	31"
<a href="#">RSUS2418BK1</a>	<a href="#">RSUS2418CG1</a>	Unvented	18"
<a href="#">RSUS2421BK1</a>	<a href="#">RSUS2421CG1</a>	Unvented	21"
<a href="#">RSUS2426BK1</a>	<a href="#">RSUS2426CG1</a>	Unvented	26"
<a href="#">RSUS2431BK1</a>	<a href="#">RSUS2431CG1</a>	Unvented	31"

Vented



Unvented

