

## Shelves (Fixed) - Panel Mount (Single Pair of Panel Rails)



**Vented**  
(7" Deep - 1U Shown)
















**Unvented**  
(7" Deep - 1U Shown)

### Panel Rail Mounted - *Light Duty (Maximum 40 - 80 pound loads)* Fixed Chassis/Shelf (Vented or Unvented)



- Allows easy rack mounting of narrow equipment or items that do not have rack mounting capabilities.
- Shelves feature formed 16-gauge steel construction
- Choice of four heights - 1.75"(1U), 3.5"(2U) or 5.25"(3U) of panel space
- Front & back edge folded - acting as both stiffeners and equipment retainers..
- Weight load tested: (1U-40 pounds, 2U-65 pounds, 3U-80 pounds)
- Mounts to rack rails either as an internal shelf or external shelf/work area
- Choice of two depths - 7" or 14.5"
- Available in either vented or unvented versions
- Shelves include tie down slots on each side & four tie down holes.
- Perfect for our smaller desk top racks (ex: [RCBS](#), [RCHS](#), [RCHV](#), [RRTT](#), [1459](#) series)
- Rugged textured - black powder paint finish
- Requires mounting [hardware](#)

### UNVENTED


| Part Number                    | Panel Height |       | PDF<br>Reader<br>File   | AutoCAD<br>.dxf File<br>(zipped)  | 3D<br>Solid Model<br>.stp files<br>(zipped)   | Shelf<br>Depth | Weight Load<br>Rating<br>(Pounds) | Stiffener Lip(s)<br>Folded |
|--------------------------------|--------------|-------|---|---|---|----------------|-----------------------------------|----------------------------|
|                                | Inches       | Units |   |   |   |                |                                   |                            |
| <b>19" Rack Mount</b>          |              |       |   |   |   |                |                                   |                            |
| <a href="#">RASU190107UBK1</a> | 1.75         | 1     |  77K |  50K |  49K | 7"             | 40                                | Up<br>(front & back)       |
| <a href="#">RASU190107DBK1</a> | 1.75         | 1     |  74K |  43K |  38K | 7"             | 40                                | Down<br>(front & back)     |
| <a href="#">RASUL190314BK1</a> | 3.50         | 2     |  80K |  46K |  42K | 14.5"          | 65                                | Up<br>(back only)          |
| <a href="#">RASUL190514BK1</a> | 5.25         | 3     |  84K |  46K |  42K | 14.5"          | 80                                | Up<br>(back only)          |

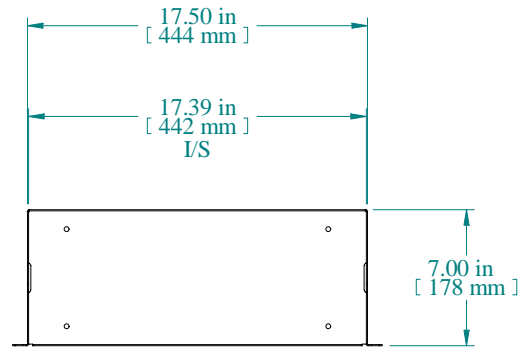

TOP VIEW

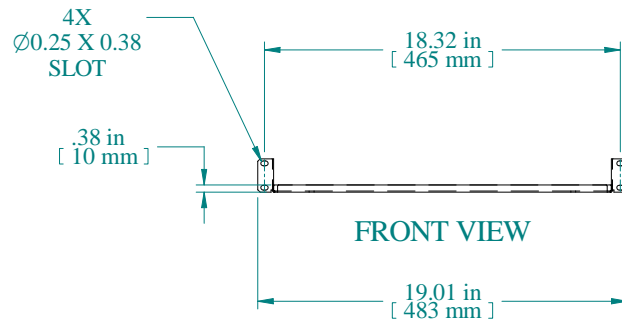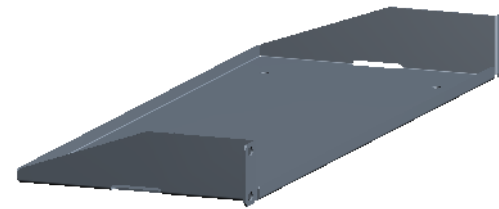

FRONT VIEW

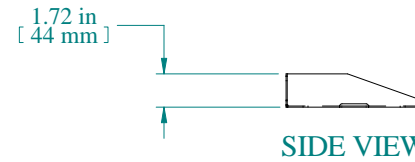


SIDE VIEW

| PART NUMBERS   |                        |
|----------------|------------------------|
| RASU190107UBK1 | PAINTED BLACK TEXTURED |

| NOTES   |
|---|
| Maximum Weight 40 lb<br>Mounting Hardware not Supplied with Shelf |

Data subject to change without notice. Isometric drawing not to scale.

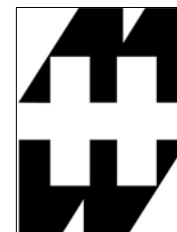

**HAMMOND  
MANUFACTURING™**

[www.hammondmfg.com](http://www.hammondmfg.com)

PART NO. RASU190107U