

# AIRVAL FOOT SWITCHES



The LINEMASTER AirVal foot switches were designed for ease of use and long life. The family of AirVal Foot Controls will meet your varying requirements in a foot operated air valve. With

the choice of two-way, three-way, or four-way operation, as well as two-way and three-way variable flow, Linemaster AirVals offer a versatile solution for applications requiring light to heavy duty foot controls. Maintained

action is a standard feature for one of the robust Hercules models. If our standard AirVal models do not meet your specific application, specialty switches are available. Only from Linemaster - American made innovation at work.

LINEMASTER Switch Corporation  
Tel (860) 974-1000

29 Plaine Hill Road, P.O. Box 238

Woodstock, Connecticut 06281-0238 USA  
Fax (800) 974-FOOT(3668)

[www.linemaster.com/ds/airval/](http://www.linemaster.com/ds/airval/)


# Pneumatic AIRVAL

## Dare to use Air



### FEATURES:

- 2-Way, 3-Way, 4-Way and Variable Flow
- Standard 1/8-27 NPT input & output ports
- Plunger can be depressed flush with valve body without damage to valve
- Filtered and lubricated air supply is required for best operation
- Line pressure up to 150 PSI
- 2-Way models do not exhaust back pressure
- Valve: Non-ferrous body, stainless steel plunger, teflon coated buna o-rings
- Full and twin guards as well as accessory base units are available for configurations using multiple switches

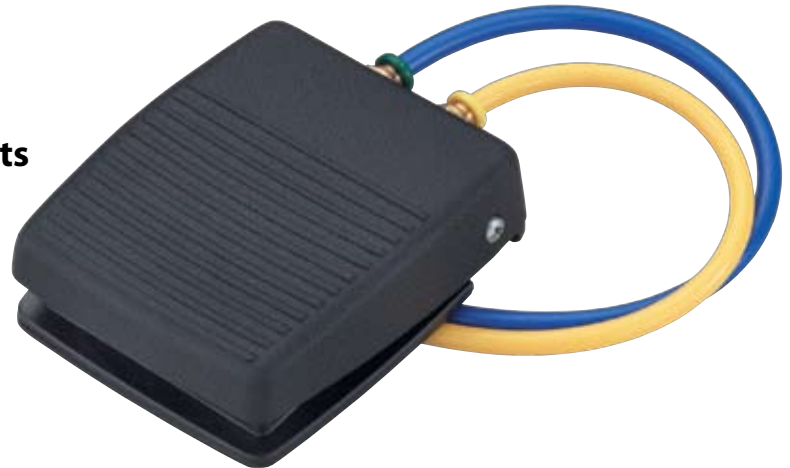

The Aquiline AirVal (Shown Above) is available on special order in 2-Way and 3-Way variations including variable flow. Available in single or multi-pedal versions, the Aquiline AirVal can also be supplied with fittings, tubing and special paint finishes.

### SPECIFICATIONS

FAMILY	Catalog Number	Type	Replacement Interior Valve	Air Flow at 100 PSI	Exhaust at 100 PSI	Operating Force	Ports 1/8-27 NPT
CLASSIC	2E-30A2-S	2-Way	2-30A2-SI	30 CFM	NONE	2-1/2 Pounds	Interior Housing
	3E-30A2-S	3-Way	3-30A2-SI	30 CFM	25 CFM	2-1/2 Pounds	Interior Housing
	2E-20V2-S	2-Way Variable	2-20V2-SI	20 CFM	NONE	2-1/2 Pounds	Interior Housing
	3E-20V2-S	3-Way Variable	3-20V2-SI	20 CFM	6 CFM	2-1/2 Pounds	Interior Housing
CLIPPER	2C-30A2-S	2-Way	2-30A2-SI	30 CFM	25 CFM	10 Pounds	Interior Housing
	3C-30A2-S	3-Way	3-30A2-SI	30 CFM	25 CFM	10 Pounds	Interior Housing
	4C-30F2-S	4-Way	4-30F2-SI	30 CFM	25 CFM	19 Pounds	Exterior Housing
TWIN CLIPPER & WIDE TREADLE	TWIN 3C-30A2-S	TWIN / 3-Way Each Side	3-30A2-SI	30 CFM	25 CFM	10 Pounds	Interior Housing
	3L-30A2-S	Wide Treadle / 3 Way	3-30A2-SI	30 CFM	25 CFM	8 Pounds	Interior Housing
COMPACT	2B-30A2-S	Single / 2-Way	2-30A2-SI	30 CFM	25 CFM	7 Pounds	Exterior Housing
	3B-30A2-S	Single / 3-Way	3-30A2-SI	30 CFM	25 CFM	7 Pounds	Exterior Housing
	TWIN 3B-30A2-S	Single / 3-Way Each Side	3-30A2-SI	30 CFM	25 CFM	7 Pounds	Exterior Housing
HERCULES	4H-30H2-SH	4-Way Momentary	4-30H2-SI	30 CFM	25 CFM	19 Pounds	Exterior Housing
	4H-30H2-DH	4-Way Maintained	4-30H2-SI	30 CFM	25 CFM	19 Pounds	Exterior Housing
PREMIER	3P-30A2-S	3-Way Momentary	3-30A2-SI	30 CFM	25 CFM	8 to 22 Pounds	Interior Housing

[www.linemaster.com/ds/airval/](http://www.linemaster.com/ds/airval/)