


The 700 Series sockets have the perfect mix of historical Magnecraft socket quality combined with a dynamic arsenal of options. When mated with the Magnecraft relays and accessories, these RoHS compliant sockets provide a complete modular system that will meet all your plug-in relay requirements in a package that is both visually appealing and functionally outstanding. Heavy-duty one piece track and contact system allows for more area of contact on the relay terminals, resulting in lower contact resistance and greater heat dissipation.


Finger-Safe Sockets with Screw Terminals

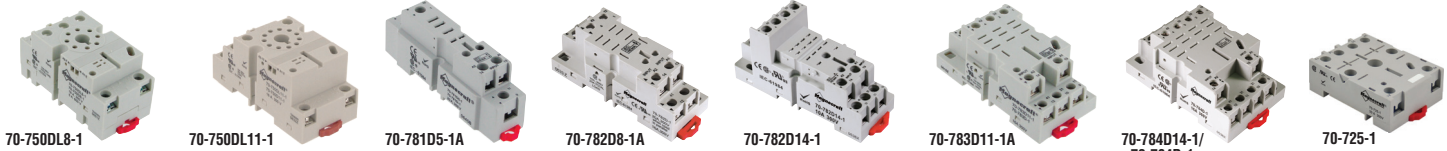

- ▶ 35 mm DIN or Panel Mounting
▶ IP20 Finger Safe Protection
- ▶ Accepts MOV, Diode, LED or RC Plug-In Modules
▶ -40 to 80°C Operating Temperature Range
- ▶ Coil Buss Jumper System Compatible Except as Indicated (—)
- ▶ UL and CSA Certification
▶ CE and RoHS Conformance

Sockets											Hold-Down Clips				
Stock No.	Mfr.'s Type	Use With Relay Series	No. of Terminals	Current Rating (Amps)	Voltage Rating (Volts)	Dimensions L x W x H (Inches)	Use Module Type	Use I.D. Tag Type	Use Jumper Type	EACH		Stock No.	Mfr.'s Type	Type	EACH
										1-19	20-49				
70185249	70-750DL8-1	750 (All) TDRSXP 750H	8	16	300	3.00 x 1.42 x 1.45	ASM	—	16-750/788CBJ-1	9.69	8.92	70185150 70185329 70185152	16-1332 16-1344 16-1351	Wire Wire Wire	.41 .91 .53
70185250	70-750DL11-1	750 (All) TDRSXP 750H	11	5	600	3.18 x 1.50 x 1.45	ASM	—	16-750/788CBJ-1	6.50	5.96	70185150 70185152 70185329	16-1332 16-1351 16-1344	Wire Wire Wire	.41 .53 .91
70185330	70-781D5-1A	781 (All)	5	20	300	3.33 x 0.82 x 1.18	BSM	—	—	4.88	4.63	70185291 70185315	16-781SC 16-781IDC	Wire Plastic	.70 1.71
70185331	70-782D8-1A	782 With 0.187 Terminal	8	16	300	3.33 x 1.18 x 1.18	BSM	—	—	5.30	5.10	70185324 70185316	16-782SC 16-782IDC	Wire Plastic	.92 2.04
70185232	70-782D14-1	782, 4 Pole (Plain and Full Featured) 782, 4 Pole (Full Featured) 782, Hermetic Only	14	10	300	3.30 x 1.18 x 1.57	BSM	16-700ST-1	—	6.18	5.70	70185324 70185253 70185151	16-782SC 16-782PC-1 16-1342	Wire Plastic Wire	.92 .37 .53
70185332	70-783D11-1A	783 (All)	11	16	300	3.33 x 1.57 x 1.18	ASM	—	—	5.54	5.08	70185325 70185317	16-783SC 16-783IDC	Wire Plastic	1.20 2.78
70185251	70-784D14-1	784 (All)	14	16	300	3.33 x 1.96 x 1.18	ASM	—	—	10.15	9.35	70185326 70185318	16-784SC 16-784IDC	Wire Plastic	1.59 2.81
70185423	70-725-1	725 (Plug-in Models)	6	30	300	2.78 x 2.12 x 0.92	ASM	16-700ST-1	—	10.40	10.20	70185424	16-725SC-1	Wire	1.73

Finger-Safe Sockets with Eurostyle (Elevator) Terminals

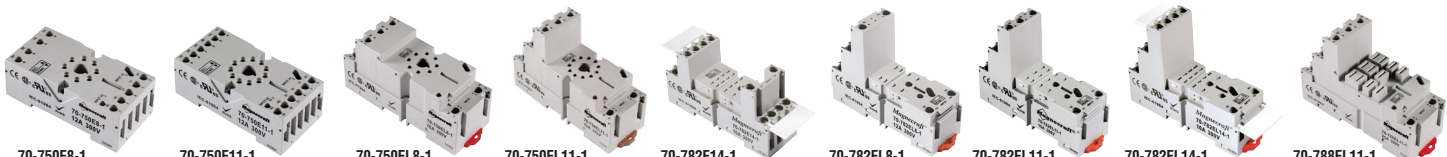

- ▶ 35 mm DIN or Panel Mounting Except as Indicated*
▶ IP20 Finger Safe Protection
- ▶ Accepts MOV, Diode, LED or RC Plug-In Modules
▶ Accepts Write-On Plastic I.D. Labels
- ▶ Coil Buss Jumper System Compatible
▶ -40 to 80°C Operating Temperature Range
- ▶ UL and CSA Certification
▶ CE and RoHS Conformance

Sockets											Hold-Down Clips				
Stock No.	Mfr.'s Type	Use With Relay Series	No. of Terminals	Current Rating (Amps)	Voltage Rating (Volts)	Dimensions L x W x H (Inches)	Use Module Type	Use I.D. Tag Type	Use Jumper Type	EACH		Stock No.	Mfr.'s Type	Type	EACH
										1-19	20-49				
70185084	70-750E8-1	750 (All), 750H 750 (All), TDRSRXP, 712	8	12	300	2.95 x 1.49 x 1.06	70-ASM	16-750/788FT-1	—	5.27	4.85	70185152 70185329	16-1351 16-1344	Wire Wire	.53 .91
70185085	70-750E11-1	750 (All), 750H, 755 TDRSRXP, 712	11	12	300	2.95 x 1.49 x 1.06	70-ASM	16-750/788FT-1	—	6.03	5.56	70185152 70185329	16-1351 16-1344	Wire Wire	.53 .91
70185235	70-750EL8-1	750 (All), 750H	8	16	300	3.77 x 1.40 x 1.77	70-ASM	16-750/788FT-1	16-750/788CBJ-1	8.66	7.97	70185152	16-1351	Wire	.53
70185234	70-750EL11-1	750 (All), 750H, 755	11	16	300	3.77 x 1.40 x 2.48	70-ASM	16-750/788FT-1	16-750/788CBJ-1	9.53	8.74	70185152	16-1351	Wire	.53
70185229	70-782E14-1	782, 4 Pole (Plain and Full Featured) 782, 4 Pole (Full Featured) 782, Hermetic Only	14	10	300	3.12 x 1.06 x 1.69	70-BSM	16-782FT-1	—	5.26	4.83	70185324 70185253 70185151	16-782SC 16-782PC-1 16-1342	Wire Plastic Wire	.92 .37 .53
70185231	70-782EL8-1	782, 2 Pole (All) 782, 2 Pole (Full Featured)	8	12	300	3.34 x 1.06 x 2.40	70-BSM	16-782FT-1	16-782CBJ-1	3.75	3.43	70185324 70185253	16-782SC 16-782PC-1	Wire Plastic	.92 .37
70185228	70-782EL11-1	782, 3 Pole (All) 782, 3 Pole (Full Featured)	11	10	300	3.34 x 1.06 x 2.40	70-BSM	16-782FT-1	16-782CBJ-1	5.26	4.83	70185324 70185253	16-782SC 16-782PC-1	Wire Plastic	.92 .37
70185230	70-782EL14-1	782, 4 Pole (Plain and Full Featured) 782, 4 Pole (Full Featured) 782, Hermetic Only	14	10	300	3.34 x 1.06 x 2.40	70-BSM	16-782FT-1	16-782CBJ-1	7.06	6.50	70185324 70185253 70185151	16-782SC 16-782PC-1 16-1342	Wire Plastic Wire	.92 .37 .53
70185233	70-788EL11-1*	788 (All), 711, 389F	11	25	300	3.70 x 1.40 x 2.48	70-ASM	16-750/788FT-1	16-750/788CBJ-1	8.15	7.51	70185152	16-1351	Wire	.53

*DIN mount only.