





Quick turn delivery available on standard terminal types.

5 Energy Way, P.O. Box 1019, West Warwick, RI 02893 USA Tel. 800-424-9850/401-823-5200 • Fax 401-823-8723 • Email info@advintcorp.com • Internet http://www.advintcorp.com


Contact Acceptance Range .016" (.41mm) - .022" (.56mm) Dia. or .010" (.25mm) x .018" (.46mm) Rectangular Lead

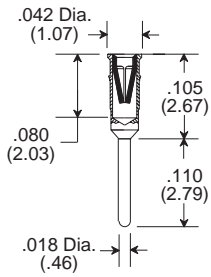


Type	Part Number	Contact Group
-347	4040-1	A

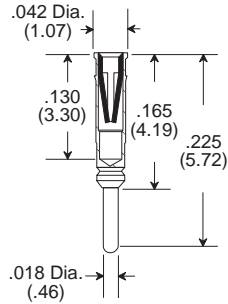


Type	Part Number	Contact Group
-586	4793	A

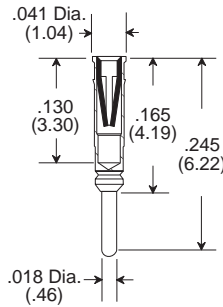


Type	Part Number	Contact Group
-168	3655	A

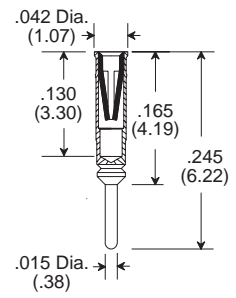


Type	Part Number	Contact Group
-386	4179	A

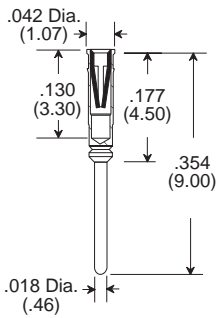


Type	Part Number	Contact Group
-595	4858	A

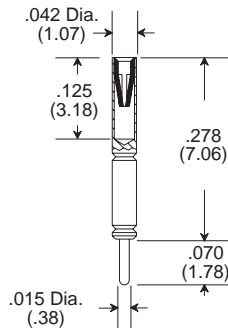


Type	Part Number	Contact Group
-205	2403	A

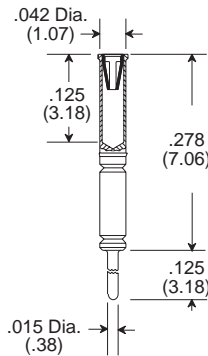


Type	Part Number	Contact Group
-474	4038	A

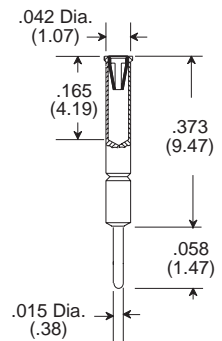


Type	Part Number	Contact Group
-425	3503-2	A

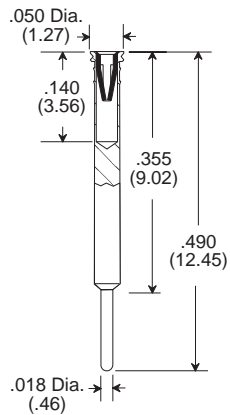


Type	Part Number	Contact Group
-496	4462	A

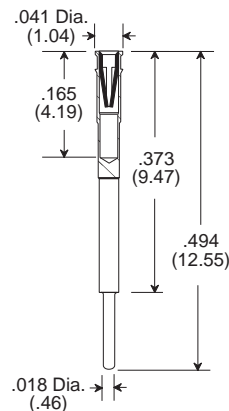

Type	Part Number	Contact Group
-505	4511	A

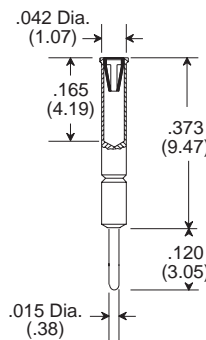

Type	Part Number	Contact Group
-269	3503-1	A

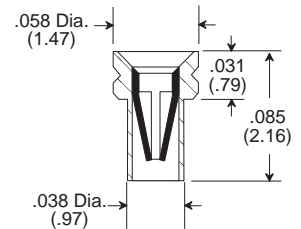

Type	Part Number	Contact Group
-550	4659	A

Material:
Terminal: Brass - Copper Alloy (C36000), ASTM-B-16
Contact: Beryllium Copper - Copper Alloy (C17200), ASTM-B-194

Plating:
Contact: G = Gold/Nickel
T = Tin-Lead/Nickel

Gold: per MIL-G-45204
Tin-Lead: per MIL-P-81728
Nickel: per QQ-N-290

Note: Pins with "V" groove in head may be supplied in Peel-A-Way®

Terminals not drawn to scale.