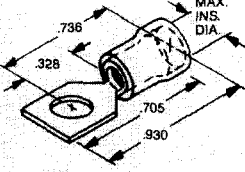


Spade and Ring Series Pre-Insulated


**.380 Square Spade
.031 Electro-Tinned Copper
16-14 AWG (Blue)**

S P A D E & R I N G

STYLE AND DIMENSIONS	STUD	MAX. INSULATION DIAMETER			SEAM	UL	CSA	QUANTITY PER REEL	PART NUMBER		
		.147	.200	.250							
	6	X			B	✓	✓	4000	50487		
				X		B	✓	✓	3000	50487-8	
					X		B	✓	*	3000	50487-8A
		X				W	✓	✓	4000	50488	
				X			W	✓	✓	3000	50488-8
					X		W	✓	*	3000	50488-8A
	8	X				B	✓	✓	4000	50499	
				X		B	✓	✓	3000	50499-8	
					X		B	✓	*	3000	50499-8A
		X				W	✓	✓	4000	50500	
				X			W	✓	✓	3000	50500-8
					X		W	✓	*	3000	50500-8A
10	X				B	✓	✓	4000	50511		
			X		B	✓	✓	3000	50511-8		
				X		B	✓	*	3000	50511-8A	
	X				W	✓	✓	4000	50512		
			X			W	✓	✓	3000	50512-8	
				X		W	✓	*	3000	50512-8A	

Spade and Ring Series Pre-Insulated

**.500 Square Spade
.031 Electro-Tinned Copper
16-14 AWG (Blue)**

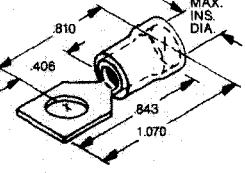STYLE AND DIMENSIONS	STUD	MAX. INSULATION DIAMETER			SEAM	UL	CSA	QUANTITY PER REEL	PART NUMBER		
		.147	.200	.250							
	10	X			B	✓	✓	4000	50691		
				X		B	✓	✓	3000	50691-8	
					X		B	✓	*	3000	50691-8A
		X				W	✓	✓	4000	50692	
				X			W	✓	✓	3000	50692-8
					X		W	✓	*	3000	50692-8A
	1/4	X				B	✓	✓	4000	50703	
				X		B	✓	✓	3000	50703-8	
					X		B	✓	*	3000	50703-8A
		X				W	✓	✓	4000	50704	
				X			W	✓	✓	3000	50704-8
					X		W	✓	*	3000	50704-8A

Recommended Strip Length $\frac{3}{32} \pm \frac{1}{32}$
* Contact Factory for Latest Agency Approvals.