


## Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

## Olympic P/N 3418, MIL-W-16878 Type E PTFE Shielded Cables

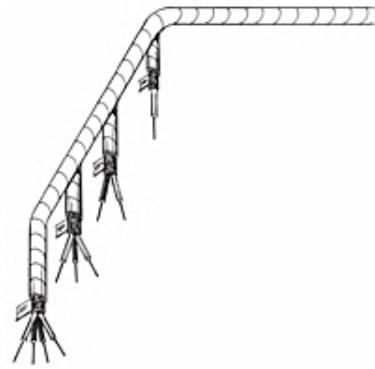

### MIL-W-16878 Type E PTFE Shielded Cables

Stranded silver plated Copper conductors, insulated with Type E extruded PTFE, color coded, twisted, braided silver plated Copper shield (90% coverage), white PTFE tape wrapped jacket.

**Temperature Rating:**  
-65°C to +200°C

## SPECIFICATIONS

No. of Conductors	3
Conductor Size	22 AWG
Stranding	19/34, Silver Plated Copper
Nom. Wall Thickness	0.010 in
Nom. Jacket Thickness	0.012 in
Nom. O.D.	0.149 in
Voltage	600 V
Insulation	PTFE
Shielding	85% Silver Plated Copper Braid
Jacket	PTFE Wrap, White
Color Code	Black Red White
Operating Temperature	-65 to 200 °C

RoHS Compliant



RoHS Compliant